

BOLLARDS

Push Plate Accessories

COMPATIBLE WITH


- LPR36 - 36 inch full-length actuator (pg 57)
- Panther plates - 4.75 inch square (pg 58)
- Vestibule plates (pg 60)
- 4.5 inch round plates (pg 53)
- 4.5 inch square plates (pg 53)
- 4.75 inch square plates (pg 54)

TECHNICAL SPECIFICATIONS

Dimensions (with cap attached)	6.25 in (W) × 41.5 in (H) × 4.25 in (D)
Material	Powder-Coated (Inside and Out) Carbon Steel UV-Resistant ABS Plastic Stainless Steel
Post	
Cap	
Bracket	
Push Plate Options	4.5 in Square, 4.75 in Square, 4.75 in Square Panther, 4.5 in Round, Dual Vestibule and LPR36 High-low actuator
Weight	35 lbs (16 kg)
Color	Black, Bronze, Silver
Hardware Included	Screws (4) Screws (3) and Finishing Washers (3) Expansion Anchors (4), Lock Washers (4) and Nuts (4)
Post	
Cap	
Bracket	

PRODUCT SERIES

P/N	Description
10BOLLARDBLK	Mounting post for stainless steel push plates-Black
10BOLLARDSLV	Mounting post for stainless steel push plates-Silver
10BOLLARDBRZ	Mounting post for stainless steel push plates-Bronze
10BOLLARDBLKWOH	Mounting post without precut mounting holes-Black
10BOLLARDSLVWOH	Mounting post without precut mounting holes-White
10BOLLARDBRZWOH	Mounting post without precut mounting holes-Bronze
	Bollard hardware pack includes:
50.0071	Compression bolts, undercut screws and washers
50.0072	U shaped bollard mounting bracket
50.0073	Plastic transmitter shelf for bollard
	Bollard hardware pack includes:
50.5320	Larger compression bolts, undercut screws and washers
70.0195	Bollard cap
70.5022	U-shaped Bollard mounting bracket (bracket only), larger screw holes

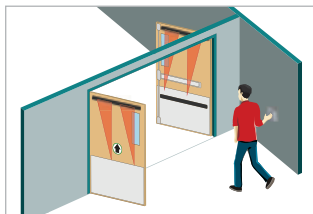

BOXES AND BRACKETS

Push Plate Accessories

COMPATIBLE WITH

- Jamb plates (pg 56)
- Single gang plates (pg 59)
- Vestibule plates (pg 60)
- 4.5 inch round & square plates (pg 53)
- 4.75 inch square plates (pg 54)
- 6 inch round & square plates (pg 55)

PRODUCT SERIES

P/N	Description
10BOXDGSM	Standard double gang surface mount box (4.5 x 4.5 in)
10BOXDG4H	Plastic mount box (4 x 4 x 0.5 in)
10BOX24SGSM	Standard single gang surface mount box (2.75 x 4.5 in)
10BOX45SQFM	PBS45 series flush mount box (4.5 in square)
10BOX45SQSM	PBS45 series surface mount box (4.5 in square)
10BOX45RNDFM	PBR45 series flush mount box (4.5 in round)
10BOX45RNDSM	PBR45 series surface mount box (4.5 in round)
10BOX475SQFM	PBS series flush mount box (4.75 in square)
10BOX475SQSM	PBS series surface mount box (4.75 in square)
10BOX6SQFM	PBS6 series flush mount box (6 in square)
10BOX6SQSM	PBS6 series surface mount box (6 in square)
10BOX6RNDFM	PBR series flush mount box (6 in round)
10BOX6RNDSM	PBR series surface mount box (6 in round)
10BOXJAMBFM	PBJ / PBJM series flush mount box (1.5 x 4.75 in jamb)

PRODUCT SERIES CONT'D

P/N	Description
10BOXJAMBSM	PBJ / PBJM series surface mount box (1.5 x 4.75 in jamb)
10BOXJAMBST	PBJMS series surface mount box; hard wired only (1.75 x 4.5 in jamb)
10ESCUTCHEON	PBR series stainless steel surface mount box; commonly used in hospital applications (6 in round)
10ESCUTCHEON45	PBR45 series stainless steel surface mount box; commonly used in hospital applications (4.5 in round)

MOUNTING ADAPTERS

P/N	Description
10PBRACKET	PBR / PBS series surface mount kit (6 in round and 4.75 in square)
10BPBRACKETCA	PBR / PBS series surface mount kit - clear anodized (6 in round and 4.75 in square)
10BRINGC	Back plate required for double gang electrical boxes
10WRSQ475	PBS series weather ring (4.75 in square)
10WRRND45	PBR45 series weather ring (4.5 in round)
10WRRND6	PBR series weather ring (6 in round)
50.5016	PBDGP series adapter ring (included with PBDGP1 Vestibule Plate)