




JPM818A

## CAT6 FEED-THROUGH PATCH PANELS

**No punchdowns needed with these feed-through panels**

- Feed-through design features RJ-45 plugs on both sides of the patch panels
- Compliant with CAT6 specs
- Work with either T568A or T568B wiring

CATALOG #	DESCRIPTION
JPM818A	CAT6 Feed-Through Patch Panel, 24 Port, 1U, 19"W, Unshielded
JPM820A	CAT6 Feed-Through Patch Panel, 48 Port, 2U, 19"W, Unshielded
JPM814A	CAT6 Feed-Through Patch Panel, 24 Port, 1U, 19"W, Shielded
JPM816A	CAT6 Feed-Through Patch Panel, 48 Port, 2U, 19"W, Shielded

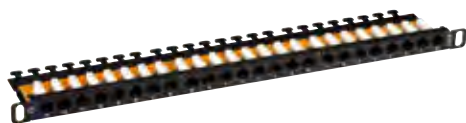

## CAT6 SPACEGAIN 24-PORT 1/2U PATCH PANEL

**Save rack space—get 24 ports in only a half U**

- Ideal for retrofitting data cabinets and high-density data centers
- Cable terminates to the 110 blocks in a 90-degree, top-down manner
- To save space, terminate cable perpendicularly to 110 blocks on rear of panel
- To terminate, slide the panel forward
- Includes rear cable management

CATALOG #	DESCRIPTION
JPM624A-HU	Patch Panel, 24 Port, 1/2U



JPM648A

## BLACK BOX® CONNECT CAT6 PATCH PANELS

**The smart choice for basic patch panels**

- Constructed of 16-gauge metal
- 3-Micron gold contacts
- Include 12-24 and 10-32 mounting screws
- Two-year warranty

CATALOG #	DESCRIPTION
JPM624A	CAT6 Patch Panel, 24 Port, 1U
JPM648A	CAT6 Patch Panel, 48 Port, 2U

