

Proximity Access Cards

The RF-programmable proximity access card is the industry choice for a cost-effective solution to proximity access control.

Proven, Reliable Technology: Offers extremely consistent read range. Unaffected by body shielding or variable environmental conditions, even when close to keys and coins.

Convenient To Use: Can fit into a wallet or purse. Use with a strap and clip as a photo ID badge.

Security: Offers over 137 billion unique codes.

Long Life: Passive, no-battery design allows for an infinite number of reads.

Durability: Strong, flexible and resistant to cracking and breaking



Features:

- Offers universal compatibility with all BlueWave Security proximity readers.
- Provides durable packaging and consistent read range.
- Provides an external number for easy identification and control.
- Supports formats up to 85 bits, with over 137 billion codes.
- Custom pre-printed artwork available.
- A PVC overlay (ISO version) allows for on-site photo ID using most direct image printers.

Specifications:

Operating Temperature: -50° to 160° F (-45° to 70° C)

Weight: 0.24 oz. (6.8 gm)

TYPICAL MAXIMUM* READ RANGE:

BlueWave reader-up to 3" (7.5 cm)

MiniProx® reader-up to 5.5" (14 cm)

ThinLine® II reader-up to 5.5" (14 cm)

ProxPro® reader-up to 8" (20 cm)

ProxPro® II reader-up to 9" (22.9 cm)


Prox80™-up to 5.5" (14 cm)

MaxiProx® reader-up to 24" (60 cm)

**Depending on local installation conditions.*

26bit Wiegand Standard Prox Cards
26B-CLMS-20

26bit Wiegand ISO Photo Ready Card
26B-ISO-20

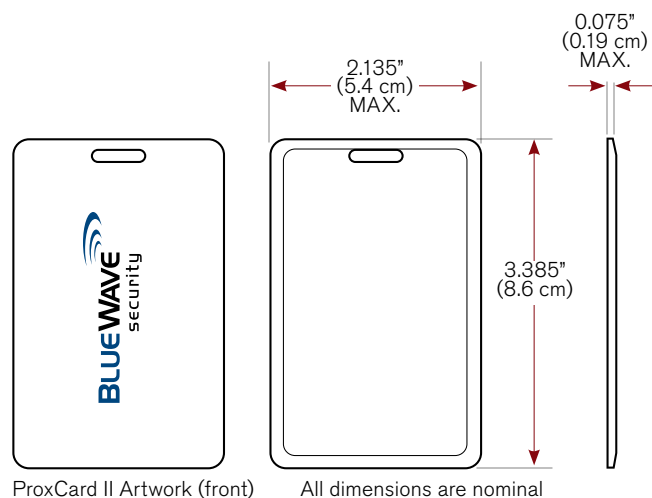

BLUEWAVE
security

The IP Lock and Security Company

2270 Camino Vida Roble
Carlsbad, CA 92011

Tel: 760-929-9596

Email: Sales@BlueWaveSecurity.com

Distributed by:

