


CE-IDX30(B) Indoor True D/N IR Dome Camera



CE-IDX30



CE-IDX30B

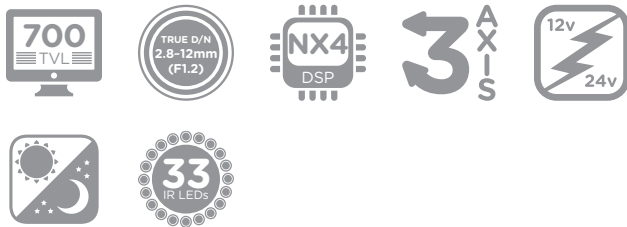

INFO:

- 1/3" SONY Super HAD II CCD
- 700 TVL Resolution
- 33 IR LEDs
- 2.8-12mm (F1.2) Lens (True D/N Version)
- NX4 Digital Signal Processor (DSP)
- OSD Menu Control via Built-in Joystick, CE-REMOTE
- 3 Axis Adjustment
- DC12V/AC24V
- Mounts to: Single Gang, Double Gang, 3-1/4" & 3-1/2", or 4" Oct/Rd Conduit Boxes
- UL Listed

DIMENSIONS:

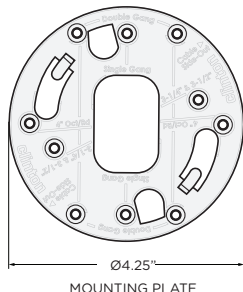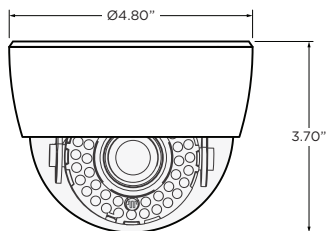

SPECIFICATIONS:

CAMERA	
Image Sensor	1/3" SONY Super HAD II CCD (960H)
Resolution	700 TVL
Effective Pixels	976 (H) x 494 (V)
Scanning System	2:1 Interlace
S/N Ratio	52dB (AGC Off)
Sync System	Internal / Line Lock
Minimum Illumination	0.15 Lux (Color), 0.0006 Lux (Sens-Up)
Shutter Speed	Auto / Manual (1/60, 1/50 - 1/100,000)
Lens	2.8-12mm (F1.2) Lens (True D/N Version)
Video Output	1.0 Vp-p, 75Ω
Frequency	Horizontal: 15.734 KHz, Vertical: 59.94 Hz
Power Consumption	Max. 220mA (DC12V), Max. 110mA (AC24V)
Power Requirement	DC12V / AC24V
Operating Temperature	32°F -113°F / 0°C - 45°C
Operating Humidity	90% RH Max.
Weather Rating	N/A
IR LEDs	33 IR LEDs
Heaters/Fan	N/A
Materials	Plastic Case w/Polycarbonate Dome
Dimensions	4.80" (Dia.) x 3.70" (H) / 121.9mm (Dia.) x 93.9mm(H)
Weight	0.60 lbs / 0.27 kg

OSD	
DSP Type	NX4
Menu Control	OSD Menu Control via Built-In Joystick
Exposure	Brightness, Shutter, AGC
Sens-Up	Yes (Level Adjustable)
White Balance	ATW, AWB, AWC Set, Manual, Indoor, Outdoor
Digital Dynamic Range	Yes (DWDR)
Backlight Control	BLC, HSBLC
Day/Night	Auto, Color, B&W, External
Noise Reduction	3DNR
Camera Title/ID	Yes (Up to 15 Characters)
Sync	Internal / Line Lock
Monitor	LCD, CRT
Motion Detection	4 Areas
Privacy Masking	8 Zones
Digital Image Stabilization	Yes
Dead Pixel Control	Yes (Defect)
Digital Effects	Mirror, Freeze, D-Zoom, Smart D-Zoom, Defog
Languages	English, Korean, Japanese, Chinese, Russian, Français, Español, Italiano, Português, Dutch, German, Polish, Turkish, Hebrew, Arab.
Other	Sharpness, Lens Shading

ACCESSORIES	
CE-REMOTE	Plug in OSD remote
CE-IDXWB (White)	Wall Bracket for IDX Series Cameras
CE-IDXPC (White)	Pendant Cap for IDX Series Cameras
CE-IDXDPC (White)	Deep Pendant Cap for IDX Series Cameras
CE-IDXWBB (Black)	Wall Bracket for IDX Series Cameras
CE-IDXPCB (Black)	Pendant Cap for IDX Series Cameras
CE-IDXDPCB (Black)	Deep Pendant Cap for IDX Series Cameras

CERTIFICATIONS:

