



The ComNet™ PS12DC-1A-UNI has a removable pin head to allow it to use one of four different outlet configured pin heads to supply 12V DC power to ComNet stand-alone units. The PSU can also accept a standard figure 8 line cord input. Pin heads for the UK and Europe will be included as standard. The US and Australian heads are available upon request at no extra charge.



SPECIFICATIONS

Electrical & Mechanical

Input Voltage Range: 100 (-10%)VAC to 240 (+10%)VAC
 Input Frequency Range: 47Hz - 63Hz
 Input Power Consumption
 (at no load): 0.3W Max
 Input Current 0.35A Max
 Output Voltage: +12V
 Output Load Range: 1.0A
 Size (L×W×H): 3.7 × 4.65 × 7.7cm (1.5 × 1.8 × 3.1 in)
 Shipping Weight: <1kg / 2lb

Environmental

Storage Temperature: -20°C - +70°C
 Operation Temperature: 0°C - 40°C
 Relative Humidity: 10% - 95% non-condensing
 MTBF: 50,000 hours at 25°C

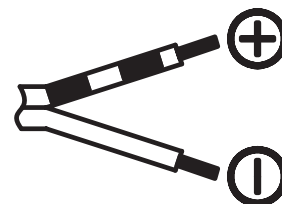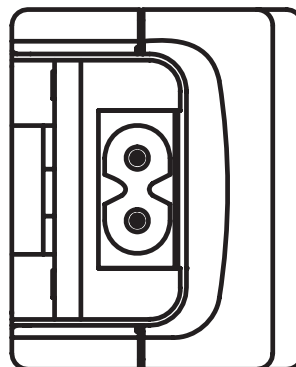

Power Supply connections: Figure 8 line cord input (left),
 wired positive and negative connections (right).

ORDERING INFORMATION

Part Number	Description
PS12DC-1A-UNI	12VDC Switching Power Supply
Accessories	EU & UK Pin Head (Included)
Options	Australian Pin Head (available on request, no charge) USA Pin Head (available on request, no charge) Standard figure 8 line cord (extra charge, consult factory)

