
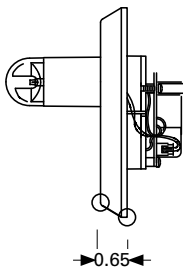


Colored Lens Appliances

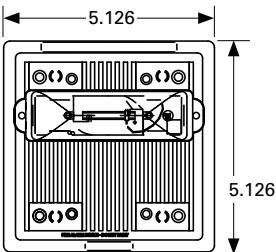

| Product Type | Model Number | Color | Order Code |
|------------------------------|--------------------------------------|-------|------------|
| Weatherproof Strobes | 75cd RSSWPA-2475W-NW | Amber | 0240 |
| | 115/177cd RSSWPA-24MCCH-NW | Amber | 6158 |
| | RSSWPB-24MCCH-NW | Blue | 6159 |
| | RSSWPG-24MCCH-NW | Green | 6160 |
| | RSSWPR-24MCCH-NW | Red | 6161 |
| Weatherproof Speaker Strobes | ET70WPA-2475W-NW | Amber | 0220 |
| Multitones | 115/177cd MTA-24MCCH-NW | Amber | 6167 |
| | MTB-24MCCH-NW | Blue | 6168 |
| | MTG-24MCCH-NW | Green | 6169 |
| | MTR-24MCCH-NW | Red | 6170 |
| Weatherproof Multitones | MTA-121575W-NW | Amber | 0048 |
| Weatherproof Multitones | MTWPA-2475W-NW | Amber | 1649 |
| | 115/177cd MTWPA-24MCCH-NW | Amber | 6171 |
| | MTWPB-24MCCH-NW | Blue | 6172 |
| | MTWPG-24MCCH-NW | Green | 6173 |
| | MTWPR-24MCCH-NW | Red | 6174 |

Note: Reference pages 58-65 for additional mounting information.

Series **ET, MT, MTWP, RSSWP** Colored Lens Appliances

Available features and options:

- Designed for effective alerting of employess and personnel in industrial, military or government applications
- Wide operating voltage range

Lens Colors: Amber, Blue, Green, Red

Mounting: Wall or Ceiling

Voltage: 24 VDC

Approvals: UL

Candela is measured on axis per UL 1638. Models with MCC strobes have 4 field selectable candela settings. MCC settings are rated for clear lens—derate approximately 25% for amber, 55% for green and 70% for blue lenses.

UL Max. Current

| Series | 16–33 VDC | | |
|------------|-----------|-------|-------|
| | 15/75cd | 115cd | 177cd |
| RSSWP/MTWP | 0.138 | 0.300 | 0.420 |

| Series | 8–17.5 VDC |
|--------|------------|
| | 15/75cd |
| MT | 0.255 |