


## CRL Jackson 10 Series Panic Exit Devices

- Designed for Use With 1-3/4" (44 mm) Narrow, Medium, and Wide Stile Aluminum, Wood, or Hollow Metal Doors
- Available With Crossbar or Engraved "Push" Paddle Operation on Active Side
- Concealed Fastening for Added Security

CRL Jackson Panic Exit Devices are universally recognized as the standard for aluminum storefront hardware. These Exit Devices are designed to withstand wear and tear, yet remain aesthetically pleasing for years to come. Each part is manufactured from the highest quality materials, which are hand fitted and adjusted for a smooth, whisper-quiet operation. CRL Jackson Panic Exit Devices are suitable for use with 1-3/4" (44.5 mm) narrow, medium, and wide stile aluminum, wood, or hollow metal doors. For additional information, contact CRL Technical Sales at (800) 421-6144 in the U.S., or (877) 421-6144 from Canada, and ask for Ext. 7520. You can also visit our website at [crlaurence.com](http://crlaurence.com).

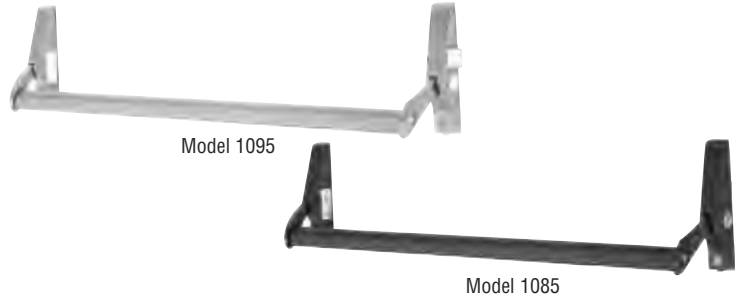

Model 1095

Model 1085

### CROSSBAR EXIT DEVICES

CAT. NO.	TYPE	HANDING	FINISH
311095LC4628	Rim - 'C' Strike	Left Hand-Reverse Bevel	Satin Aluminum
311095RC4628	Rim - 'C' Strike	Right Hand-Reverse Bevel	Satin Aluminum
311095LC4313	Rim - 'C' Strike	Left Hand-Reverse Bevel	Dark Bronze
311095RC4313	Rim - 'C' Strike	Right Hand-Reverse Bevel	Dark Bronze
311095LS4628	Rim - 'S' Strike	Left Hand-Reverse Bevel	Satin Aluminum
311095RS4628	Rim - 'S' Strike	Right Hand-Reverse Bevel	Satin Aluminum
311095LS4313	Rim - 'S' Strike	Left Hand-Reverse Bevel	Dark Bronze
311095RS4313	Rim - 'S' Strike	Right Hand-Reverse Bevel	Dark Bronze
31108547628	Concealed Vert. Rod	Non-Handed	Satin Aluminum
31108547313	Concealed Vert. Rod	Non-Handed	Dark Bronze

Minimum order: 1 each. All Panic Exit Devices can be combined for quantity pricing.

### PADDLE DEVICES

CAT. NO.	TYPE	HANDING	FINISH
311095PLC628	Rim - 'C' Strike	Left Hand-Reverse Bevel	Satin Aluminum
311095PRC628	Rim - 'C' Strike	Right Hand-Reverse Bevel	Satin Aluminum
311095PLC313	Rim - 'C' Strike	Left Hand-Reverse Bevel	Dark Bronze
311095PRC313	Rim - 'C' Strike	Right Hand-Reverse Bevel	Dark Bronze
311085PL7628	Concealed Vert. Rod	Left Hand-Reverse Bevel	Satin Aluminum
311085PR7628	Concealed Vert. Rod	Right Hand-Reverse Bevel	Satin Aluminum
311085PL7313	Concealed Vert. Rod	Left Hand-Reverse Bevel	Dark Bronze
311085PR7313	Concealed Vert. Rod	Right Hand-Reverse Bevel	Dark Bronze

Minimum order: 1 each. All Paddle Exit Devices can be combined for quantity pricing.



'C' Strike

'S' Strike



Paddle Device

### SPECIFICATIONS:

- Contoured Field Sizeable 48" (1219 mm) Long Crossbar
- Dual Dogging Feature – By Outside Cylinder – By Dogging Pins on Panic Housing
- Wear Points Insulated by Nylon Sleeves and Rollers

### 1095 Rim Device

- Requires Rim Cylinder for Keyed Entry; See Page D463 for Cylinders
- Cylinder Mounting Pad Not Required

### 1085 Concealed Vertical Rod Device

- Standard Height 84" (2134 mm); See Page D462 for Extensions
- Requires Mortise Cylinder and No. 30821J Mounting Pad for Keyed Entry; See Page D462-D463 for Cylinders and Pads

### MATERIALS:

- Body and Arms: High Tensile Strength Aluminum
- Mechanical Components: Stainless and Hardened Plated Steel
- Latch and Strikes: Sintered Steel

## CRL Jackson 10 Series Push-Pad Retrofit Device

- Sleek, Contemporary Style Push-Pad to Retrofit Existing Jackson 1085 Concealed Vertical Rod Crossbar Exit Devices
- Uses Existing 10 Series Rod and Case Assembly
- Easy Installation – Cut to Fit



36" DOOR CAT. NO.	48" DOOR CAT. NO.	HANDING	FINISH
311285RL3628	311285RL4628	Left Hand-Reverse Bevel	Satin Aluminum
311285RR3628	311285RR4628	Right Hand-Reverse Bevel	Satin Aluminum
311285RL3313	311285RL4313	Left Hand-Reverse Bevel	Dark Bronze
311285RR3313	311285RR4313	Right Hand-Reverse Bevel	Dark Bronze

Minimum order: 1 each.

### SPECIFICATIONS:

- Stocked in Both 36" (914 mm) and 48" (1219 mm) Widths

### MATERIALS:

- Base and Push-Pad: Extruded Aluminum
- Mechanical Components: Stainless and Hardened Plated Steel