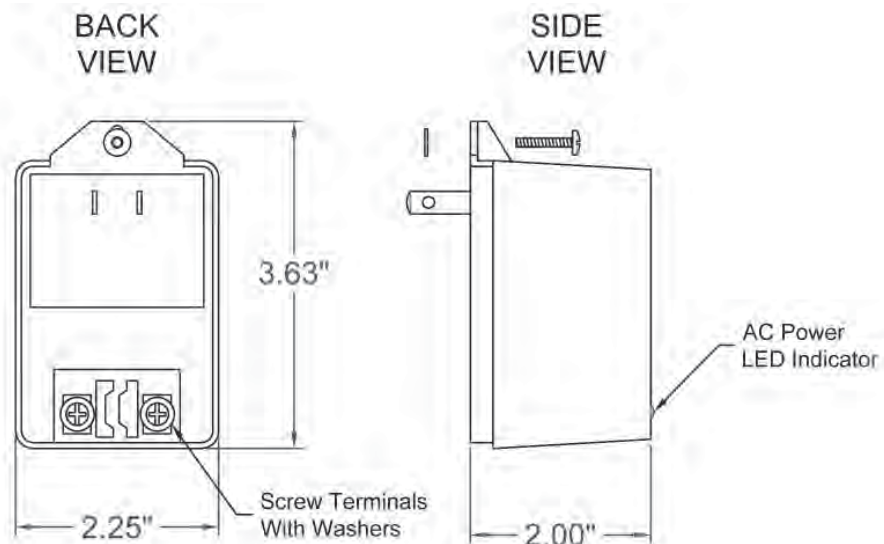


Plug-in Transformer Features - LED and Basic Surge Protection

Description	Plug-in Class II Transformer with LED Power indicator, built in cable strain relief, and has basic surge protection. The housing is bright white plastic, and comes with a mounting tab and screw.
Specifications	UL Listed Primary: 120VAC 60Hz Secondary: 16.5VAC 20VA Primary Termination: 2 Male Blades Secondary Termination: 2 #6-32 Screw Terminals w/washers Dimensions: W:2.25" (57mm) x 2.0" (50mm) D x H 3.63" (92mm) Weight: 1LB Color: White
Surge Protection	Single mode (hot to neutral), Clamping Voltage 340V, Max. Spike 4500 Amps, Energy Dissipation 60 Joules Max. Spike Voltage 6000 Volts Clamping Response Time 15 ns (Nanoseconds)
For Use With	ES4200, ES4300, ES4600, ES411