



Regular Style Deadbolt

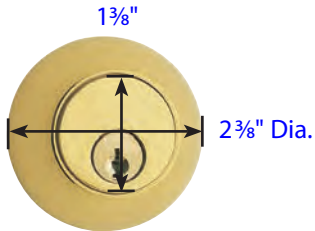

Exterior Trim (8450)


- Projection is $1\frac{3}{16}$ "
- 8350 same on both sides
- Available Extension Collar for Thin Doors

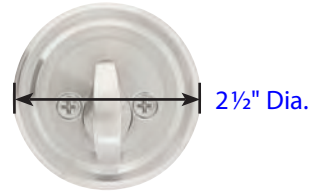

Interior Trim (8450)


- Projection is $1\frac{1}{4}$ "
- Thickness is $\frac{5}{16}$ "

Low Profile Style Deadbolt

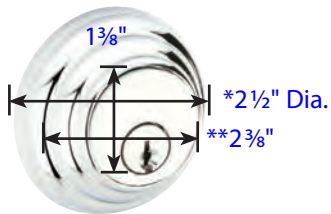

Exterior Trim (8455)

- * $2\frac{1}{2}$ " Diameter with Exterior ring
- ** $2\frac{3}{8}$ " Diameter without Exterior ring
- Projection with Exterior ring: $\frac{7}{8}$ "
- Projection without Exterior ring: $\frac{5}{8}$ "
- 8355 same both sides
- Available Extension Collar for Thin Doors

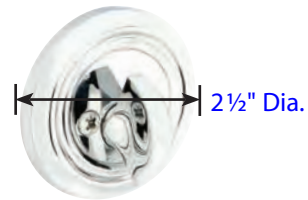

Interior Trim (8455)

- Projection is $1\frac{1}{4}$ "
- Thickness is $\frac{5}{16}$ "

Brass Regular Style Deadbolt, Single Cylinder

Regular Style (8450)

<ul style="list-style-type: none"> • Standard Door Thickness: 1³/₈" - 2¹/₈" Standard Components: • 2¹/₄" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2¹/₈" - 2³/₄" Extended Components: • Long Single Cylinder Tailpiece • 2¹/₂" & 3" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2³/₄" - 3" Extended Components: • Extra Long Single Cylinder Tailpiece • 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
---	---	---

Brass Regular Style Deadbolt, Double Cylinder

Regular Style (8350)

<ul style="list-style-type: none"> • Standard Door Thickness: 1³/₈" - 1³/₄" Standard Components: • Double Cylinder Tailpieces • 2¹/₂" & 3" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 1³/₄" - 2¹/₂" Extended Components: • Long Double Cylinder Tailpieces • 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
--	---

Brass Low Profile & Rope Style Deadbolt, Single Cylinder

Low Profile (8455)* & Rope Style (8464)

<ul style="list-style-type: none"> • Standard Door Thickness: 1¹/₄" - 2¹/₄" Standard Components: • Single Cylinder Tailpiece • 2¹/₄" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2¹/₄" - 2³/₄" Extended Components: • Long Single Cylinder Tailpiece • 3" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2³/₄" - 3" Extended Components: • Extra Long Single Cylinder Tailpiece • 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
--	---	---


* Part # DB4-COLRG2 Available for 1³/₈" Thick Doors

Brass Low Profile & Rope Style Deadbolt, Double Cylinder

Low Profile (8355) & Rope Style (8364)

<ul style="list-style-type: none"> • Standard Door Thickness: 1¹/₄" - 2¹/₈" Standard Components: • Double Cylinder Tailpieces • 2¹/₂" & 3" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2¹/₈" - 2⁷/₈" Extended Components: • Long Double Cylinder Tailpieces • 3" & 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
--	--

Bronze Regular Style Deadbolt

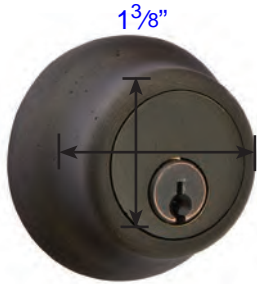

2³/₈" Dia.


- Exterior Trim (8450)
- Projection is 1"
 - 8350 same on both sides




2¹/₂" Dia.

- Interior Trim (8450)
- Projection is 1¹/₄"
 - Thickness is 5/16"

#1 Style Plate with Flap Deadbolt

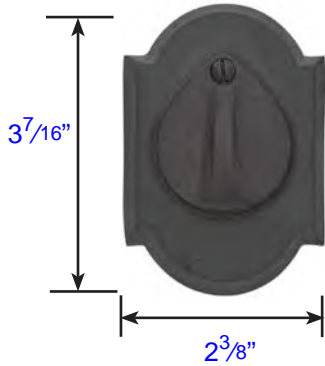


- Exterior Trim (8457)
- Projection is 1³/₁₆"
 - 8357 same on both sides

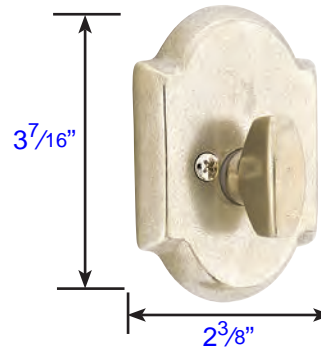


- Interior Trim (8457)
- Projection is 1¹/₄"
 - Thickness is 1/2"

#3 Style Plate with Flap Deadbolt

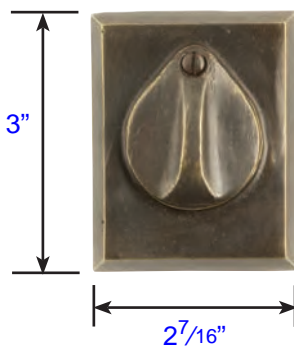

- Exterior Trim (8465)
- Projection is 1¹/₁₆"
 - 8365 same on both sides

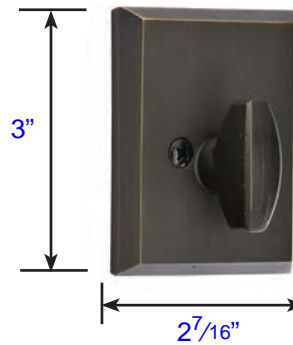

- Interior Trim (8465)
- Projection is 1¹/₄"
 - Thickness is 1/2"

Bronze Regular Style Deadbolt, Single Cylinder

Regular (8450)*

<ul style="list-style-type: none"> • Standard Door Thickness: 1³/₄"- 2³/₄" Standard Components: • Single Cylinder Tailpiece • 2¹/₄" & 2¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2"- 2¹/₂" Extended Components: • Long Single Cylinder Tailpiece • 3" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2¹/₂"- 3" Extended Components: • Extra Long Single Cylinder Tailpiece • 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
---	---	--

**No Extension Collars Available for this Model*

Bronze Regular Style Deadbolt, Double Cylinder

Regular (8350)*

<ul style="list-style-type: none"> • Standard Door Thickness: 1³/₄"- 2" Standard Components: • Long Double Cylinder Tailpieces • 3" & 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate

**No Extension Collars Available for this Model*

Bronze Decorative Deadbolts, Single Cylinder

#1 (8457), #3 (8465), #4 (8474), Ridgemont (8476)

<ul style="list-style-type: none"> • Standard Door Thickness: 1³/₄"- 2¹/₈" Standard Components: • Single Cylinder Tailpiece • 2¹/₂" & 3" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 2¹/₈"- 3" Extended Components: • Long Single Cylinder Tailpiece • 3" & 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
--	---

Bronze Decorative Deadbolts, Double Cylinder

#1 (8357) , #3 (8365), #4 (8374), Ridgemont (8376)

<ul style="list-style-type: none"> • Standard Door Thickness: 1³/₄"- 2³/₈" Standard Components: • Double Cylinder Tailpieces • 2¹/₄" & 2¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate 	<ul style="list-style-type: none"> • Extended Door Thickness: 1⁷/₈"- 2⁵/₈" Extended Components: • Long Double Cylinder Tailpieces • 3" & 3¹/₂" Deadbolt Mounting Screws • Deadbolt Strike Plate
--	---

Bronze *Single-Sided* Deadbolts

Regular Style (8450)

- Standard Door Thickness: 1³/₈" - 2³/₈"
- Standard Components:
 - Single Cylinder Tailpiece
 - 1³/₄" Deadbolt Mounting Screws
 - Deadbolt Strike Plate

- **Extended** Door Thickness: 2³/₈" - 2³/₄"
- Extended Components:
 - Long Single Cylinder Tailpiece
 - 2¹/₄" Deadbolt Mounting Screws
 - Deadbolt Strike Plate

- **Extended** Door Thickness: 2⁷/₈" - 3³/₈"
- Extended Components:
 - Extra Long Single Cylinder Tailpiece
 - 2¹/₂" & 3" Deadbolt Mounting Screws
 - Deadbolt Strike Plate

Bronze *Single-Sided* Deadbolts with Flaps

#1 (8457), #3 (8465), #4 (8474), Ridgmont (8476)

- Standard Door Thickness: 1³/₄" - 2³/₈"
- Standard Components:
 - Single Cylinder Tailpiece
 - 1³/₄" Deadbolt Mounting Screws
 - Deadbolt Strike Plate

- **Extended** Door Thickness: 2³/₈" - 2³/₄"
- Extended Components:
 - Long Single Cylinder Tailpiece
 - 2¹/₄" Deadbolt Mounting Screws
 - Deadbolt Strike Plate

- **Extended** Door Thickness: 2⁷/₈" - 3³/₈"
- Extended Components:
 - Extra Long Single Cylinder Tailpiece
 - 2¹/₂" & 3" Deadbolt Mounting Screws
 - Deadbolt Strike Plate

Deadbolt Strike Plates

