



#### Features: V-66 Professional Multiroom Distributed Audio System

- Distribute 6 stereo audio signals to 6 rooms simultaneously
- Any source to any room simultaneously
- Cascade-able for larger systems up to 18 zones
- Complete Infrared control and discrete source matrix control
- Bi-directional RS232 control of all functions
- Easy integration with master control systems
- Six stereo analog audio inputs
- One digital SPDIF optical audio input
- Six stereo pre-amp outputs
- Six discrete Infrared output ports / one master Infrared output port
- Seven 12V trigger outputs
- Master mute 12V trigger input
- Switchable AGC automatic source gain control leveler
- All zones (play source one) 12V trigger input (party mode or paging)
- 50 watts RMS output power per speaker @ 4ohms
- 100 watts RMS bridge mode

#### Kit includes:

- 1 x V-66 master controller amplifier
- 6 x LED keypads
- 1 x Keypad hub
- 1 x Master IR remote control
- 1 x Expansion cable
- 1 x 2U Rack mounting kit
- 3 Year Warranty




Master IR Remote Included

Expansion cable & keypad hub included





The V-66 LED keypad..... *Elegant Simplicity*

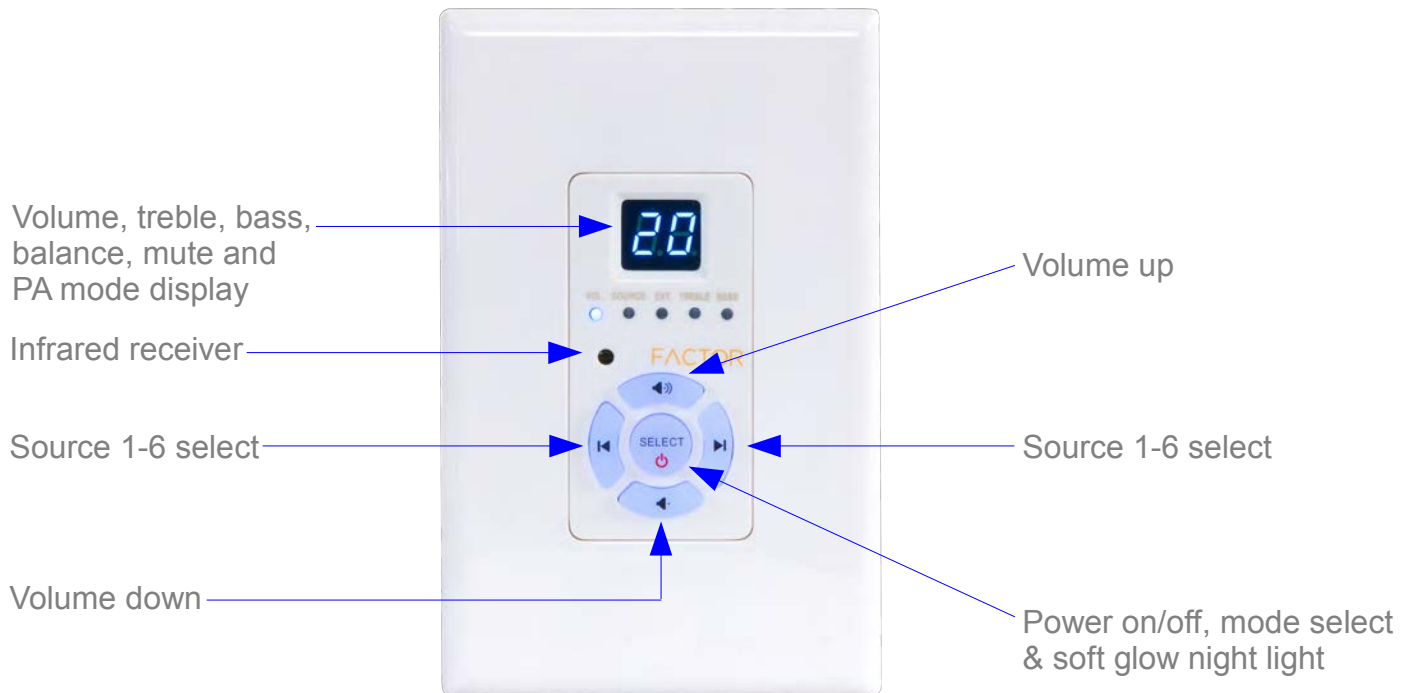

### Specifications:

RMS Power @ 8ohms 25 watts x 12  
 RMS Power @ 4ohms 50 watts x 12  
 RMS Power @ 8ohms 100 watts x 6 (bridge mode)  
 S/N Ratio >85dB A Weighted  
 THD <0.1%  
 Frequency Response 20Hz-20kHz  
 Input Impedance >47Kohms  
 Input Sensitivity 250mv  
 Amplifier Protection Overload, short circuit & thermal  
 Trigger System on DC + 12V  
 Trigger External Mute DC + 12V  
 Infrared Frequency 38kHz

Input Connectors 3.5mm stereo, RCA  
 stereo, Digital SPDIF Optical  
 Output Connectors Terminal Block,  
 3.5mm mono  
 Power Supply AC115V/60Hz or  
 230V/50Hz switchable

### Power Consumption

1250 watts

### Dimensions:

W- 19"/482.6mm w/rack kit  
 W- 17"/430mm no/rack kit  
 H - 3.5"/89mm  
 D - 16.4"/416mm

**Shipping Weight 25lbs (11kg)**