

Features:


- RJ45 Cat5/6 breakout board
- Converts the V-RVC-PRO Cat5/6 output to balanced line level
- Allows the V-RVC-PRO to be used with any amplifier, mixer or pre-amp
- Mounts anywhere with screws or double sided tape pad
- Can be used to break out any RJ45 Cat5/6 device
- Sturdy Fiberglas construction
- Includes 1A 24VDC power supply
- Includes 1 x RJ45 crimp-on connector
- Includes 2 x mounting screws
- Includes double sided tape pad
- Three year warranty!

Specifications:

- Fiberglas circuit board
- One RJ45 in/out jack
- DC In jack +/- (push connector)
- DC in jack +/- (screw terminal)
- Balanced audio out + / - / G
- Vox Sense
- RVC +/- (remote volume control)

Dimensions:

- Width – 1.25" / 34mm
- Length – 2.5" / 60mm
- Height – 0.75" / 18mm
- Weight – 0.2lb / 0.09kg

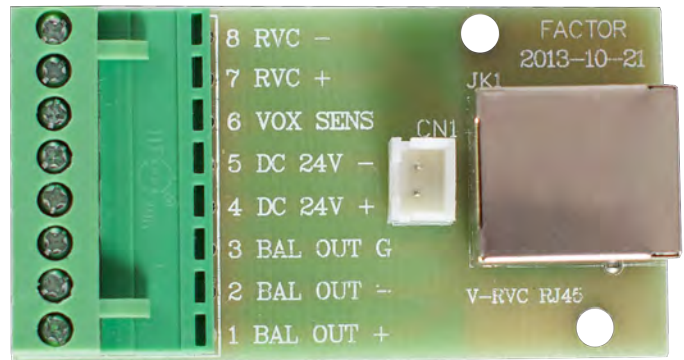

Includes 1 x RJ45 jack 2 mounting screws & 1A power supply



One two or three V-RVC-PRO units can be daisy chained to one V-RVC-RJ45 breakout

