

ED2300 Series Exit Devices


APPLICATIONS:

For use on a single door or double doors with or without mullion. Vertical rod (V) for use where two-point latching is desired. For 1-3/4" (44 mm) thick standard RHR or LHR hollow metal doors, and wood doors. Minimum stile width: 3-7/8" (98 mm) for rim device and 3-1/2" (89mm) for vertical rod. All devices and accessories are to be used on a 1-3/4" standard door.



The **ED2300R** is ideally suited for:

- Single exterior doors
- Single exit doors
- Pairs of Doors with Mullion
- Aluminum entrance doors
- Passage doors

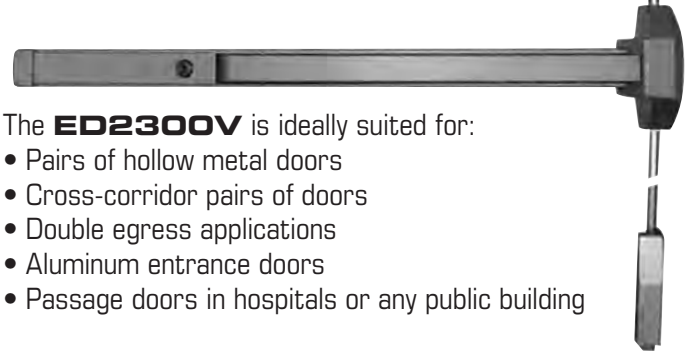

The **ED2300V** is ideally suited for:

- Pairs of hollow metal doors
- Cross-corridor pairs of doors
- Double egress applications
- Aluminum entrance doors
- Passage doors in hospitals or any public building

STANDARD FEATURES:

CERTIFICATIONS: ANSI A156.3 Grade 1, UL Listed (ED2300R-P), UL Listed 3-hour (ED2300R-F)



SIZES: 36" and 48"

HANDING: Non-handed

STRIKES: Panic rim device furnished with roller strike & strike shim. Fire rim device furnished with roller strike only. Vertical rod device furnished with top and bottom strikes.

LATCHBOLT: 11/16" throw and 5/8" dead locking latch for Panic Rim and Fire Rim device. 1/2" throw top and bottom bolt for Vertical Rod Device.

DOGGING: 3/16" hex key dogging. No dogging on fire-rated devices.

CYLINDER: Rim cylinder sold separately.

TRIM: Trim sold separately

MATERIALS: Housing, end cap, and push bar all steel. Chassis is plated steel. Head cover is a non-ferrous alloy.

MOUNTING HARDWARE: Machine screws, sex nuts and bolts

GENERAL LOCK

Quality & Value™

— Product Guide 105.0 — E:1

Exit Devices

How to Order - Nomenclature

ED 2300 R-F 689 36

LENGTH

36" = For 36" (2300 Series only)
48" = For 48" (2300 Series only)

FINISH

313 = Dark Bronze (1000 Series only)
628 = Satin Aluminum (1000 Series only)
689 = Sprayed Aluminum (2300 Series only)
695 = Sprayed Duronodic (2300 Series only)

EXIT USE / HANDING

P = Panic (2300 Series only)
F = Fire (2300 Series only)
LHR = Left Hand - Reverse Bevel (1000 Series Rim only)
RHR = Right Hand - Reverse Bevel (1000 Series Rim only)

MOUNTING APPLICATION

R = Rim
V = Vertical Rod (2300 Series only)
CV = Concealed Vertical Rod (1000 Series only)

STYLE

1048 = 1000 Series
2300 = 2300 Series

TYPE

ED = Exit Device

Note: Not all exit device types are available in all lengths and finishes.