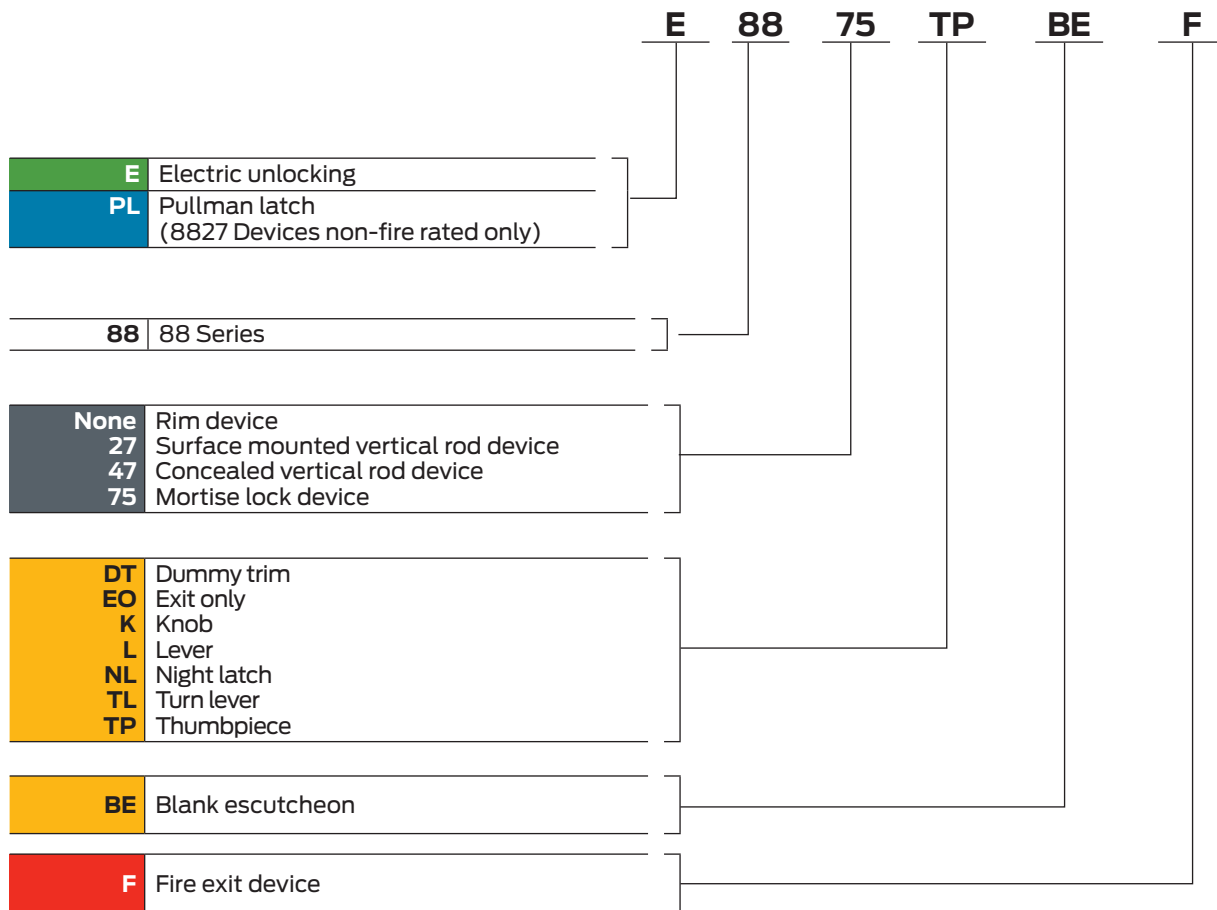


How to order



Rim and mortise lock devices, specify:

 
 
 
 
 
 
 
 
- Exit device model number with trim selection. Examples: 88EO (Exit only with no outside trim). 88TP (Includes standard 880TP thumbpiece trim). 88TP x 608TP (Includes the optional 608TP thumbpiece trim).
- Door width if greater than 4' (1219 mm).
- Door thickness if other than 1 3/4" (44 mm).
- Door and frame material if other than hollow metal.
- Finish
- Handing required on "L" function, "F" fire devices. Specify LHR or RHR. See diagram below.
- "SNB" when using sex nuts and bolts.

Vertical rod devices, specify:

- Exit device number with trim selection. Examples: 8827EO (Exit only, no outside trim). 8827TP (Includes 880TP thumbpiece trim). 8827TP x 608 TP (Includes the optional 608TP thumbpiece trim).
- Door width of greater than 4' (1219 mm).
- Door thickness if other than 1 3/4" (44 mm).
- Door and frame material if other than hollow metal.
- Door height if greater than 7' (2134 mm), extension rods must be ordered. (One piece top rod available)
- Finish
- Handing, LHR or RHR, required on "L" function. Specify LHR or RHR. See diagram below.
- "SNB" when using sex nuts and bolts..

Pullman latches are optional for 8827 devices. Latchbolts remain extended at all times. Specify "Pullman Latch" when required. (Normally used with an electric strike and less bottom rod)

Trim options

Function		01 Exit only	02 Pull when dogged	03 Key retracts latch bolt	05 Key retracts thumbpiece	06 Key locks lever	08 Key locks knob	08 Key locks lever	11/12 Key locks thumbturn
Trim number and dimensions		880EO 	880DT 	880NL 	880TP 	371-L 	880K 	373-L 	377T or 376T x 880DT-V 
Device/trim center line to finished floor									
Projection		—	2" (51 mm)	2" (51 mm)	2" (51 mm)	2 ⁵ / ₈ " (67 mm)	2 ³ / ₄ " (70 mm)	2 ⁵ / ₈ " (67 mm)	1 ¹³ / ₁₆ " (46 mm)
Rim	Panic	880EO	88DT	88NL	88TP	—	88K	88L	—
	Fire	88EO-F	—	88NL-F▲	88TP-F▲	—	88K-F▲	88L-F■	—
	Ctr. line	A 39 ¹³ / ₁₆ (1011 mm) —	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹¹ / ₃₂ (847mm)	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹¹ / ₃₂ (847mm)	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹¹ / ₃₂ (847mm)	—	A 39 ¹³ / ₁₆ (1011 mm) B 36 ¹³ / ₁₆ (935 mm)	A 39 ¹³ / ₁₆ (1011 mm) B 36 ¹³ / ₁₆ (935 mm)	—
Mortise lock	Panic	8875EO	8875DT	8875NL	8875TP	—	8875K	8875L	—
	Fire	8875EO-F	—	8875NL-F	8875TP-F	—	8875K-F	8875L-F	—
	Ctr. line	A 39 ¹³ / ₁₆ (1011 mm) —	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹ / ₂ (851 mm)	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹ / ₂ (851 mm)	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹ / ₂ (851 mm)	—	A 39 ¹³ / ₁₆ (1011 mm) B 38 ⁹ / ₁₆ (979 mm)	A 39 ¹³ / ₁₆ (1011 mm) B 38 ⁹ / ₁₆ (979 mm)	—
Surface mounted vertical rod	Panic	8827EO	8827DT	—	8827TP	—	8827K	8827L	8827TL
	Fire	8827EO-F	—	—	8827TP-F	—	8827K-F	8827L-F	8827TL-F
	Ctr. line	A 39 ¹³ / ₁₆ (1011 mm) —	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹ / ₂ (851 mm)	—	A 39 ¹³ / ₁₆ (1011 mm) B 33 ¹ / ₂ (851 mm)	—	A 39 ¹³ / ₁₆ (1011 mm) B 38 ⁵ / ₁₆ (973 mm)	A 39 ¹³ / ₁₆ (1011 mm) B 38 ⁵ / ₁₆ (973 mm)	A 39 ¹³ / ₁₆ (1011 mm) B 53 ¹ / ₂ (1359 mm)
Concealed vertical rod	Fire	8847EO-F	—	—	—	8847L-F	—	—	8847TL-F
	Ctr. line	A 39 ¹³ / ₁₆ (1011 mm) —	—	—	—	A 39 ¹³ / ₁₆ (1011 mm) B 41 ¹¹ / ₁₆ (1059 mm)	—	—	A 39 ¹³ / ₁₆ (1011 mm) B 53 ¹ / ₂ (1359 mm)
Additional snb requirements		4/8/16	4, 12	4	4, 12	4	4, 12	4, 12	4
Cylinder type required	Rim	—	—	Rim	Rim	—	Rim	Mortise	—
	Mortise	—	—	Mortise	Mortise	—	Mortise	Mortise	—
	Vert. rod	—	—	—	Rim	—	Rim	Mortise	Mortise
	C.V.R.	—	—	—	—	Mortise	—	—	Mortise

▲ Requires stainless steel trim for wood or composite fire doors.

■ Requires 889 Plate for wood or composite fire doors.

Note: 8827-F uses 377T, 8847-F uses 376T.

Trim options

Standard trim

880DT 3" x 14 ³ / ₁₆ " 	880K 3" x 14 ³ / ₁₆ " 	880NL 3" x 14 ³ / ₁₆ " 	880TP 3" x 14 ³ / ₁₆ " 	880EO 3" x 14 ³ / ₁₆ " 	377T 1 ¹¹ / ₁₆ " x 7 ¹ / ₂ " 	373L 1 ¹¹ / ₁₆ " x 7 ¹ / ₂ " 
---	--	---	---	--	---	---

880 Series trim
Heavy 10 gauge (2.4 mm) brass, bronze, or stainless steel.
Available functions: 880DT, 880K, 880NL, and 880TP. Optional 880EO exit only trim plate is available. To order with the exit device, specify 88EOx880EO.

*880 Stainless Steel Trim used with fire rated rim device on wood doors.

373L/371L Series trim
Lever control has a forged brass ⁷/₈" (22 mm) thick escutcheon.
An NL cylinder plate is included for lever operation only when key is used. BE blank escutcheon is available, specify 373L-BE.

377T Series trim
Thumbturn control has a forged brass ⁷/₈" (22 mm) thick escutcheon. Often used with DT trim or pull. An NL cylinder plate is included for thumbturn operation only when key is used. BE blank escutcheon is available, specify 377T-BE

Optional trim

608DT 	608NL 	608TP 	606K 
---	---	---	--

608 Series trim
Narrow design ³/₁₆" (5 mm) thick brass, bronze, or stainless steel with flat pull grip. Available functions: 608DT, 608NL, and 608TP. When ordering with the exit device, specify 88NLx608NL.

606K Series trim
Narrow design knob trim ³/₁₆" (5 mm) thick brass, bronze, or stainless steel ³/₁₆" (5 mm) escutcheon.