


How to order

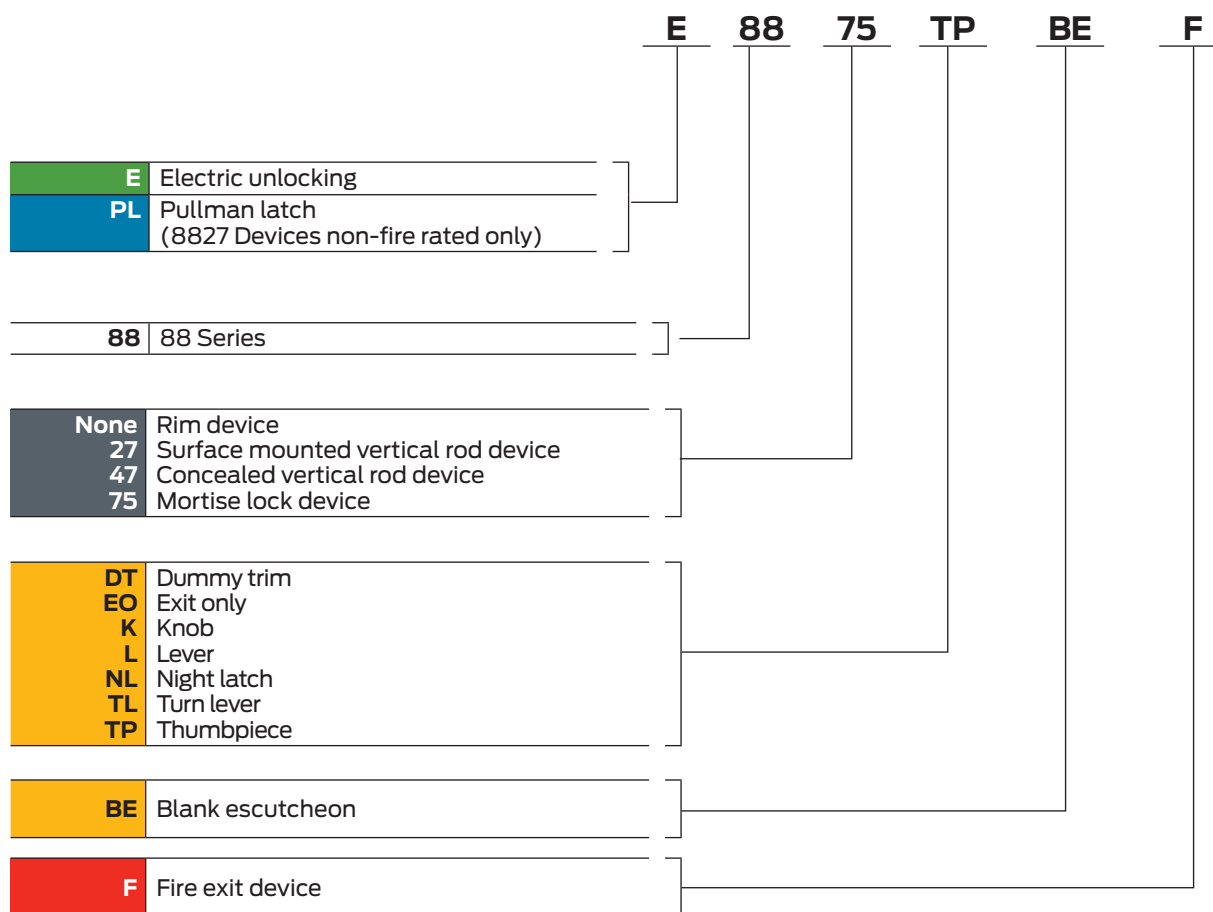

Rim and mortise lock devices, specify:

- Exit device model number with trim selection. Examples: 88EO (Exit only with no outside trim). 88TP (Includes standard 880TP thumbpiece trim). 88TP x 608TP (Includes the optional 608TP thumbpiece trim).
- Door width if greater than 4' (1219 mm).
- Door thickness if other than 1 3/4" (44 mm).
- Door and frame material if other than hollow metal.
- Finish
- Handing required on "L" function, "F" fire devices. Specify LHR or RHR. See diagram below.
- "SNB" when using sex nuts and bolts.

Vertical rod devices, specify:

- Exit device number with trim selection. Examples: 8827EO (Exit only, no outside trim). 8827TP (Includes 880TP thumbpiece trim). 8827TP x 608 TP (Includes the optional 608TP thumbpiece trim).
- Door width of greater than 4' (1219 mm).
- Door thickness if other than 1 3/4" (44 mm).
- Door and frame material if other than hollow metal.
- Door height if greater than 7' (2134 mm), extension rods must be ordered. (One piece top rod available)
- Finish
- Handing, LHR or RHR, required on "L" function. Specify LHR or RHR. See diagram below.
- "SNB" when using sex nuts and bolts..

Pullman latches are optional for 8827 devices. Latchbolts remain extended at all times. Specify "Pullman Latch" when required. (Normally used with an electric strike and less bottom rod)

88 Rim exit device



88 rim devices for all types of single and double doors with mullion, UL listed for accident hazard installations. Covers stock hollow metal doors with 86 or 161* cutouts. This device is field reversible.

Finishes – US26, US26D, US3, US4, US10B, US10, SPBLK



The 299 Strike
ships standard, optional
strikes available

Hex key dogging comes
standard on 88 Rim exit
devices



Specifications

Device functions	Device ships EO, DT, NL, TP, L, K	
Handing	Field reversible	
Crossbar length	42" (1067 mm) field sizeable	
Device centerline	39 ¹³ / ₁₆ "	
Crossbar centerline to finished floor	36 ¹³ / ₁₆ " (935 mm) at center	
Lock stile case	8 ¹ / ₄ " X 2 ³ / ₄ " X ¹⁵ / ₁₆ " (210 mm x 70 mm x 24 mm)	
Hinge stile case	6" X 1 ³ / ₄ " X ¹⁵ / ₁₆ " (152 mm x 44 mm x 24 mm)	
Crossbar tubing	1" (25 mm) outside diameter	
Projection	Neutral – 4 ³ / ₄ " (121 mm) Depressed – 4" (102 mm)	
Latch bolt	³ / ₄ " (19 mm), throw	
Fasteners	All necessary mounting fasteners are included.	
Electrical options	RX	Crossbar monitor switch in end case
	E	Electric unlocking (BE trim only)
Mechanical options	RCB	Reinforced crossbar
	KN	Knurled crossbar
Strikes	299 - Dull black	

* Not applicable with all strike and mullion combinations, consult factory.

RX

Crossbar monitor switch

- Signals use of an opening
- SPDT switch to monitor crossbar

Standard trims

	EO	NL 	TP 	DT 	K 	L 
	Exit only	Night latch Key retracts latchbolt	Key locks thumbpiece	Dummy trim Pull when dogged	Key locks knob	Key locks lever #06 Standard
Product description	88EO	88NL	88TP	88DT	88K ^{1,2,3}	88L ^{1,2,4,5,6,7}
Trim description	—	880NL-R	880TP-R	880DT-R	880K-R	373L
Escutcheon plate size	—	3" x 14 ³ / ₁₆ " x ³ / ₃₂ "	3" x 14 ³ / ₁₆ " x ³ / ₃₂ "	3" x 14 ³ / ₁₆ " x ³ / ₃₂ "	3" x 14 ³ / ₁₆ " x ³ / ₃₂ "	3" x 14 ³ / ₁₆ " x ³ / ₃₂ "
Grip mounting center	—	5 ¹ / ₂ "	5 ¹ / ₂ "	5 ¹ / ₂ "	—	6 ¹ / ₄ "
Projection	—	2"	2"	2"	2 ³ / ₄ "	2 ⁵ / ₈ "
ANSI function	01	03	05	02	08	08/09
Cylinder type	—	Rim	Rim	—	Rim	1 ¹ / ₄ " Mortise
Sex bolt quantity #425 (optional)	8	4	4	4	4	4

Optional trims

	NL 	TP 	DT 	K 	EO 
	Night latch Key retracts latchbolt	Key locks thumbpiece	Dummy trim Pull when dogged	Key locks knob	Exit only
Product description	88NL x 608NL	88TP x 608TP	88DT x 608DT	88K x 606K ^{1,2,3,5}	88L x 880EO
Trim description	608NL-R	608TP-R	608DT-R	606K-R	880EO-R
Escutcheon plate size	1 ⁵ / ₈ " x 13 ¹ / ₂ " x ³ / ₁₆ "	1 ⁵ / ₈ " x 13 ¹ / ₂ " x ³ / ₁₆ "	1 ⁵ / ₈ " x 13 ¹ / ₂ " x ³ / ₁₆ "	1 ⁵ / ₈ " x 8 ³ / ₄ " x ³ / ₁₆ "	3" x 14 ³ / ₁₆ " x ³ / ₃₂ "
Grip mounting center	5 ¹ / ₂ "	5 ¹ / ₂ "	5 ¹ / ₂ "	—	—
Projection	2 ¹ / ₆ "	2 ¹ / ₆ "	2 ¹ / ₆ "	2 ³ / ₄ "	—
ANSI function	03	05	02	08	01
Cylinder type	Rim	Rim	—	Rim	—
Sex bolt quantity #425 (optional)	NR	NR	NR	NR	4

¹ If no cylinder operation is required, specify "BE" blank escutcheon, trim always operable; example 88TP-BE.

² Matching dummy trim available, use suffix "DT"; example 88K-DT.

³ Night latch function available, order 88NL x 880K-R rigid.

⁴ When using sex bolts, an 889 cover plate is required. See page 24.

⁵ When using on wood doors without sex bolts, "WDA" cover plate is required. See page 24.

⁶ Not available with E88.

⁷ The 373L is shipped L. An NL cylinder plate is also furnished standard (for operation only when key is used).

NR-Not recommended

Notes