


190S

Door Protection Plate
0.050" gauge with no bevel

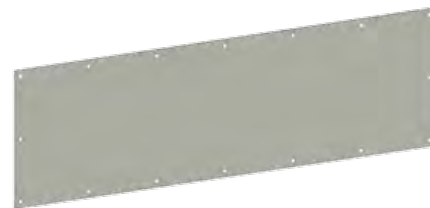

NFPA Notes:

- NFPA 80 Standards
- 6.4.5 Protection Plates 6.4.5.1
- Factory installed protection plates shall be installed in accordance with the listing of the door. 6.4.5.2
- Field installed protection plates shall be labeled and installed in accordance with their listing. 6.4.5.3
- Labeling shall not be required where the top of the protection plate is not more than 16" (406mm) above the bottom of the door.



PRODUCT SPECIFICATIONS

GAUGE:

- 0.050" (1 mm)

MATERIALS:

- Aluminum, Brass, Bronze, Stainless Steel

FINISHES:

- US3, US4, US10, US10B, US28, US32, US32D

BEVEL:

- None

ORDER:

- Furnish item #, height, width, and finish (i.e., 190S – 6" x 30", US32D).
- Plates are sized on even inches. Odd size available and priced to next larger size.
- May be ordered with counter sunk holes (specify "CSK") at extra charge.

OPTIONS:

- UL listed for US32 and US32D with screw fasteners (must specify UL stamp)
- Self-adhesive tape available on all plates
- Spanner head screws
- Torx head screws
- Round corners
- Wrap around side and bottom return
- 0.125" material

CERTIFICATION:

- Meets ANSI A156.6 for J101 Metal Armor Plate, J102 Metal Kickplate, and J103 Metal Mop Plate

PRODUCT SIZE OPTIONS

ITEM #	B&S GAUGE	US GAUGE	BEVEL	FASTENERS	QUANTITY BAG	QUANTITY CASE
190S	16	18	none	#6 x 5/8 truss head screws	1 each	---
194S	16	18	B4E	#6 x 5/8 truss head screws	1 each	---
196R	16	18	none	#6 x 5/8 truss head screws	1 each	---
198S	---	20	none	#6 x 5/8 truss head screws	1 each	---
199B	---	38	none	#6 x 5/8 truss head screws	1 each	---
220S	14	16	none	#6 x 5/8 truss head screws	1 each	---
223S	14	16	B3E	#6 x 5/8 truss head screws	1 each	---
224S	14	16	B4E	#6 x 5/8 truss head screws	1 each	---