


DS-7104NI-SL/W


Embedded Mini WiFi NVR

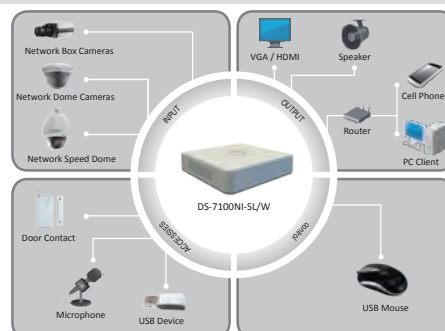

Key features

- Third-party network cameras supported
- Up to 5 Megapixels resolution recording
- HDMI and VGA output at up to 1920×1080P resolution
- HDD quota and group management
- Built-in WiFi modular to support wireless AP function, support automatic detection and connection of IP cameras from Hikvision without any operations

Rear Panel of DS-7104NI-SL/W

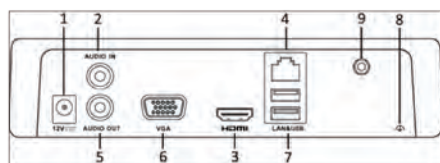

1. Power Supply
2. Audio In
3. HDMI Interface
4. LAN Network Interface
5. Audio Out
6. VGA Interface
7. USB Interface
8. Ground
9. Antenna Interface

DS-7104NI-SL/W	
Video/Audio input	
Video input	4-ch
Two-way audio input	1-ch, RCA (2.0 Vp-p, 1kΩ)
Network	
Incoming bandwidth	25Mbps
Outgoing bandwidth	40Mbps
Remote connection	128
Video/Audio output	
Recording resolution	5MP/3MP/1080p/UXGA/720p/VGA/4CIF/DCIF/2CIF/CIF/QCIF
HDMI/VGA output	1-ch, resolution: 1920 × 1080P /60Hz, 1600 × 1200 /60Hz, 1280 × 1024 /60Hz, 1280 × 720 /60Hz, 1024 × 768 /60Hz
Audio output	1-ch, RCA (Linear, 1kΩ)
Playback resolution	5MP /3MP /1080P /UXGA /720P /VGA /4CIF /DCIF /2CIF /CIF /QCIF
Synchronous playback	4-ch @720P, 2-ch @1080P, 1-ch @5MP
Hard disk	
SATA	1 SATA interface for 1 HDD
Capacity	Up to 4TB for each disk
External interface	
Network interface	1 RJ-45 10 /100 Mbps self-adaptive Ethernet interface
Antenna Interface	1, with wireless AP function
USB interface	2 × USB 2.0
Others	
Power supply	12V DC
Consumption	≤ 15 W (without hard disk)
Working temperature	-10 °C ~ +55 °C (+14 °F ~ +131 °F)
Working humidity	10 % ~ 90 %
Chassis	1U chassis
Dimensions(W × D × H)	200 × 200 × 45 mm
Weight	≤ 1 Kg (without hard disk)