

DS-7700NI-K4/P Series NVR



Features and Functions

Professional and Reliable

- Dual-OS design to ensure high reliability of system running
- ANR technology to enhance the storage reliability when the network is disconnected

HD Input

- H.265/H.264/MPEG4 video formats
- Connectable to the third-party network cameras
- Up to 32 IP cameras can be connected
- Recording at up to 8 MP resolution
- Supports live view, storage, and playback of the connected camera at up to 8 MP resolution

HD Output

- HDMI and VGA independent outputs provided
- HDMI Video output at up to 4K (3840 × 2160) resolution

HD Storage

- Up to 4 SATA interfaces connectable for recording and backup
- Storage space effectively saved by 50% to 70% with the use of H.264+ decoding format

HD Transmission

- 1 self-adaptive 10M/100M/1000M network interface
- 16 independent PoE network interfaces are provided

Various Applications


- Centralized management of IP cameras, including configuration, information import/export, real-time information display, two-way audio, upgrade, etc.
- Connectable to smart IP cameras from Hikvision and the recording, playing back, and backing up of VCA alarms can be realized
- VCA detection alarm is supported
- Instant playback for assigned channel during multi-channel display mode
- Smart search for the selected area in the video; and smart playback to improve the playback efficiency
- Supports HDD quota and group modes; different capacity can be assigned to different channels



Specifications

Model		DS-7716NI-K4/16P	DS-7732NI-K4/16P
Video/ Audio input	IP video input	16-ch	32-ch
	Incoming bandwidth	160 Mbps	256 Mbps
	Outgoing bandwidth	160 Mbps	
Video/ Audio output	HDMI output resolution	4K (3840 × 2160)/30Hz, 2K (2560 × 1440)/60Hz, 1920 × 1080/60Hz, 1600 × 1200/60Hz, 1280 × 1024/60Hz, 1280 × 720/60Hz, 1024 × 768/60Hz	
	VGA output resolution	1920 × 1080/60Hz, 1280 × 1024/60Hz, 1280 × 720/60Hz, 1024 × 768/60Hz	
	Audio output	1-ch, RCA (Linear, 1 KΩ)	
Decoding	Decoding format	H.265/H.264/MPEG4	
	Recording resolution	8MP/6MP/5MP/4MP/3MP/1080p/UXGA/720p/VGA/4CIF/DCIF/2CIF/CIF/QCIF	
	Synchronous playback	16-ch	16-ch
Hard disk	Capability	2-ch @ 4K, or 8-ch @ 1080p	
	SATA	4 SATA interfaces for 4HDDs	
	Capacity	500GB/1TB/2TB/3TB/4TB/5TB/6TB	
External interface	Two-way audio	1-ch, RCA (2.0 Vp-p, 1kΩ)	
	Network interface	1 RJ-45 10/100/1000 Mbps self-adaptive Ethernet interface	
	Serial interface	1 RS-485 (half-duplex), 1 RS-232, 1 keyboard (optional)	
POE Interface	USB interface	Front panel: 2 × USB 2.0; Rear panel: 1 × USB 3.0	
	Alarm in/out	16/4	
	Interface	16 RJ-45 10/100 Mbps self-adaptive Ethernet interfaces	
General	Power	≤ 200 W	
	Supported standard	IEEE 802.3 af/at	
	Power supply	100 to 240 VAC	
	Power	≤ 300 W	
	Consumption (without hard disk)	≤ 20 W (without enabling PoE)	
	Working temperature	-10 to +55°C (14 to 131°F)	
	Working humidity	10 to 90 %	
	Chassis	19-inch rack-mounted 1.5U chassis	
	Dimensions (W × D × H)	445 × 390 × 70 mm (17.5"× 15.3" × 2.8")	
	Weight (without hard disk)	≤ 5 kg (11 lb)	

Physical Interfaces

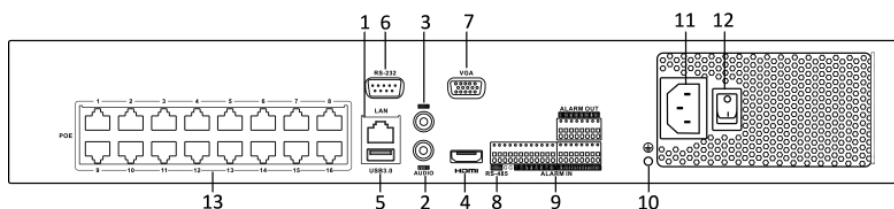


The DS-7708NI-K4/8P provides 8 network Interfaces with PoE function.

Index	Description	Index	Description
1	LAN Network Interfaces	8	RS-485 Serial Interface
2	AUDIO OUT	9	ALARM IN and ALARM OUT
3	AUDIO IN	10	GND
4	HDMI Interface	11	100 to 240 VAC Power Input
5	USB 3.0 Interface	12	Power Switch
6	RS-232 Serial Interface	13	Network Interfaces with PoE function
7	VGA Interface		

Available Models

DS-7716NI-K4/16P, DS-7732NI-K4/16P.

 Distributed by



Headquarters

No.555 Qianmo Road, Binjiang District,
Hangzhou 310051, China
T +86-571-8807-5998
overseasbusiness@hikvision.com

Hikvision Poland

T +48-22-460-01-50
poland@hikvision.com

Hikvision USA

T +1-908-895-0400
sales.usa@hikvision.com

Hikvision India

T +91-22-28469900
sales@pramahikvision.com

Hikvision UK

T +44-1628-9021-4
support.uk@hikvision.com

Hikvision Europe

T +31-23-5542770
saleseuro@hikvision.com

Hikvision Italy

T +39-0438-6902
info.it@hikvision.com

Hikvision Singapore

T +65-6684-4718
sg@hikvision.com

Hikvision Middle East

T +971-4-8816086
salesme@hikvision.com

Hikvision France

T +33(0)1-85-330-444
info.fr@hikvision.com

Hikvision Oceania

T +61-2-8599-4233
salesau@hikvision.com

Hikvision Russia

T +7-495-669-67-99
saleru@hikvision.com

Hikvision Spain

T +34-91-737-16-55
info.es@hikvision.com

Hikvision Hong Kong

T +852-2151-1761