

UTP/STP/Coaxial Cable Strippers

- Adjustable blades can be set for any depth to help ensure nick-free strips



Description	Typical RG Cables	Cat. No.
Coaxial Cable Stripper, up to 1/8 in. (3.2mm) O.D.	RG-174, RG-187	45-162 (Gray)
Coaxial Cable Stripper, 1/8 in. (3.2mm) to 7/32 in. (5.556mm) O.D.	RG-58 Mini Coax	45-163 (Blue)
Coaxial Cable Stripper, 1/4 in. (6.4mm) to 9/16 in. (14.3mm) O.D.	RG-11, RG-8	45-164 (Blue)
Cable Stripper, 3/16 in. (4.8mm) to 5/16 in. (8mm) O.D.	RG-59, UTP Cable	45-165 (Black)
Replacement Blade Set* for 45-162, 45-163, 45-165	—	L-9225
Replacement Blade Set* for 45-164	—	L-9226

*A set of blades consists of three straight blades and one round blade.

Coax Strip and Crimp Tool

- Precision, form-ground stripping holes remove outer jacket and insulation from RG-59 and RG-6 coaxial cable
- Durable blades cut copper-coated steel conductors
- Three crimping nests for crimping F-connectors and ring terminals
- Cushioned, comfort-grip handles



Description	Cat. No.
Coax Strip & Crimp Tool	30-433
Coax Strip & Crimp Tool Kit w/ten RG-6 F-Connectors	30-433F

4-Way Indent Crimp Tools

Crimp solid barrel contacts for RS232 interface connectors. Feature four-way indent dies (per MS22520 specifications), full cycle ratchet, built-in pin and socket locator and comfort-grip handles.




35-465

- High-grade steel construction for outstanding performance

Description	Cat. No.
20-26 AWG (.519 mm ² - .128 mm ²) RS232 D-sub Round Barrel Contacts, Pins or Sockets	35-465
16-22 AWG (1.31 mm ² - .324 mm ²) Round Barrel Contacts, Pins, Sockets and Deutsch 16 Pin Contacts	35-466
Trompeter BNC Connector Center Pins	35-468

Crimpmaster™ Crimp Tool Replacement Die Sets

Dies change quickly and easily with a screwdriver. Interchangeable dies provide versatility in a single tool

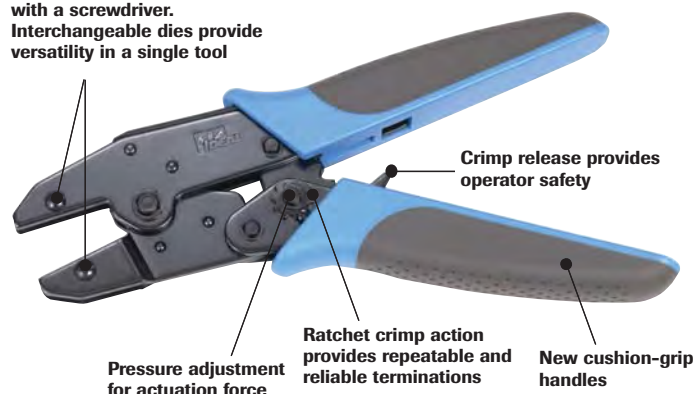

Coaxial Termination

Description	Tool Cat. No.	Replacement Die Set Cat. No.
22-10 AWG (.324mm ² - 5.261mm ²) fully insulated slide-on connectors	—	30-594
Insulated Terminal Crimp Tool with built-in locator	30-479	—
22-12 AWG (.324mm ² - 3.31mm ²) Non-insulated open barrel crimp style connectors	—	30-586
RG-58, 59, 62 Non-plenum Cambridge BNC/TNC connectors	30-481	30-573
RG-8/11, RG-213, RG-216 Ethernet Thickwire, N-Series type plugs and jacks	30-482	30-577
RG-9, Belden® 8281® and RG-6 Cable, 50 & 75 Ohm	30-483	30-578
RG-58 and RG-174 cable for 50 and 75 Ohm cables	—	30-587
RG-174 Mini-59 Hex BNC/TNC coax connector	30-485	30-576
RG-58 and RG-59 Plenum cables, Thinwire PVC Hex	—	30-591
16-26 AWG (1.31mm ² - 1.28mm ²) Miniature insulated rings and splices	—	30-572
22-10 AWG (.324mm ² - 5.261mm ²) Insulated ring tongue terminals and splices	30-500	30-579
22-8 AWG (.3mm ² - 8mm ²) Non-insulated terminals and splices	—	30-580
RG-58 RG-59/62AU BNC/TNC 3-Piece Hex type connectors	30-502	30-581
CATV RG-59 and RG-6 Captive Ring F-connectors	30-503	30-582
RG-6, RG-174, Belden-Type RG-8281 cables	—	30-570
Mini UHF and BNC/TNC 5 cavity	—	30-593
30-18 AWG, Open barrel pins and sockets	—	30-599