

Side-Cutting Pliers

Side-Cutting Pliers

Additional Features:

- Streamlined design



D201-9NE

Cat. No.	Nose Type	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Finish	Handle Color	Weight
Streamlined Design									
D201-7NE	New England	7-7/16" (188.9 mm)	1-9/32" (32.5 mm)	1-1/16" (27.0 mm)	1/2" (12.7 mm)	5/8" (15.9 mm)	Plastic-Dipped	Dark Blue	8.8 oz. (249 g)
D201-8NE	New England	8-11/16" (220.7 mm)	1-7/16" (36.5 mm)	1-3/16" (30.2 mm)	5/8" (15.9 mm)	23/32" (18.3 mm)	Plastic-Dipped	Dark Blue	14.7 oz. (417 g)
D201-9NE	New England	9-3/8" (238.1 mm)	1-19/32" (40.5 mm)	1-5/16" (33.3 mm)	5/8" (15.9 mm)	25/32" (19.8 mm)	Plastic-Dipped	Dark Blue	1.1 lbs. (0.50 kg)
Square Nose									
D201-8	Square	8-11/16" (220.7 mm)	1-7/16" (36.5 mm)	1-7/32" (31.0 mm)	5/8" (15.9 mm)	23/32" (18.3 mm)	Plastic-Dipped	Dark Blue	14.9 oz. (422 g)
D201-9	Square	9-3/8" (238.1 mm)	1-19/32" (40.5 mm)	1-5/16" (33.3 mm)	5/8" (15.9 mm)	25/32" (19.8 mm)	Plastic-Dipped	Dark Blue	1.1 lbs. (0.50 kg)

High-Leverage Universal Combination Pliers

Additional Features:

- Crimping die behind hinge for superior leverage crimping non-insulated connectors, lugs and terminals
- High-leverage design. Rivet is closer to the cutting edge for 46% greater cutting and gripping power than other pliers designs
- Toothed pipe-grip for greater gripping power



12098


Cat. No.	Nose Type	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Finish	Handle Color	Weight
12098	Universal	8-5/8" (219.1 mm)	1-25/32" (45.2 mm)	1-1/32" (26.2 mm)	17/32" (13.5 mm)	3/4" (19.1 mm)	Plastic-Dipped	Dark Blue	11.5 oz. (327 g)
Journeyman™ Series – Dual-material handles									
J12098	Universal	8-3/4" (222.3 mm)	1-25/32" (45.2 mm)	1-1/32" (26.2 mm)	17/32" (13.5 mm)	3/4" (19.1 mm)	Journeyman	Dark Blue/Black	13.1 oz. (371 g)

Refer to the insulated section for insulated pliers.

Ironworker's Work Pliers

Additional Features:

- Twists and cuts soft annealed rebar tie wire
- Cat. Nos. 213-9ST, D213-9ST and D20009ST feature high-leverage design. Rivet is closer to the cutting edge for 46% greater cutting and gripping power than other pliers designs
- Hook bend handle
- Spring-loaded action for self-opening
- Cat. Nos. 213-9ST, D213-9ST and D2000-9ST feature heavy-duty knurled jaws
- D201-7CSTT and D213-9STT has split tether ring for use with tether device

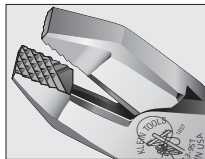

D201-7CST

NEW!


D213-9ST

Cat. No.	Nose Type	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Finish	Handle Color	Weight
201-7CST	Square	9-1/8" (231.8 mm)	1-9/32" (32.5 mm)	1-5/32" (29.4 mm)	1/2" (12.7 mm)	5/8" (15.9 mm)	Plain	—	10.4 oz. (295 g)
D201-7CST	Square	9-1/4" (235.0 mm)	1-9/32" (32.5 mm)	1-5/32" (29.4 mm)	1/2" (12.7 mm)	5/8" (15.9 mm)	Plastic	Blue	12.0 oz. (340 g)
D201-7CSTT NEW!	Square	9" (228.6 mm)	1-1/2" (38.1 mm)	1-1/4" (31.8 mm)	1/2" (12.7 mm)	5/8" (15.9 mm)	Plastic	Blue	10.9 oz (308 g)
213-9ST	Square	9-1/4" (235.0 mm)	1-19/32" (40.5 mm)	1-1/4" (31.8 mm)	5/8" (15.9 mm)	25/32" (19.8 mm)	Plain	—	1.0 lbs. (0.45 kg)
D213-9ST	Square	9-3/8" (238.1 mm)	1-19/32" (40.5 mm)	1-1/4" (31.8 mm)	5/8" (15.9 mm)	25/32" (19.8 mm)	Plastic	Blue	1.1 lbs. (0.50 kg)
D213-9STT NEW!	Square	9-3/8" (238.1 mm)	2" (50.8 mm)	1-1/4" (31.8 mm)	5/8" (15.9 mm)	25/32" (19.8 mm)	Plastic	Blue	1.1 lbs. (0.50 kg)
2000 Series* – Heavy-duty cutting knives									
D2000-7CST	Square	9-1/4" (235.0 mm)	1-9/32" (32.5 mm)	1-5/32" (29.4 mm)	1/2" (12.7 mm)	5/8" (15.9 mm)	Plastic	Blue	11.2 oz. (318 g)
D2000-9ST	Square	9-3/8" (238.1 mm)	1-19/32" (40.5 mm)	1-1/4" (31.8 mm)	5/8" (15.9 mm)	25/32" (19.8 mm)	Plastic	Blue	1.1 lbs. (0.50 kg)

*Cuts ACSR, screws, nails, and most hardened wire. Features combination polished and black-oxide finish.