


Replacement Bits

Standard Order Pack

10 pieces - BULK

General Specifications: 1/4" x 2" (6.35 mm x 50 mm)

Hex Shank Double End Bits S2 Steel HRC 60 ± 2

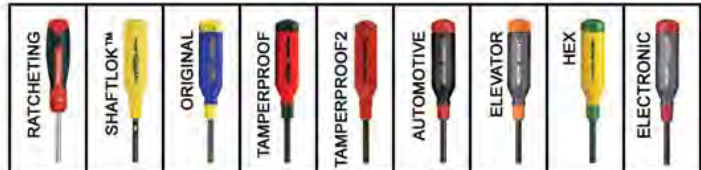

Part #	Description	RATCHETING	SHAFTLOK™	ORIGINAL	TAMPERPROOF	TAMPERPROOF2	AUTOMOTIVE	ELEVATOR	HEX	ELECTRONIC
FD4-6	Flat (Slot) Bit 4-6	●		●				●		●
HD3/32-7/64	Hex (Allen) Bit 3/32"-7/64"								●	
HD1/8-9/64	Hex (Allen) Bit 1/8"-9/64"								●	
HD5/32-3/16	Hex (Allen) Bit 5/32"-3/16"								●	
HD7/32-1/4	Hex (Allen) Bit 7/32"-1/4"								●	
HD2.00-3.00	Hex (Allen) Bit 2.00-3.00 mm								●	
HD4.00-5.00	Hex (Allen) Bit 4.00-5.00 mm								●	
HD5.50-6.00	Hex (Allen) Bit 5.50-6.00 mm								●	
PD0-3	Phillips Bit 0-3	●		●				●		●
PD1-2	Phillips Bit 1-2	●		●			●	●		●
SD0-3	Square (Robertson) Bit 0-3			●						
SD1-2	Square (Robertson) Bit 1-2	●		●						●
TD9-40	Star (Torx) Bit 9-40						●			
TD10-15	Star (Torx) Bit 10-15	●		●			●			
TD20-25	Star (Torx) Bit 20-25	●		●			●			
TD27-30	Star (Torx) Bit 27-30						●			
F4D4-6	Flat (Slot) Bit 4-6		●							
P4D0-3	Phillips Bit 0-3		●							
P4D1-2	Phillips Bit 1-2		●							
S4D0-3	Square (Robertson) Bit 0-3		●							
S4D1-2	Square (Robertson) Bit 1-2		●							
T4D10-15	Star (Torx) Bit 10-15		●							
T4D20-25	Star (Torx) Bit 20-25		●							
TWDT2-3	Tri-Wing 2-3					●				
TWDT4-5	Tri-Wing 4-5					●				
TSDT4-6	Torq-Set 4-6					●				
TSDT8-10	Torq-Set 8-10					●				
TPDT10-15	Torx-Plus TR 10-15					●				
TPDT20-25	Torx-Plus TR 20-25					●				
TPDT27-30	Torx-Plus TR 27-30					●				
HDT1/8-9/64	Hex (Allen) Pin Bit 1/8"-9/64"				●					
HDT5/32-3/16	Hex (Allen) Pin Bit 5/32"-3/16"				●					
STD6-8	Spanner Bit 6-8				●			●		●
STD10-12	Spanner Bit 10-12				●			●		●
TDT10-15	Star (Torx) Pin Bit 10-15				●			●		●
TDT20-25	Star (Torx) Pin Bit 20-25				●			●		●
TDT27-30	Star (Torx) Pin Bit 27-30				●			●		●
F5.5-VST	Flat (Slot) 5.5 x Valve Stem Bit						●			
6SA1/4	1/4" Socket Adapter						●			