

Overview

The HDMI Extender Kit (500451) allows HDMI equipment to be connected up to 131ft (40m) at 4K/30 (4:4:4) or 4K/60 (4:2:0) resolutions, or 230 ft (70 m) at resolutions up to 1080p via one (1) Cat 5e/6 unshielded twisted pair cable in a point-to-point configuration. This kit comes with one (1) transmitter, one (1) receiver, one (1) IR Emitter, and one (1) IR sensor.

Applications

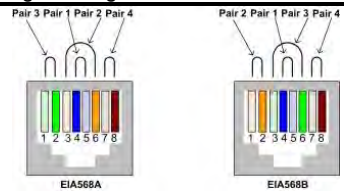
Digital signage, commercial AV systems, classroom projector systems, boardroom systems, collaborative PC systems, medical information systems.



Key Features

- Supports 1080p deep color and full 3D to distances of up to 230 ft (70m) over single Cat5e/6
- Supports 4K @ 24/25/30Hz (4:4:4) and 4K/60 (4:2:0) to distances of up to 131 ft (40m) over single Cat5e/6
- Supports Bi-directional IR pass through
- Supports all digital audio modes
- Includes IR emitter and IR sensor (carrier-wave)
- Compatible with 500451-PoE

Specification Chart

Environment	HDMI 1.4a (3D)								
Devices	DVDs, Blu-ray players, projectors, monitors, TVs, PCs, laptops, servers supporting HDMI.								
Transmission	Transparent to the user.								
Bandwidth	340MHz								
Signals	HDMI 1.4a protocol.								
Connectors	One (1) HDMI receptacle. One (1) RJ45S for Cat5e/6 unshielded or shielded twisted pair.								
<i>Cables not included.</i>	Two (2) 3.5mm sockets for IR Sensor & Emitter (carrier-wave).								
Max. Distance*	<table border="0"> <tr> <td>4K/30 (4:4:4):</td><td>Cat 5e/6: 131ft (40m)</td></tr> <tr> <td>4K/60 (4:2:0):</td><td>Cat 5e/6: 131ft (40m)</td></tr> <tr> <td>1080p:</td><td>Cat 5e/6: 230ft (70m)</td></tr> <tr> <td>1080p Deep Color:</td><td>Cat 5e/6: 230ft (70m)</td></tr> </table> <p><i>*Based on a maximum length of 6.6 ft (2m) of HDMI cable per end.</i></p> <p><i>When installed in an electrically noisy environment, STP cable must be used. Also, cross-connection reduces the effective distance depending on the grade of twisted cable used.</i></p>	4K/30 (4:4:4):	Cat 5e/6: 131ft (40m)	4K/60 (4:2:0):	Cat 5e/6: 131ft (40m)	1080p:	Cat 5e/6: 230ft (70m)	1080p Deep Color:	Cat 5e/6: 230ft (70m)
4K/30 (4:4:4):	Cat 5e/6: 131ft (40m)								
4K/60 (4:2:0):	Cat 5e/6: 131ft (40m)								
1080p:	Cat 5e/6: 230ft (70m)								
1080p Deep Color:	Cat 5e/6: 230ft (70m)								
RJ45 Pin Configuration	RJ45 <table border="0"> <tr> <td>Pin 1 (R)</td><td>Pin 2 (T)</td></tr> <tr> <td>Pin 3 (R)</td><td>Pin 6 (T)</td></tr> <tr> <td>Pin 4 (R)</td><td>Pin 5 (T)</td></tr> <tr> <td>Pin 7 (R)</td><td>Pin 8 (T)</td></tr> </table> <div style="text-align: center;">  <p>EIA568A EIA568B</p> </div> <p><i>Reverse Polarity Sensitive Use EIA/TIA 568 A or B, straight-through wiring.</i></p>	Pin 1 (R)	Pin 2 (T)	Pin 3 (R)	Pin 6 (T)	Pin 4 (R)	Pin 5 (T)	Pin 7 (R)	Pin 8 (T)
Pin 1 (R)	Pin 2 (T)								
Pin 3 (R)	Pin 6 (T)								
Pin 4 (R)	Pin 5 (T)								
Pin 7 (R)	Pin 8 (T)								
Cable	One (1) Category 5e or better twisted pair cables required.								
Power Supply	Two (2) 110-240V/5VDC power supplies with interchangeable blades.								
Power Consumption	Transmitter: 1.6 Watt Receiver: 3.2 Watt								
Temperature	Operating: 0° to 40° C. Storage:-20° to 85° C. Humidity: up to 95% non-condensing.								
Enclosure	Metal								
Dimensions	4.40" x 3.00" x 1.00" (11.2 x 7.6 x 2.5 cm)								
Weight	1.4 lbs (.6 kg)								
Compliance	Regulatory: FCC, CE, RoHS								
Warranty	2 years								
Order Information	500451 HDMI Extender Kit, HDBT, UHD-4K (UPC: 627699004517) 500451-RX, HDMI Receiver, HDBT, UHD-4K (UPC: 627699804513)								
Accessories	500905 Rackmount Transceiver Chassis 3 Port 500920 Rackmount Transceiver Chassis 16 Port								

Typical Application Schematic

