



NC-ST100-A



NC-SL075-MCL



NC-SL100



NC-SL150-EL



NC-ST100-CV




NC-RL075-UM



NC-ST100




NC-RL075-S

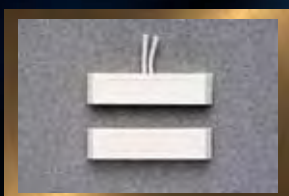


NC-SL100-CLA



NC-RT075

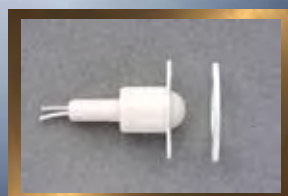

NC-RBL

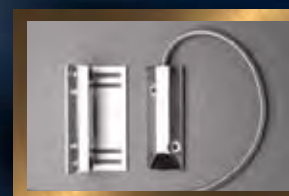

NC-OL200



NC-SL050-UMCL



NC-RL100



NC-RL100-I



NC-RT100

New from Napco!

**Superior value and performance
for every application**

- Professional grade contacts for every installation need
- Precision gold reeds ensure unparalleled catch
- Lifetime performance and durability from gold hardened and stabilized with alloying elements
- UV stabilized, anti-aging, impact-resistant construction for long-life dependability
- Double burn-in quality screening ensures consistent reliability



Napco Gold Series Magnetic Contacts

MODEL	DESCRIPTION	QTY
NC-RL075-S	3/8" Recessed, stubby, leads, 3/4" gap	10
NC-ST100-A	Surface mount, self-adhesive, terminals, 1" gap	10
NC-SL100	Surface mount, leads, 1" gap	10
NC-RT075	3/8" Recessed, terminals, 3/4" gap	10
NC-RT100	3/4" Recessed, terminals, 1" gap, steel door	5
NC-RBL	3/4" Recessed, roller ball, leads	10
NC-OL200	Overhead door, 2" gap, armored cable	1
NC-ST100	Surface mount, terminals, 1" gap	10
NC-ST100-CV	Surface mount, 1" gap, cover, spacer	10
NC-SL100-CLA	Surface mount, self-adhesive, center lead, 1" gap	10
NC-SL150-EL	Surface mount, flanged, end lead, 1.5" gap	10
NC-SL050-UMCL	Surface mount, center lead, 1/2" gap, ultra-mini, nails	10
NC-SL075-MCL	Surface mount, end lead, 3/4" gap, mini, nails	10
NC-RL075-UM	1/4" Recessed, leads, 3/4" gap, ultra-mini	10
NC-RL100	3/8" Recessed, leads, 1" gap	10
NC-RL100-I	Industrial, 1" recessed, leads, 1" gap, steel door	5
NC-SL200-I	Industrial, surface mount, 2" gap, armored cable	1

NAPCO Contact Model Names

NC - R L 075 - S


R = RECESSED
S = SURFACE MOUNT
RB = RECESSED ROLLER BALL

L = LEADS
T = TERMINALS

050 = 1/2 " GAP
075 = 3/4 " GAP
100 = 1" GAP
150 = 1 1/2 " GAP
200 = 2 " GAP

S = STUBBY
A = SELF-ADHESIVE
CV = COVER
CL = CENTER LEAD
EL = END LEAD
UM = ULTRA MINI
M = MINI
I = INDUSTRIAL

Just added!

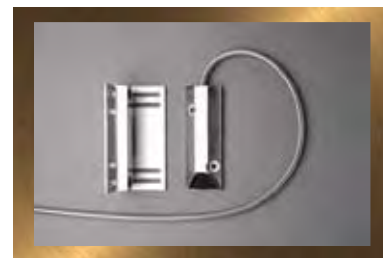

SL-100-1

More Gold Series Contacts are being added regularly. To see the full line go to www.napcoinsider.com/contacts.html



333 Bayview Avenue, Amityville, New York 11701 USA • 1-800-645-9445 • www.napcosecurity.com

Preliminary Data Sheet. Specifications subject to change. © NAPCO, 5/06 A517

Publicly traded on
NASDAQ
NSSC

NAPCO Product Availability Hotline – Call our Stock-Out Hotline at 1-800-645-9330 Press 1, pause, then 2.
Or email us at hotline@napcosecurity.com