



Allseal® Gasketing Perimeter Seal or Sweep 9600



Material

Aluminum alloy 6063, T5 temper
Synthetic polymer: Polyamide
Nylon brush plus


- Premium grade seals specially formulated to withstand greater temperature extremes while providing maximum protection against air infiltration
- Excellent abrasion resistance, flexibility and memory
- Moisture resistant
- Retains insecticides well
- Temperature range -70°F to 425°F
- BHMA Certified to ANSI/BHMA A156.22 performance tests for heat, cold, air infiltration and smoke infiltration in most common profiles as indicated by BHMA Certified symbol
- REACH and RoHS compliant
- Not effective against water penetration
- #6 x 3/4" stainless steel sheet metal screws furnished
- Screw holes slotted for adjustment

Finishes

9600	Mill Aluminum	Gray Brush
9600A	Anodized Aluminum	Gray Brush
9600B	Gold	Black Brush
9600DKB	Dark Bronze	Black Brush

Options

FATT - Fast Attach Tape

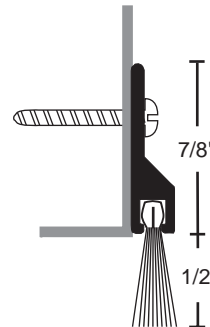

Project:

Submitted by:

Date:

Notes: