



Sliding 200 Series

For Sliding Panels up to 200 lbs.
Manufactured by P.C. Henderson

280C Side Wall Mounted

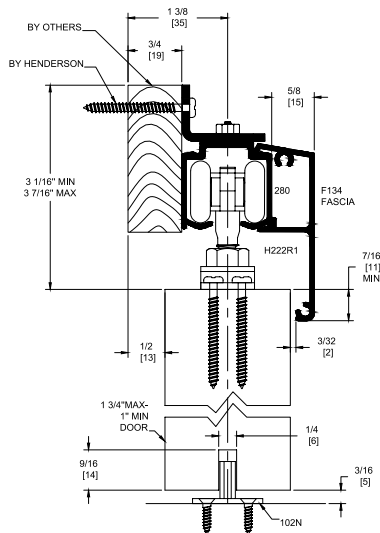

280C Soffit Mounted with Fascia

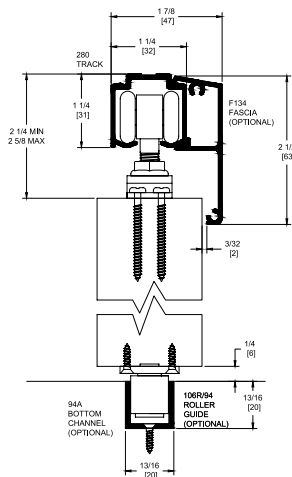

Configurations:

- Single
- Bi-parting

Installations:

- Overhead Mount
- Side Wall Mount
- Face/Face Fixed Mount with Fascia

Features:

- Hanger body is made of nickel plated zinc alloy for durability and long life
- Zinc alloy ball bearing wheels coated in nylon for smooth operation
- 200 lb. panel capacity
- Galvanized steel track 280
- Clear anodized aluminum track 280C
- 2 year warranty

H200A Kits Include:

- 1 ea **280C** Clear Anodized Aluminum Track
- 2 ea **H222R1** Hangers
- 1 ea **102N** Nylon Guide
- 2 ea **TELS-14KIT** Stops
- 1 ea Adjusting Wrench and Mounting Hardware

H200 Kits Include:

- 1 ea **280** Steel Track
- 2 ea **H222R1** Hangers
- 1 ea **102N** Nylon Guide
- 2 ea **TELS-14KIT** Stops
- 1 ea Adjusting Wrench and Mounting Hardware

Standard Kit Sizes

Part Number	Material	Track Length	Door Width
H200A/4	Aluminum	48"	24"
H200A/5-4	Aluminum	64"	32"
H200A/6	Aluminum	72"	36"
H200A/7	Aluminum	84"	42"
H200A/8	Aluminum	96"	48"
H200A/10	Aluminum	120"	60"
H200A/12	Aluminum	144"	72"
H200/6	Steel	72"	36"
H200/8	Steel	96"	48"

Options: See page 49

Hardware Kit
Mounting Bracket

H200PACK

281 available as 5 pack only, **2815**
NOTE: Need one at each end and no more than 3 feet in between.

Fasteners included

287HD

94A

F134C in clear anodized (**280C** only)
F134D dark bronze anodized fascia

280D dark bronze anodized
106R/94

102WA (steel) and **102WN** (nylon)

971A

K134EP (use with F134C and 280C only) **K134DEP** (use with F134D and 280D only)

Polypropylene Guide Rail **EPD3BL** for use with 102N or 102WN

ASSA ABLOY

The global leader in
door opening solutions

800-824-3018 | www.pemko.com

Check the web site for the up-to-date catalog

Copyright © 2015-2017, Pemko Manufacturing Co., an ASSA ABLOY Group company. All rights reserved.
Reproduction in whole or in part without the express written permission of Pemko Manufacturing Co. is prohibited.