

FSS-26T

DYNAMIC FLAT TRUMPET SIREN




- Wall or ceiling mount
- 6 dip-switch selectable sounds
- 125dB sound output
- Impact resistant housing
- Low profile design
- Patented design
- Bi-directional mounting bracket
- Waterproof housing
- Designer white housing
- FSS-26T: 3.34"(W) x 3.34"(L) x 2.16" (D)


The FSS-26T siren is extremely loud and surprisingly small. It is almost half the size of standard 15 watt trumpet sirens and puts out 125dB. This little screamer is almost as powerful as a big 30 watt horn. However, the FSS-26T is not a high pitched piezo. It does utilize a unique patented reverse trumpet technology to generate the loudest sound blast. In addition, there is a six dip-switch selectable siren sound option. These sounds can be set individually or programmed sequentially. The FSS-26T is an indoor/outdoor design with a reversible mounting bracket.

Multiple Tones:


- (1) Yelp
- (2) Ray Gun Warble
- (3) European
- (4) Slow Whoop
- (5) Pulsing Buzzer
- (6) Ray Gun Yowl

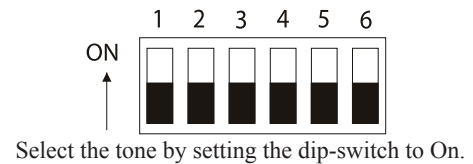

Dynamic Flat Trumpet Design

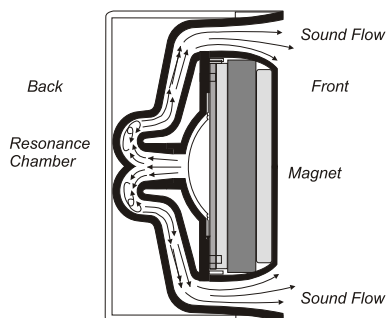

Bi-directional Mounting Bracket

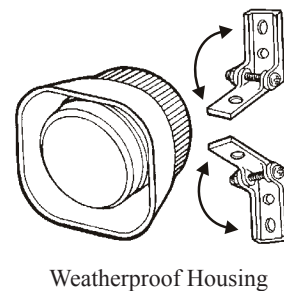

Specifications

Model Number	Rated Power (VDC)	Rated Current (Amps)	Multi-Tones (Selectable)	Sound Output (dBA/1ft)	Installation Type	Housing Color	Operating Temperature Range
FSS-26T	12	1.2	6	125	Indoor/Outdoor	White	14°F - 122°F -10°C - 50°C