

J-Hooks

2 Types (JH & CCP)

5 Styles

6 Sizes



End Hook
J-Hook



CCP Series
J-Hook

Locked

Unlocked

PLATINUM TOOLS®

J-Hooks

The perfect solution for heavy duty hanging applications. Traditional style, construction grade, multi-purpose J-Hooks, provide stress free cable support and help organize and build a distribution pathway for various types of cables. Some popular uses would be for above-suspended ceilings and below-raised floors. Perfect for the garage and shop too!

- Pre-assembled attachments
- All steel construction
- UL & CUL listed (JH only)

Application

Perfect for the cabling industry, shop and home.

- Telcom / Voice
- Network / Data
- Broadband, Satellite
- CCTV
- Fiber
- Flexible conduit

Technical Data

- 5 J-Hook Styles: Standard, Batwing, 90° Angle, End Hook & Hammer-On
- Material: Galvanized Steel
- Finish: Yellow Zinc Chromate
- COO: China

J-Hook Size	Load Capacity
12 (3/4")	12 lbs
16 (1")	14 lbs
21 (1 5/16")	17 lbs
32 (2")	17 lbs
48 (3")	30 lbs
64 (4")	50 lbs

Packaging

- Sizes 12, 16, 21 and 32 — box of 100
- Sizes 48 and 64 — box of 25

*Threaded rods and end attachments not included.
See reverse for additional J-Hooks and order information.*

Phone: 800.749.5783
Fax: 800.749.5784


806 Calle Plano
Camarillo, CA 93012
www.platinumtools.com

We Make Connections EZ!

NEW!

J-Hook Ordering Information (UL and CUL listed)

Part No.	Description	Quantity	UPC	Weight Per Box	CADDY® Part No.	B-Line Part No.
JH12-100	3/4" Standard J-Hook, Size 12	Box of 100	899740001879	5 lbs	CAT12	BCH12
JH12W-100	3/4" Batwing J-Hook, Size 12	Box of 100	899740001886	8 lbs	CAT124Z34	BCH12-W2
JH12AC-100	3/4" 90° Angle J-Hook, Size 12	Box of 100	899740001893	8 lbs	CAT12AB	BCH12-RB
JH21-100	1 5/16" Standard J-Hook, Size 21	Box of 100	899740001909	14 lbs	CAT21	BCH21
JH21W-100	1 5/16" Batwing J-Hook, Size 21	Box of 100	899740001916	16 lbs	CAT214Z34	BCH21-W2
JH21AC-100	1 5/16" 90° Angle J-Hook, Size 21	Box of 100	899740001923	18 lbs	CAT21AB	BCH21-RB
JH32-100	2" Standard J-Hook, Size 32	Box of 100	899740001930	17 lbs	CAT32	BCH32
JH32W-100	2" Batwing J-Hook, Size 32	Box of 100	899740001947	20 lbs	CAT324Z34	BCH32-W2
JH32AC-100	2" 90° Angle J-Hook, Size 32	Box of 100	899740001954	21 lbs	CAT32AB	BCH32-RB
JH32EH-100	2" End Hook J-Hook, Size 32	Box of 100	899740002258	21 lbs	N/A	N/A
JH32HOK58-100	2" Hammer-On J-Hook, Size 32, 5/16" - 1/2" Flange	Box of 100	899740002180	21 lbs	CAT3258SM	BCH32E58
JH64-25	4" Standard J Hook, Size 64	Box of 25	899740002166	13.5 lbs	CAT64	BCH64
JH64W-25	4" Batwing J-Hook. Size 64	Box of 25	899740002197	14 lbs	N/A	N/A
JH64AC-25	4" 90° Angle J-Hook, Size 64	Box of 25	899740002210	14 lbs	CAT64AB	BCH64-RB

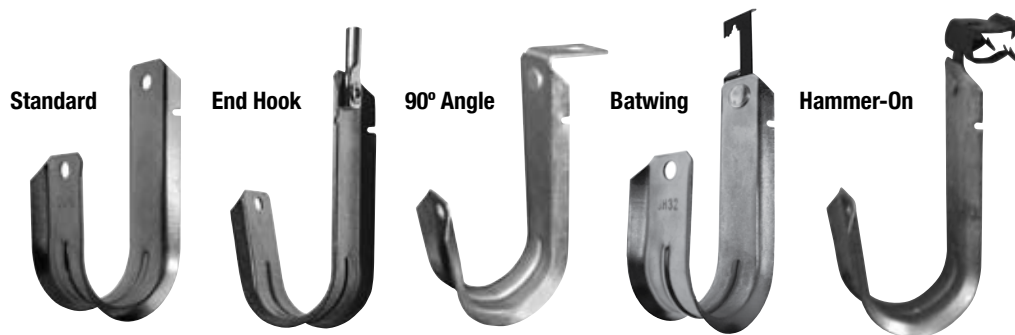


CCP Series—Cable Cage Polypropylene J-Hooks

Part No.	Description	Quantity	UPC	Weight Per Box	CADDY® Part No.	B-Line Part No.
CCP16-100	1" Standard CCP J-Hook. Size 16.	Box of 100	899740003132	7.5 lbs	N/A	N/A
CCP16W-100	1" Batwing CCP J-Hook. Size 16	Box of 100	899740003170	11 lbs	N/A	N/A
CCP16AC-100	1" 90° Angle CCP J-Hook. Size 16	Box of 100	899740003156	12 lbs	N/A	N/A
CCP32-100	2" Standard CCP J-Hook. Size 32	Box of 100	899740002241	13 lbs	N/A	N/A
CCP32W-100	2" Batwing CCP J-Hook. Size 32	Box of 100	899740002234	16 lbs	N/A	N/A
CCP32AC-100	2" 90° Angle CCP J-Hook. Size 32	Box of 100	899740002227	16 lbs	N/A	N/A
CCP48-25	3" Standard CCP J-Hook. Size 48	Box of 25	899740003149	8.5 lbs	N/A	N/A
CCP48W-25	3" Batwing CCP J-Hook. Size 48	Box of 25	899740003187	11 lbs	N/A	N/A
CCP48AC-25	3" 90° Angle CCP J-Hook. Size 48	Box of 25	899740003163	11 lbs	N/A	N/A

CCP Series—Cable Cage Polypropylene J-Hooks: Steel J-Hooks are over-molded with polypropylene for ultra smooth cable glide and designed with a locking cable cage.

- Super smooth edges eliminates cable snags
- Molded hook for fast lock & latch
- EZ open & close
- Plenum safe
- Patent pending

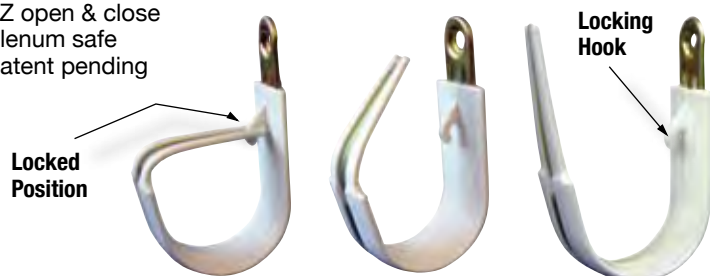

PLATINUM TOOLS®

Phone: 800.749.5783

Fax: 800.749.5784

806 Calle Plano
Camarillo, CA 93012

www.platinumtools.com

We Make Connections EZ!

©2010 Platinum Tools, Inc. All rights reserved. J-Hook REV-D1 10/10
CADDY® is the registered trademark of ERICO International Corporation.