



## International Eurovault Safes

These burglary and fire resistant safes are an affordable solution to protect documents and valuables.

All Eurovaults come with the revolutionary **Security Installation Platform** to ensure accurate, secure installation.

SIP →



The four-point anchoring system and pry-resistant designs deters attempts to remove the safe by force.

U.L. Group II combination lock with satin finish dial, dial ring, and handle

Auto firing passive relocker protects locks during forced entry attempt

High security key lock on most sizes

One hour fire rating at 1500°

High tensile strength drill resistant stainless steel hardplate

 
Heavy duty, adjustable shelves

Auto lock bolt extends automatically after door is closed


Excellent for both residential and small business use!




High security safe construction in a variety of sizes,




EV-1713

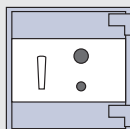


EV-1717

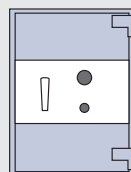

EV-2417

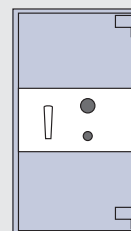

EV-3417

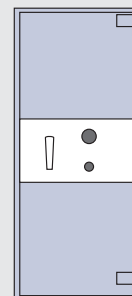

EV-4517

Model	Interior H x W x D (in)	Exterior H x W x D (in)	Weight (lbs)	Capacity (cu ft)	Shelves
EV-1713	17 x 13 x 13	21 x 17 x 19.5	380	1.6	1
EV-1717	17 x 17 x 17	21 x 21 x 23.5	510	2.8	1
EV-2417	24 x 17 x 17	28 x 21 x 23.5	625	4.2	2
EV-3417	34 x 17 x 17	38 x 21 x 23.5	810	5.6	2
EV-4517	45 x 17 x 17	49 x 21 x 23.5	1084	7.5	3

# Customized Design and Extra Features

## International EVRH-2417

The international Eurovault Rotary Hopper is the first depository safe of its kind

Great for any business environment!

Provides temporary storage for excess cash throughout the day

Deposit through tamper-proof slot, and pull the rotary hopper

Slot sends accumulated cash into a secured inner compartment

Electronic lock available

### Interior H x W x D (in)

10/compartment x 17 x 17

### Exterior H x W x D (in)

28.75 x 22.5 x 23.5

### Weight (lbs)

693

### Capacity (cu ft)

1.8

### Shelves

0

## International EV-2519 DDS

Secure until authorized personnel opens moves contents to a high security location

### Interior H x W x D (in)

24 x 17 x 17

### Exterior H x W x D (in)

28 x 21 x 23.5

### Weight (lbs)

625

### Capacity (cu ft)

4.2

### Shelves

0

Shown with electronic lock

Dual locking function with bolt control

Slots drop into individual compartments

Two separate locking compartments

Electronic lock offers programmable combinations, multiple user interface, time delay, and auditing feature

### Dallas

3140 Towerwood Drive  
Dallas, Texas 75234  
Tel. 972.243.3711  
Toll. 800.225.2984

[www.rslc.net](http://www.rslc.net)

### New Orleans

1926 Airline Drive  
Metairie, LA 70001  
Tel. 504.835.7233  
Toll. 800.873.8898

[www.rollandnola.net](http://www.rollandnola.net)