

15 Series Electric Strike


The SDC 15 Series Electric Strike is a Centerline Latch Entry* strike designed for use with Cylindrical lockset with up to 3/4" (19mm) throw latchbolts. The 15 series electric strikes incorporates all stainless steel deadlocking mechanism and an internally mounted solenoid.

*Centerline Latch Entry: The latch must enter at the strike "Centerline" located exactly between the top and bottom of the strike faceplate. Refer to strike installation instructions and template to determine strike location prior to frame preparation for New and Retrofit installations. Not recommended for word applications.




FEATURES

- For use with 5/8" latchbolt, or up to 3/4" latchbolt with 1/8" door gap
- Choice of failsafe or failsecure
- Non-handed
- All stainless steel parts with durable die case body for corrosion resistance
- 630 Satin stainless steel face plate
- Screw terminals

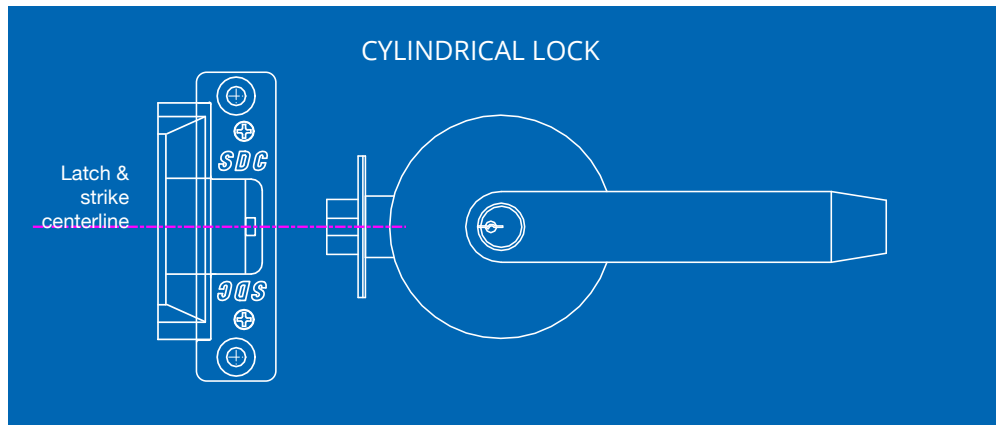

INSTRUCTIONS

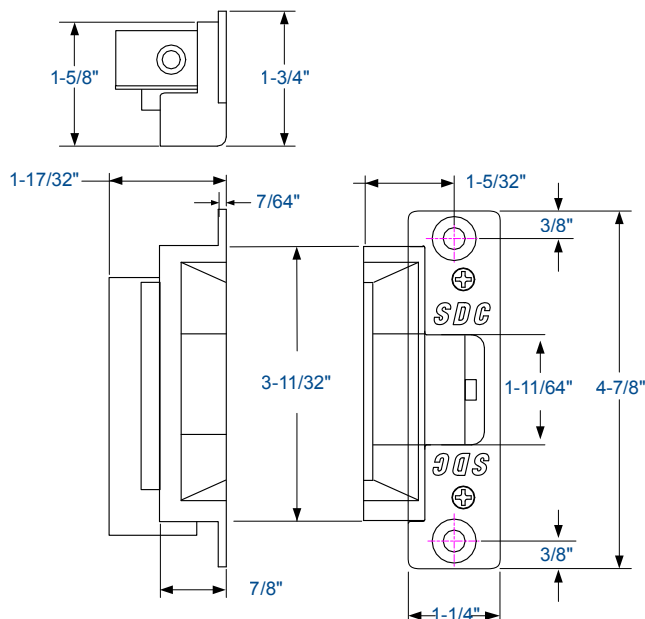

MODEL

15-4S24U

Failsecure, 24VDC continuous;

15-4F24U

Failsafe, 24VDC continuous

15-4SU

Failsecure, 12VDC continuous

15-4FU

Failsafe, 12VDC continuous

SPECIFICATIONS

Voltage	150 mA @ 24VDC
	200 mA @ 12VDC

Dimensions	1-1/4" W x 4-7/8" H x 1-1/2" D
------------	--------------------------------





920 IPRW Wiegand Access Control Keypad or Reader



IPPro IP-based Access Control Controller



602RF 1 Amp, 12/24 VDC Class 2 Output Power Supply