

Flush-Mount Sensor

E-932-D33TBQ - Dual Photobeam Sensor

E-932-S16RRQ - Reflective Beam Sensor


Features:

- Typical applications include: sensor for entrances, hallways, office rooms, retail shops or homes.
- Attractive flush-mount design fits unobtrusively into the decor of most offices, retail shops or homes.
- Fits single-gang box.
- Adjustable alignment angle, up to ± 15 degrees horizontally/vertically.
- Compact size: $4\frac{3}{4}" \times 2\frac{3}{4}" \times 1\frac{1}{2}"$ (121x70x38mm)
- Form "C" 1-amp relay output (N.O./N.C./COM).



E-932-D33TBQ


Range: 33ft

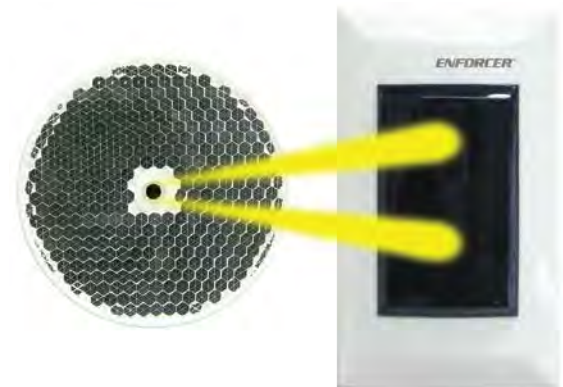

E-932-S16RRQ

Range: 16ft

Installation:

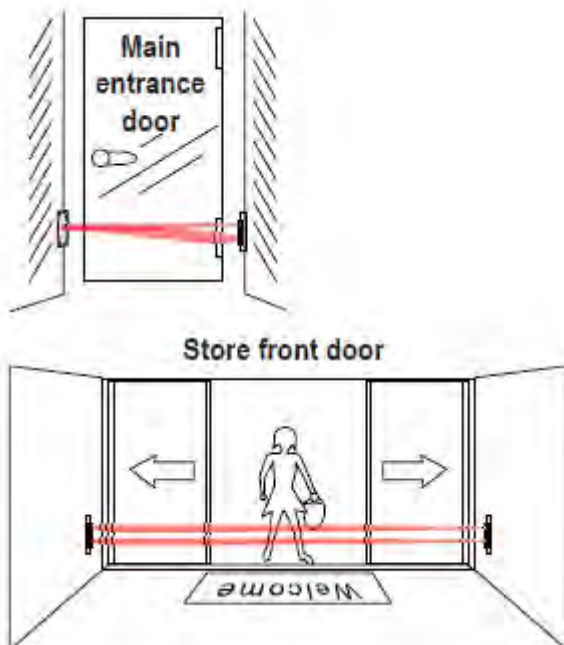

Specifications:

	E-932-S16RRQ	E-932-D33TBQ
Type	Reflective beam	Dual through beam
Sensing Range	16ft (5m)	33ft (10m)
Supply Voltage	12~18VDC	12~18VDC
Current Drain	50mA max.	50mA max.
Response Time	10msec.	10msec.
Light Source	IR LED	IR LED
LEDs	Red (on): Power Yellow (off): Aligned Yellow (on): Out of alignment	TX Red (on): Power RX Red (off): Aligned RX Red (on): Out of alignment
Output	N.C., N.O., Common	N.C., N.O., Common
Switching Capacity	1A@120V (AC/DC)	1A@120V (AC/DC)
Ambient Temperature	14°~122°F (-10°~50°C)	14°~122°F (-10°~50°C)
Alignment Angle	Vert. $\pm 15^\circ$, Horiz. $\pm 15^\circ$	Vert. $\pm 15^\circ$, Horiz. $\pm 15^\circ$

SECO-LARM® U.S.A., Inc.

16842 Millikan Avenue, Irvine, CA 92606

Phone: (949) 261-2999 | (800) 662-0800 Fax: (949) 261-7326

Website: www.seco-larm.com Email: sales@seco-larm.com

Copyright 2015 © SECO-LARM U.S.A., Inc. All rights reserved.
All trademarks are the property of SECO-LARM U.S.A., Inc. or their respective owners.
The SECO-LARM policy is one of continual development. For that reason, SECO-LARM reserves the right to change prices and specifications without notice. SECO-LARM is not responsible for misprints.

SECO-LARM® ENFORCER® CRIMEBUSTER® CBA SLI®

PI_E-932-D33TBQ_150811.docx