

Outdoor Piezoelectric Request-to-Exit Pushbuttons

- SD-6276-SS1Q** Single-gang plate, "EXIT/SALIDA"
SD-6276-SSVQ Single-gang plate, manual override
SD-6176-SS1Q Slimline plate, "EXIT/SALIDA"
SD-6176-SSVQ Slimline plate, manual override

Features:

- Piezoelectric pushbuttons for indoor or outdoor use (IP65)
- No moving parts for heavy duty use
- LED ring around button changes from green to red or red to green when the button is pressed
- Timed or toggle output
- SD-6176-SSVQ and SD-6276-SSVQ include separate manual override button for use in case of a power failure to the pushbutton
- Relay rated 2A@30VDC with two individually programmable outputs (NO/NC)

Specifications:

Operating voltage		12~24 VDC
Current drain		100mA@12VDC
Contact rating		2A@30VDC or 0.5A@125VAC
Ring LED Default	Standby	Red
	Active	Green
Output time		1~30 s, Toggle
IP rating		IP65
Operating temperature		32°~158° F (0°~70° C)
Plate material		Stainless steel
Weight	Single-Gang	3.5-oz (99g)
	Single-Gang w/Manual Override	4-oz (113g)
	Slimline	2.6-oz (74g)
	Slimline w/Manual Override	3.1-oz (88g)



SD-6276-SS1Q



SD-6176-SS1Q




SD-6276-SSVQ



SD-6176-SSVQ

Dimensions:

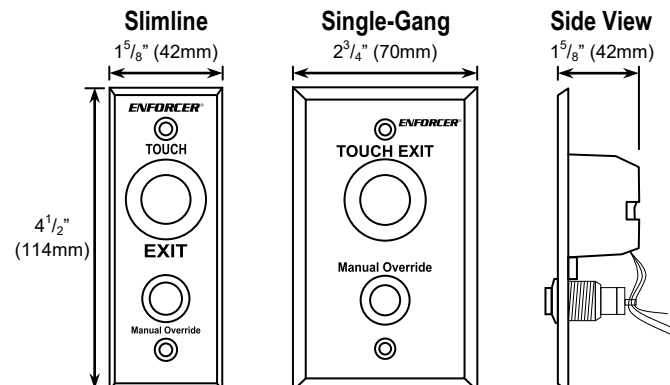

SECO-LARM

16842 Millikan Ave • Irvine, CA 92606

Tel: 949-261-2999 / 800-662-0800 • Fax: 949-261-7328

sales@seco-larm.com • www.seco-larm.com



Copyright 2012 © SECO-LARM U.S.A., Inc. All rights reserved.
 The SECO-LARM policy is one of continual development. For that reason, SECO-LARM reserves the right to change prices and specifications without notice. SECO-LARM is not responsible for misprints.

SECO-LARM® CRIMEBUSTER® CBA® SLI®

pi-SD-6x73-SSxQ_1005.docx