

No-Cut Door Strike

SD-993C-D3Q

The **SECO-LARM®** No-Cut Door Strike provides for both horizontal and vertical adjustment with a reversible non-handed design for greater flexibility.

SECURITY



Features:

- Horizontally adjustable keeper accommodates latchbolt positioning
- Vertically adjustable ramp accommodates nib positioning
- Low profile: Strike is only 1 1/16" deep for use with aluminum frames
- Field selectable for fail-safe or fail-secure operation
- Mounting tabs included for mounting to hollow aluminum & metal doors
- Reversible non-handed design fits most door frames
- For Indoor Use Only
- Static strength – 1,500 lbs. (680kg)
- Dynamic strength – 70 ft-lbs. (9.68 m-kgs)
- 12/24 VDC Operating voltage
- Tested to 100,000 cycles (UL Tested), tested to 1,000,000 cycles (Factory Tested)
- Low current draw: 300mA@12VDC, 150mA@24VDC



12/24
VDC

Fail
Safe
Fail
Secure

Horizontal
Adjustment


Vertical
Adjustment

1,500 lbs.
Static
Strength

Specifications:

Operating voltage	12/24 VDC	
Current draw	12VDC	300mA
	24VDC	150mA
Latch throw	9/16" (15mm)	
Keeper width	17/16" (36mm)	
Static strength	1,500 lbs. (680kg)	
Dynamic strength	70 ft-lbs. (9.68 m-kgs)	
Endurance	100,000 cycles (UL Tested), 1,000,000 cycles (Factory Tested)	
Operating temperature	32°~120° F (0°~49° C)	
Operating humidity	0~85%	
Dimensions	4 7/8" x 1 1/4" x 1 1/16" (124x32x27.5 mm)	

Dimensions:

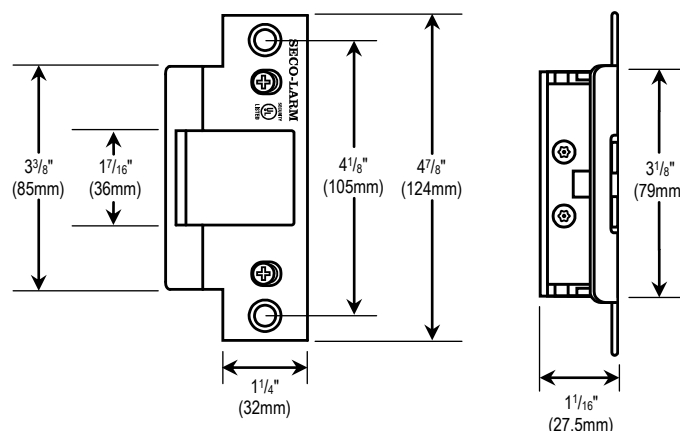

SECO-LARM® U.S.A., Inc.

16842 Millikan Avenue, Irvine, CA, 92606

Phone: (949) 261-2999 | (800) 662-0800 Fax: (949) 261-7326

Website: www.seco-larm.com Email: sales@seco-larm.com



Copyright © 2016 SECO-LARM U.S.A., Inc. All rights reserved.
The SECO-LARM policy is one of continual development. For that reason, SECO-LARM reserves the right to change prices and specifications without notice. SECO-LARM is not responsible for misprints.

SECO-LARM® ENFORCER® CRIMEBUSTER® CBA SLI®

PI_SD-993C-D3Q_161020.docx