


HD-TVI IR Bullet Camera

CVC617T 3.6mm fixed lens, dark gray housing

Features

- Full HD resolution over coax (HD-TVI)
- IR Range: 65' (depending on scene reflection)
- IP66 compliant, weather resistant
- Mounting bracket included
- Additional analog output for 960H
- Full OSD operation via UTC (TVI)
- 12VDC operation
- 5 year warranty

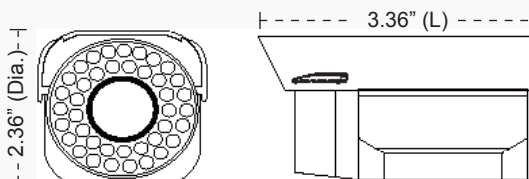

Specifications

Image Sensor	1/3" Progressive Scan CMOS, 2MP
Resolution	1920 x 1080 @ 30fps
Minimum Illumination	0.00 lux (IR LED on)
Effective Pixels	1984 (H) x 1105 (V)
Total Pixels	2000 (H) x 1121 (V)
Number of IR LEDs	24
IR Range	65' (depending on scene reflection)
Scanning System	2:1 interlaced
Synchronization	Internal
S/N Ratio	50dB
Video Output	CVBS: 1.0Vp-p, 75 ohms
Electronic Shutter Speed	1/60 sec. – 1/100,000 sec.
Backlight Compensation	Automatic
AGC	Automatic
Power Consumption	120mA (IR LED off), 350mA (IR LED on)
Power Supply	12VDC (power supply not included)
Operating Temperature	14° F – 120° F
Dimensions	2.36" (Dia.) x 3.36" (L)
Weight	12.8 oz.
Included in Package	Mounting bracket with screws

Optional Accessories



PSW5
12VDC
Power Supply



TVIUTPPT
HD Video Transceiver
with Pigtail (Balun)



TVIUTP
HD Video
Transceiver