

Commercial Series 70/25V Weather Resistant P.A. Horn Speakers


SPC10RT 7" x 5" P.A. Horn Speaker - 70/25V

SPC15RT 8" x 6" P.A. Horn Speaker - 70/25V

SPC30RT 11" x 8" P.A. Horn Speaker - 70/25V

Features

- Stylish appearance
- Weather-resistant, ABS construction
- Includes mounting bracket
- 2 year warranty

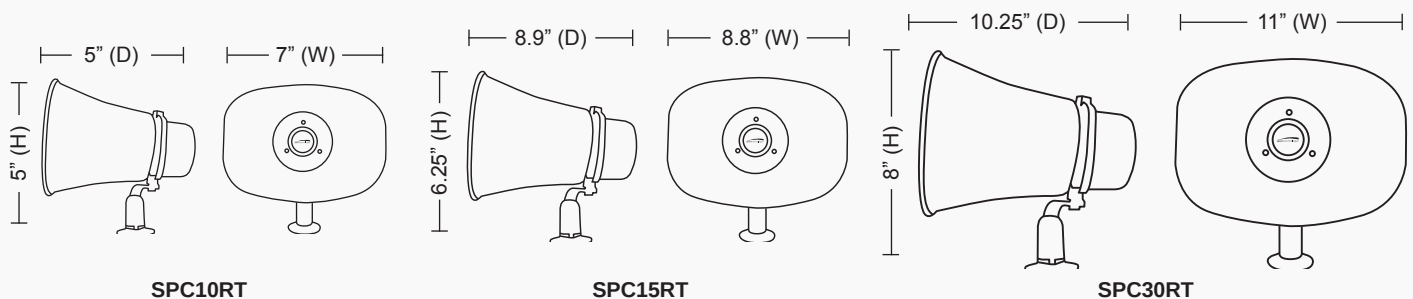

Specifications

	SPC10RT	SPC15RT	SPC30RT
RMS Power	10W	15W	30W
Max. Power.....	20W	30W	60W
Transformer Type.....	70/25V	70/25V	70/25V
Transformer Power Taps	70V: 10W, 5W, 3W, 1W 25V: 10W, 5W, 1.3W, 0.6W, 0.4W, 0.1W	70V: 15W, 10W, 5W, 3W, 1W 25V: 15W, 10W, 5W, 1.3W, 0.6W, 0.4W, 0.1W	70V: 30W, 15W, 10W, 5W, 3W, 1W 25V: 30W, 15W, 10W, 3.7W, 1.9W, 1.3W, 0.6W, 0.4W, 0.1W
Termination Type	Wire strip	Wire strip	Wire strip
Sensitivity (1W/1M).....	103dB	105dB	107dB
Maximum SPL (Pmax/1m).....	113dB	117dB	122dB
Driver Impedance	8 Ohms	8 Ohms	8 Ohms
Magnet.....	4.1 oz.	5.1 oz.	5.3 oz.
Frequency Response Range.....	500Hz ~ 15kHz	450Hz ~ 15kHz	350Hz ~ 15kHz
Dispersion@100Hz	65° conical	70° (H) x 60° (V)	90° (H) x 60° (V)
Speaker Dimensions	7" (W) x 5" (H) x 5" (D)	8.8" (W) x 6.25" (H) x 8.9" (D)	11" (W) x 8" (H) x 10.25" (D)
Weight	3 lbs.	3.6 lbs.	4.2 lbs.
Material.....	ABS	ABS	ABS
Color	Khaki	Khaki	Khaki