

# SCB-6003

1080p Analog HD Camera




\* Lens not included

## Key Features

- Full HD (1920 x 1080, 30fps) resolution
- 0.04Lux@F1.2 (Color), 0.004Lux@F1.2 (B/W)
- Day & Night (ICR), DWDR, SSNRIV, Motion detection
- Transmission distance max. 500m
- Easy installation (Plug & play), Dual power, RS-485

## Dimensions

Unit : mm (inch)

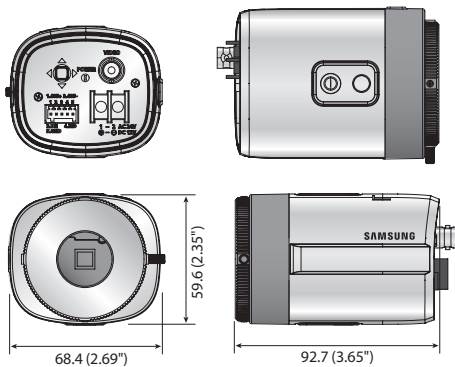

SCB-6003N/P	
<b>VIDEO</b>	
Imaging Device	1/3" 2M CMOS
Total Pixels	1,956(H) x 1,266(V) 2.47M pixels
Effective Pixels	1,944(H) x 1,092(V) 2.12M pixels
Scanning System	Progressive scan
Min. Illumination	Color : 0.04Lux (F1.2) B/W : 0.004Lux (F1.2)
S / N Ratio	52dB (AGC off, Weight on)
Video Output	BNC (AHD, CVBS selectable)
Resolution	1920 x 1080
Max. Framerate	30fps@1080p, 30fps@720p
<b>LENS</b>	
Mount Type	C / CS
<b>OPERATIONAL</b>	
On Screen Display	English, Japanese, Spanish, French, Portuguese, Korean, German, Italian, Russian, Polish, Czech, Romanian, Serbian, Swedish, Danish, Turkish
Camera Title	Off / On (Displayed 15 characters)
Day & Night	Auto (ICR) / External / Color / B/W
Backlight Compensation	Off / User BLC / HLC
Wide Dynamic Range	DWDR
Digital Noise Reduction	SSNRIV (Off / On)
Defog	Off / Auto / Manual
Motion Detection	Off / On (4 zones)
Privacy Masking	Off / On (4 zones rectangle)
Gain Control	Off / Low / Middle / High
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,800K ~ 10,500K)
Electronic Shutter Speed	1sec ~ 1/12,000sec
Reverse	Off / H-Rev / V-Rev / HV-Rev
Profile	Basic, Day & Night, Backlight, Indoor, User
Alarm	(MD) output 1, External D/N 1
Remote Control Interface	Coaxial control, RS-485
Protocol	Coax : NTSC/PAL - Samsung CCVC, Pelco-C (Coaxitron), AHD - ACP (AHD Coax Protocol) RS-485 : Samsung-T/E, Pelco-D/P, Panasonic, Bosch, Honeywell, Vicon, AD, GE
Video Transmission Distance	500m (1,640.42ft) (75-5 coaxial cable)
<b>ENVIRONMENTAL</b>	
Operating Temperature / Humidity	-10°C ~ +55°C (+14°F ~ +131°F) / Less than 90% RH
<b>ELECTRICAL</b>	
Input Voltage / Current	Dual (24V AC & 12V DC ±10%)
Power Consumption	Max. 4.2W
<b>MECHANICAL</b>	
Color / Material	Black, Ivory / Aluminum, Plastic
Dimensions (WxHxD)	68.4 x 59.6 x 92.7mm (2.69" x 2.35" x 3.65")
Weight	175.5g (0.39 lb)

\* The latest product information / sepecification can be found at <http://security.hanwhatechwin.com>

## Available Lenses / Accessories (Optional)

