

DESCRIPTION

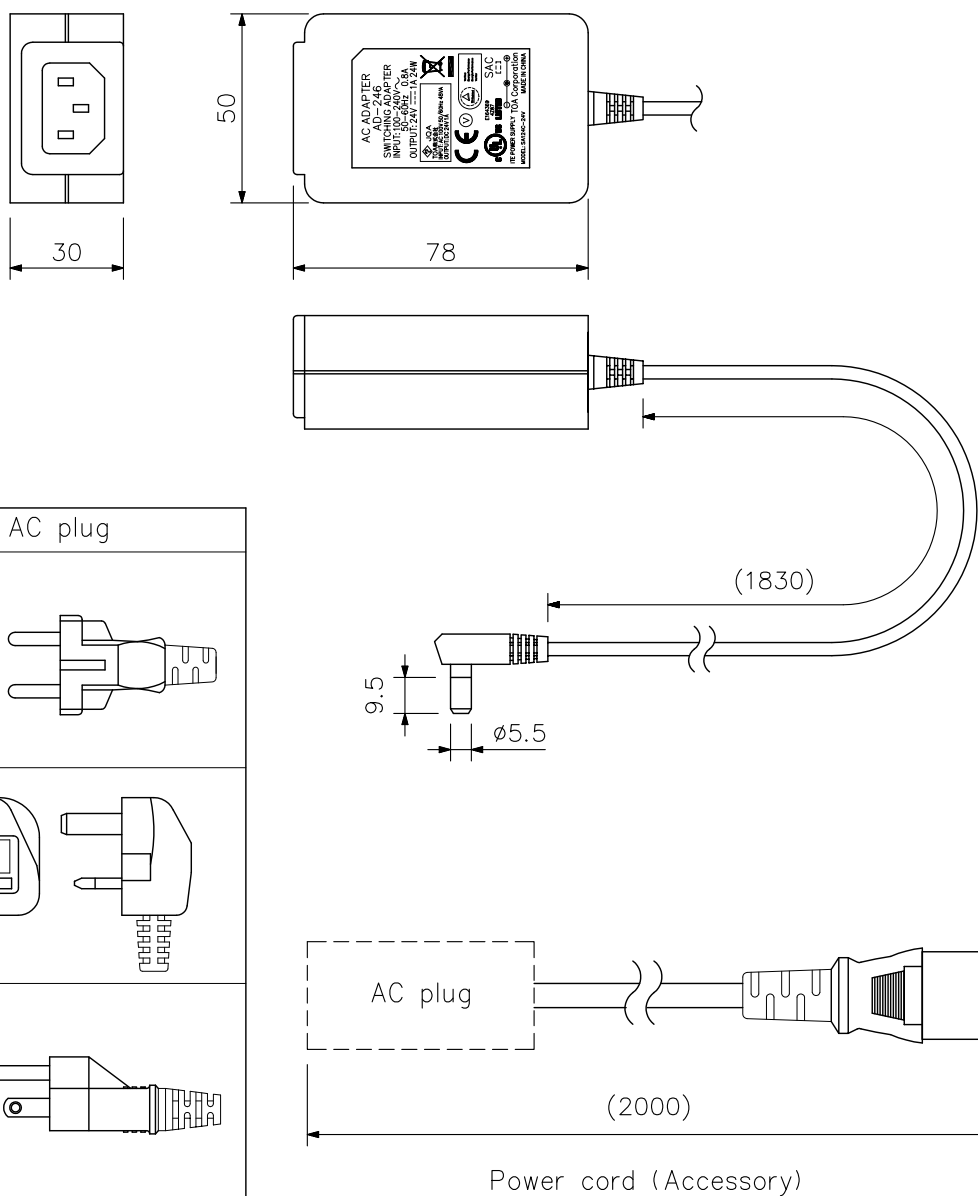
The AD-246 is a compact switching AC adapter.

 
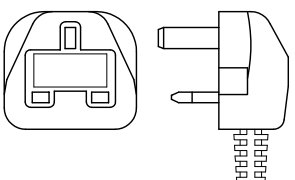
 
SPECIFICATIONS

Version	ER/UK	US
Power Source	220 – 240 V AC, 50/60 Hz	110 – 120 V AC, 50/60 Hz
Output	24 V DC, 1 A	
Current Consumption	270 mA (rated output)	420 mA (rated output)
Cord Length	1.8 m	
Plug	RC6705 center”+”	
Operating Temperature	0 °C to +40 °C	
Finish	Case: Heat-resistant resin, black	
Weight	130 g	
Accessory	Power cord (2 m) *1	

※ Do not use this AC adapter for the unit which does not designate its use in combination.
Doing so may cause a fire.

APPEARANCE



Version	AC plug
ER	
UK	
US	

UNIT:mm SCALE:1/2

Note: Numerical values in parentheses are for reference only.