

## DESCRIPTION



The CA-130 is a 1-DIN size unit 30 W car amplifier designed for use with a 12 V battery car.

## SPECIFICATIONS


|                      |   |
|----------------------|---|
| Power Source         | Standard voltage: 14 V DC<br>Usable voltage: 10 – 16 V DC (12 V battery used)   |
| Power Consumption    | 5 A or less at rated output   |
| Rated Output         | 30 W  |
| Output Impedance     | 4 Ω (BRN), 8 Ω (ORG), Common (WHT)<br>Changeable by changing lead wire connections  |
| Distortion           | 5 % or less (at 1 kHz rated output)   |
| Frequency Response   | 100 Hz – 10 kHz   |
| Input                | Mic1, 2: 600 Ω, 4 mV, phone jack<br>Aux: 10 kΩ, 500 mV, phone jack  |
| Finish               | Front panel: ABS resin, black<br>Case: Zinc plated steel sheet  |
| Dimensions           | 178 (W) × 50 (H) × 144 (D) mm (Mounting device excluded)  |
| Weight               | 1.1 kg  |
| Accessory            | Microphone holder ..... 1, Mounting bracket ..... 1, Mounting screw ..... 1set,<br>Fuse (8 A) ..... 1, Connection cord ..... 1set |
| Accessory Microphone | Unidirectional dynamic type with talk switch<br>Impedance: 600 Ω<br>Sensitivity : -53 dB (1 kHz, 0 dB = 1 V/Pa)                   |

## APPEARANCE


Rear View

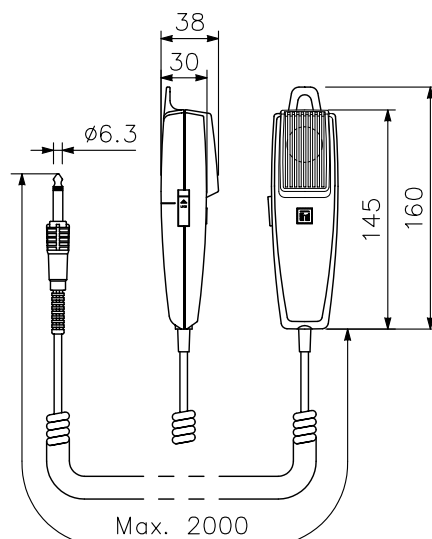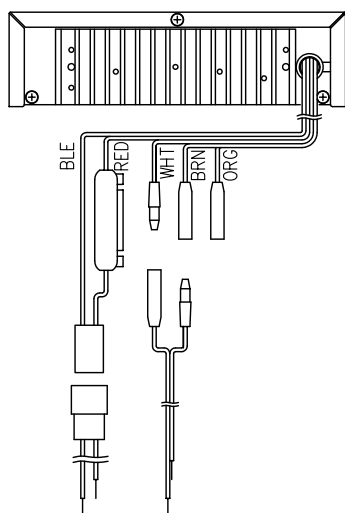


Top View

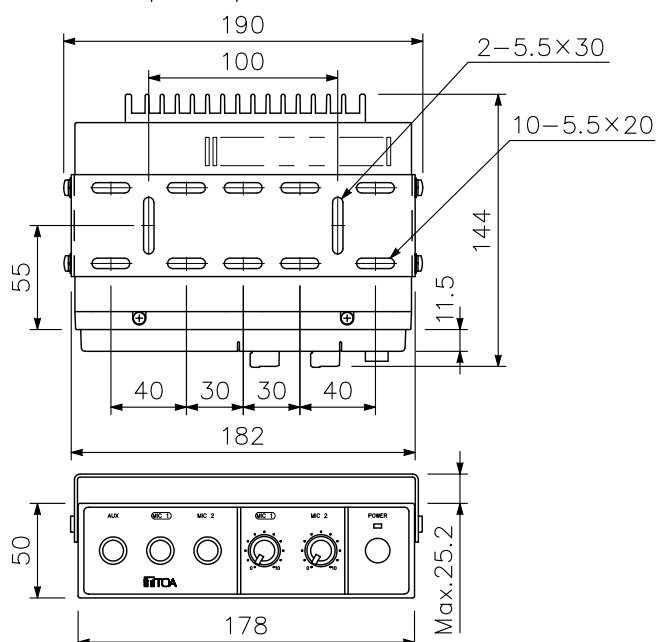

Front View

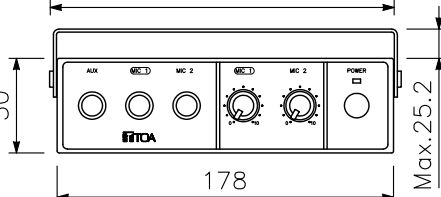

Accessory microphone (1/5)

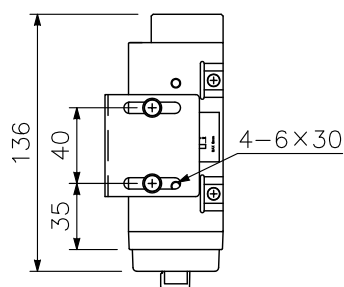

Side View

UNIT:mm SCALE:1/4