

PM-LPB

Yokeless Low Profile Projector Mount

Product Features:

Fits most projectors with mounting holes inside 14.5" dia.

Low 2.625" mounting profile
(measurement includes the mounting feet)

Adjustable tilt - $\pm 20^\circ$ / Adjustable pitch - $\pm 15^\circ$

Adjustable yaw (rotation) - 360°

1.5" NPT mast telescopes 23" - 35"

Cable management through the center of the mast

Flush mount plate and mounting screws included

Load capacity - 75 lbs

Black powder coat finish

Also available in silver finish (PM-LP)

Product Specifications:

(for Architects & Engineers)

The low profile universal yokeless ceiling mount for LCD projectors shall be a Video Mount Products (VMP) model PM-LP. The mount shall be constructed primarily of formed steel and shall incorporate arc welds. The mount shall have adjustable tilt up to a maximum of 20° , adjustable pitch up to a maximum of 15° , and adjustable yaw (rotation) of $\pm 180^\circ$.

The mount shall be able to fit most projects with hole patterns inside a 14.5" diameter. The mount shall include a telescoping ceiling mast adjustable from 23" to 35". The projector mount shall also have the ability to be flush mounted to the ceiling on 16" centers or along a ceiling joist. The mount shall have cable management through the center of the mast with multiple access point at the top and the bottom of the mast. The load capacity shall be 75 lbs.

Video Mount Products

345 Log Canoe Circle


Stevensville, MD 21666

Toll Free: 877.281.2169

Telephone: 410.643.6390

Facsimile: 410.643.6615

www.videomount.com

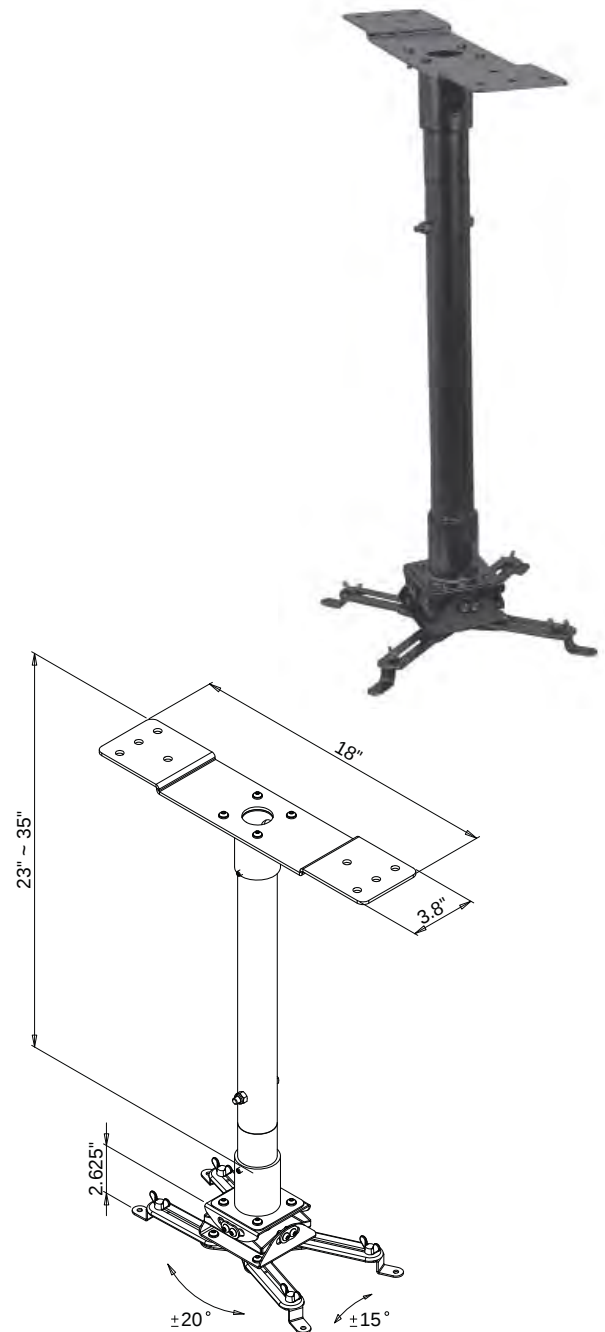

VMP
VIDEO MOUNT PRODUCTS