



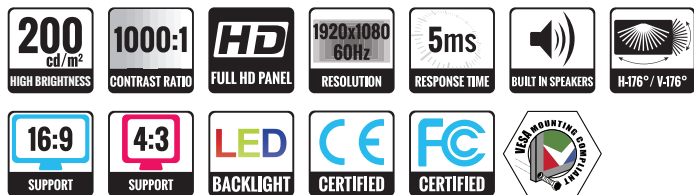

VZ-19CME ADVANTAGES


- 19.5" HD Resolution
- 16:9 / 4:3 Ratio Available
- HDMI, DVI, VGA
- Built-in Speakers
- 3-Year Warranty

DIMENSIONS

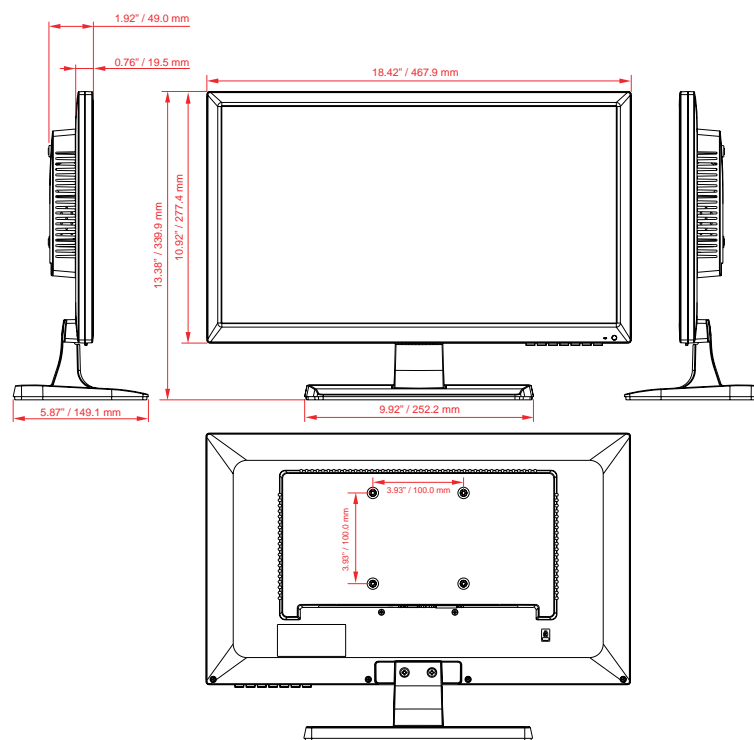

MODEL #		VZ-19CME
VIDEO		
Screen Size	19.5"	
Max. Resolution	1920 x 1080 @60Hz	
Pixel Pitch	0.2265 mm x 0.221 mm	
Brightness	200cd/m ² (Typical)	
Contrast Ratio	1000:1	
Aspect Ratio	16 : 9	
Viewing Angle (H/V)	176° / 176°	
Display Color	16.7 Million	
Response Time	< 5ms	
Video System	NTSC / PAL	
Frequency (H)	30 ~ 80 kHz	
Frequency (V)	56 ~ 75 Hz	
INTERFACE		
HDMI In	1	
DVI In	1	
VGA In (15Pin D-Sub)	1	
Audio In / Out	1 / 1	
AUDIO		
Built in speaker	2W X 2	
SPECIAL FEATURES		
Language	English, Deutsch, French, Spanish, Italian	
DIMENSIONS & WEIGHT		
Outline Dimension (W x H x D)	18.42" x 13.38" x 1.92" 467.9 mm x 339.9 mm x 49.0 mm	
Net Weight / Gross Weight	7.05 lbs (3.2kg) / 8.37 lbs (3.8kg)	
MOUNT		
VESA	100mm x 100mm (M4 x L8 screws)	
GENERAL		
Power	Electrical Ratings	DC 12V, 3A (AC 100-240V, 50/60Hz)
	Consumption	≤ 24 W
Operating Temperature Humidity		14 ~ 122°F / -10 ~ 50°C 20 ~ 70% RH
Regulations		FCC(A), CE, WEEE
Compatible Mounts	WALL CEILING RACK	VZ-WM05, VZ-WM11, VZ-AM01, VZ-AM02 VZ-CM06W/B, VZ-CM18W/B, VZ-CMKIT-01 VZ-RMK08

INTERFACE

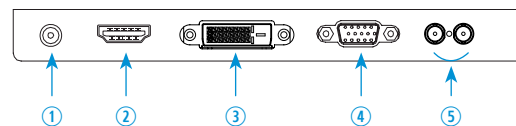

1. DC12V IN
2. HDMI IN
3. DVI IN
4. VGA IN
5. AUDIO IN / OUT

Contact ViewZ

- Address : 177 W. Orangethorpe Ave., Placentia, CA 92870
- Phone : (714) 996-1177, Fax : (714) 996-1138
- Sales : sales@viewzusa.com
- Specification subject to change without notice.