


NEW
TRADITIONS®

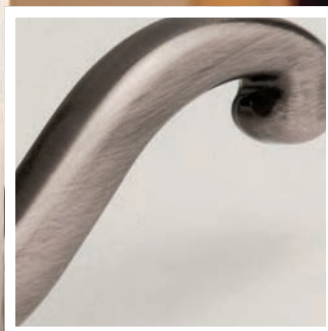

New Traditions®
Grade 3 Residential
Enhanced Quality



The world's favorite lock since 1843

Knob Selection

Knob Specifications


Door Specs	2 1/8" Face Bore 1" Edge Bore 2 3/8" or 2 3/4" Backset Box Pack: Latch Face 1" x 2 1/4" RC (Round Corner) SC (Square Corner, optional)
Latch	Box Pack: Adjustable 2 3/8" to 2 3/4" RC RC (Round Corner)
Door Thickness	1 3/8" to 1 3/4"
Cylinder	5 Pin Cylinder (KW-1 Compatible) SC-1 optional
Keying	Box Pack: KD (Keyed Different) KA3 (Keyed Alike) Clear Pack: KA3 (Keyed Alike in sets of 3)
Faceplate	1" W x 2 1/4" H RC (Round Corner)
Strike	Box Pack: 2 1/4" Full Lip RC (Round Corner)
Certified ANSI/BHMA	A156.2 Series 4000 Grade 3 BHMA CERTIFIED

New Traditions®

Yale's Grade 3 line brings a new level of affordability, durability and style to your home. That's our tradition.



- 'Quick Install' mounting system and square spindles simplify knob and lever installation
- Keyway: KW-1; SC-1 optional, PARA optional for Levers and Deadbolts
- Non-handed levers eliminate handing issues
- Concealed holding screws

NOTE: Not for use on hollow metal doors

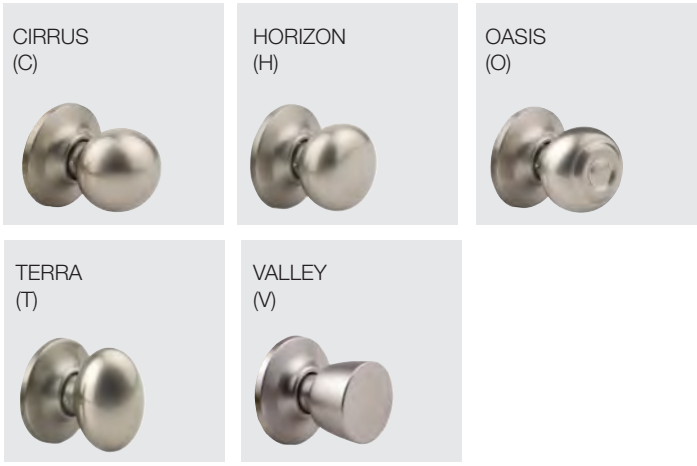

DIMENSIONS	A	B	C	FUNCTIONS
CIRRUS	2 9/16"	2 1/2"	2"	KNOB
HORIZON	2 9/16"	2 1/4"	2"	DUMMY 80
OASIS	2 9/16"	2 1/4"	2"	PASSAGE 100
TERRA	2 9/16"	2 3/8"	2 1/2"	ONE SIDED w/Plate 160
VALLEY	2 9/16"	2 5/16"	1 15/16"	PRIVACY 200
				BATH* 226
				ENTRY 700
				STOREROOM 780

*Bath: Privacy with US26 interior finish

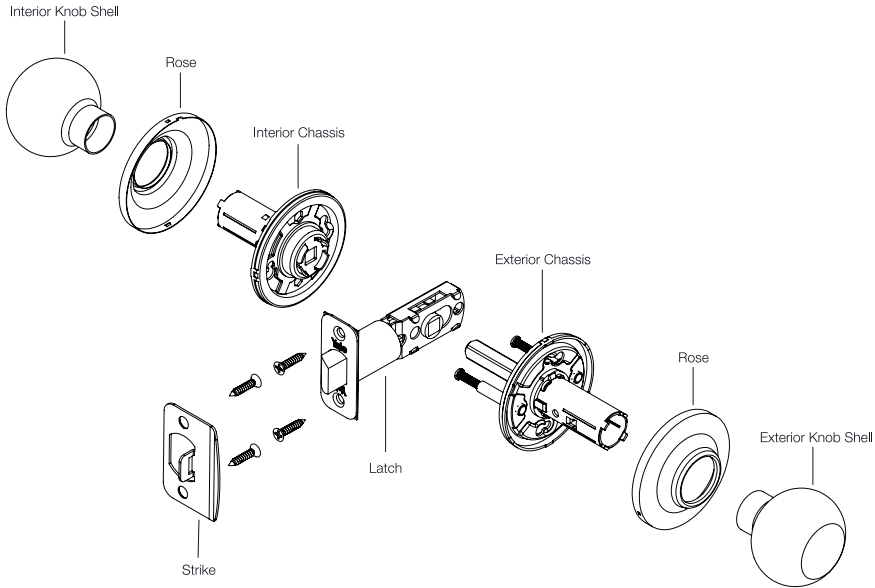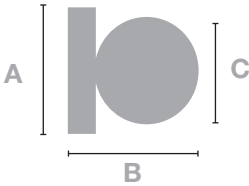

FLASHship™	US3	US5	US10BP	US10BE	US15	US15A	US26	US26D	GM	SB
CIRRUS	•		•		•			•	•	
HORIZON	•	•	•		•	•	•	•	•	•
OASIS										
TERRA			•		•				•	
VALLEY								•		

Lever Selection

Lever Specifications

Door Specs 2 1/8" Face Bore
1" Edge Bore
2 3/8" or 2 3/4" Backset
Box Pack:
Latch Face 1" x 2 1/4"
RC (Round Corner)
SC (Square Corner, optional)

Latch Box Pack: Adjustable
2 3/8" to 2 3/4" RC
RC (Round Corner)

Door Thickness 1 3/8" to 1 3/4"


Cylinder 5 Pin Cylinder
(KW-1 Compatible)
SC-1, PARA optional

Keying Box Pack:
KD (Keyed Different)
KA3 (Keyed Alike)
Clear Pack: KA3
(Keyed Alike in sets of 3)

Faceplate 1" W x 2 1/4" H
RC (Round Corner)


Strike Box Pack: 2 1/4" Full Lip
RC (Round Corner)

Certified ANSI/BHMA A156.2 Series 4000
Grade 3 **BHMA**
CERTIFIED

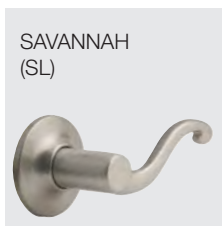


DIMENSIONS	A	B	C	FUNCTIONS
MESA	2 9/16"	2 3/8"	3 1/4"	LEVER
NIAGARA	2 9/16"	2 1/2"	4 7/32"	DUMMY 81
PRAIRIE	2 9/16"	2 1/4"	3 7/8"	PASSAGE 101
SAVANNAH	2 9/16"	2 7/16"	4 19/64"	ONE SIDED w/Plate 161
WOODLAND	2 9/16"	2 5/8"	3 7/8"	PRIVACY 201
VIDALIA	2 9/16"	2 1/2"	4 5/8"	BATH* 221
				ENTRY Knob/Lever 701
				ENTRY Lever/Lever 771
				ENTRY SFIC** 74LC

*Bath: Privacy with US26 interior finish

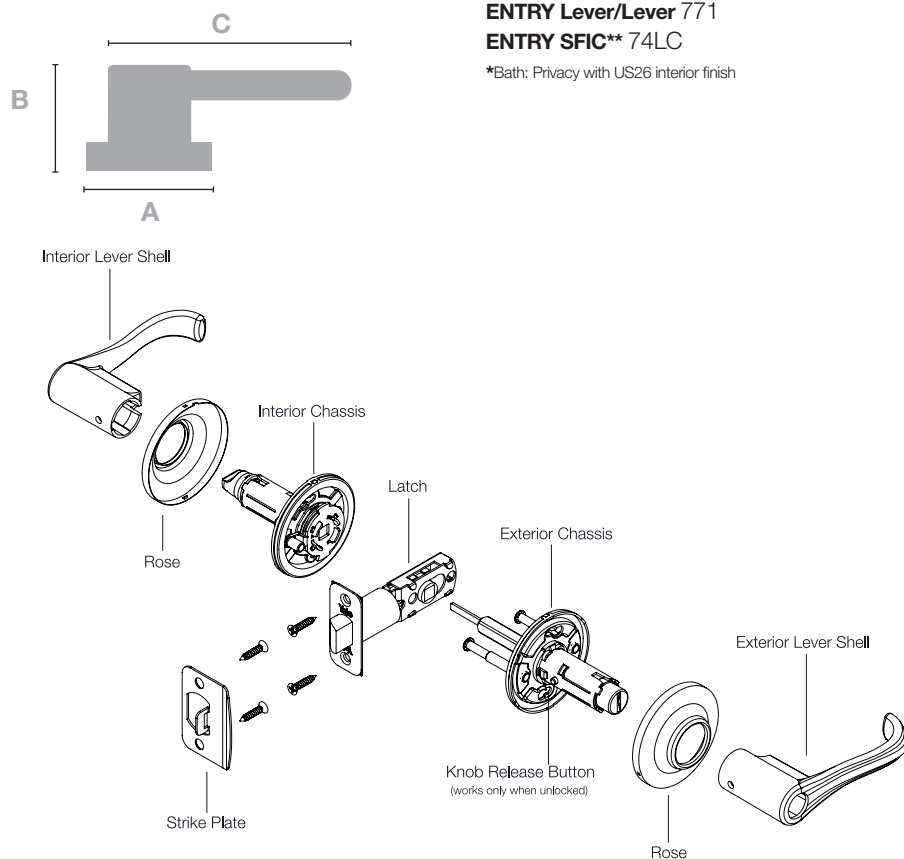

Lever rosettes


Select an upgrade for any lever styles in
Oil Rubbed Bronze Permanent, Satin Nickel,
Polished Chrome, or Suede Black.


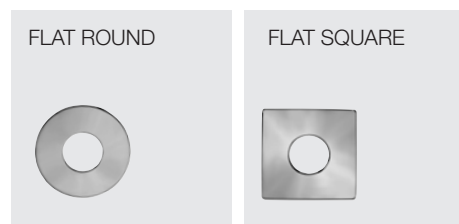


FLASHship™	US3	US5	US10BP	US10BE	US15	US15A	US26	US26D	GM	SB
MESA								•		
NIAGARA			•		•					•
PRAIRIE					•			•		
SAVANNAH	•		•		•	•	•	•	•	
WOODLAND		•	•		•	•	•	•	•	•
VIDALIA			•		•			•		•

Deadbolt Selection

Deadbolt Specifications

Door Specs	2 1/8" Face Bore 1" Edge Bore 2 3/8" or 2 3/4" Backset Box Pack: Latch Face 1" x 2 1/4" RC (Round Corner) SC (Square Corner, optional)
Latch	Box Pack: Adjustable 2 3/8" or 2 3/4" RC RC (Round Corner)
Door Thickness	1 3/8" to 1 3/4"
Cylinder	5 Pin Cylinder (KW-1 Compatible) SC-1, PARA optional
Keying	Box Pack: KD (Keyed Different) KA3 (Keyed Alike) Clear Pack: KA3 (Keyed Alike in sets of 3)
Faceplate	1" W x 2 1/4" H RC (Round Corner)
Strike	Box Pack: 1 x 2 1/4" RC (Round Corner)
Certified ANSI/BHMA	A156.5, Grade 3 

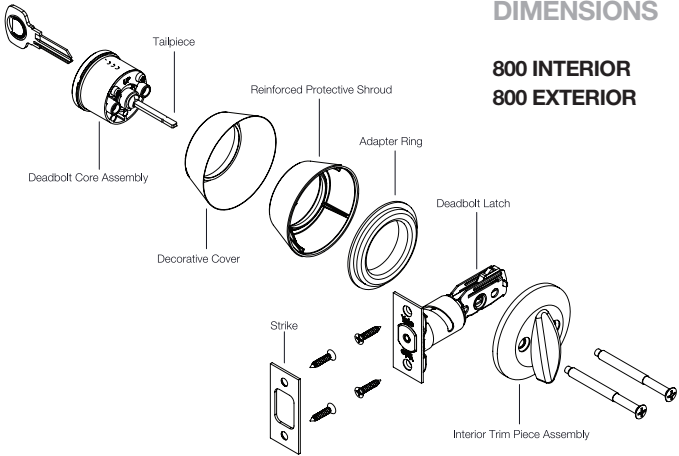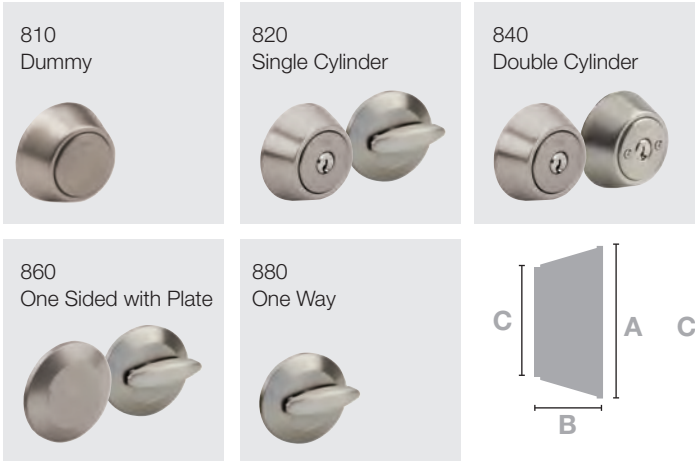


DIMENSIONS	A	B	C
800 INTERIOR	2 1/2"	15/16"	2"
800 EXTERIOR	2 1/2"	1"	1 7/8"

FUNCTIONS
DEADBOLT
DUMMY 810
SINGLE CYLINDER 820
DOUBLE CYLINDER 840
ONE SIDED W/ PLATE 860
ONE WAY 880

FLASHship™	US3	US5	US10BP	US10BE	US15	US15A	US26	US26D	GM	SB
DUMMY										
SINGLE CYL	•	•	•		•	•	•	•	•	•
DOUBLE CYL	•		•		•	•			•	•
ONE SIDED/ PLATE								•		
ONE WAY					•			•		

Yale Designer Finishes

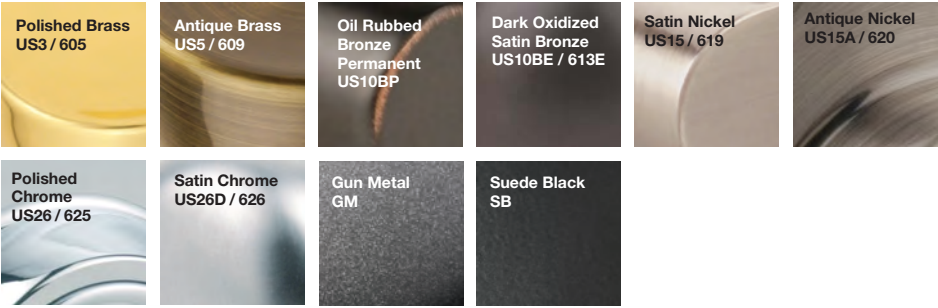

Yale Locks & Hardware 225 Episcopal Road, Berlin, CT 06037 USA
Tel 1-800-438-1951 Fax 1-800-338-0965 YaleHome.com

Yale Locks & Hardware is a division of Yale Security Inc., an ASSA ABLOY Group company.

Yale® and New Traditions® are registered trademarks of Yale Security Inc., an ASSA ABLOY Group company. Copyright © 2017, Yale Security Inc., an ASSA ABLOY Group company. All rights reserved. Reproduction in whole or in part without express written permission of Yale Security Inc., an ASSA ABLOY Group company is prohibited.

YALE, with its unique global reach and range of products, is the world's favorite lock — the preferred solution for securing your home, family and personal belongings.

ASSA ABLOY is the global leader in door opening solutions, dedicated to satisfying end-user needs for security, safety and convenience.

099646E 9/17

Community Service

Yale is Habitat for Humanity's national lockset partner and has helped families build strength, stability and self-reliance since 2001.



Habitat
for Humanity®

