



YH
COLLECTION™




YH Collection™
Grade 2 Residential
Light Commercial



The world's favorite lock since 1843

Knob selection

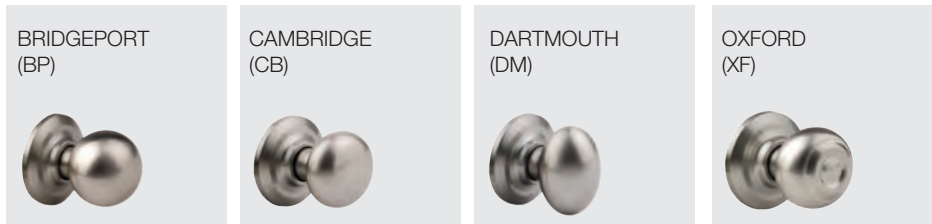

Knob/Lever Specifications

Door Specs 2 1/8" Face Bore
1" Edge Bore
2 3/8" or 2 3/4" Backset

Box Pack:
Latch Face 1" x 2 1/4"
RC (Round Corner)
SC (Square Corner, optional)

Latch Box Pack: Adjustable
2 3/8" to 2 3/4" RC
RC (Round Corner)

Door Thickness 1 3/8" to 1 3/4"


Cylinder 6 Pin Cylinder
(KW-1 Compatible)

Keying Box Pack:
KA3 (Keyed Alike)

Faceplate 1" W x 2 1/4" H
RC (Round Corner)

Strike Box Pack: 2 1/4" Full Lip
RC (Round Corner)

Certified ANSI/BHMA
A156.2 Series 4000
Grade 2 **BHMA**
CERTIFIED

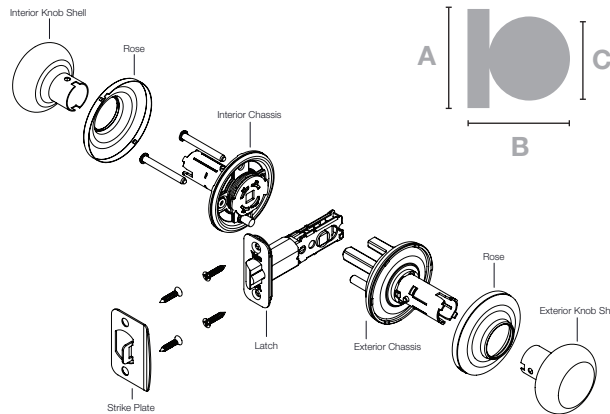

DIMENSIONS	A	B	C
BRIDGEPORT	2 9/16"	2 9/16"	2"
CAMBRIDGE	2 9/16"	2 1/4"	2 5/64"
DARTMOUTH	2 9/16"	2 3/8"	2 1/2"
OXFORD	2 9/16"	2 1/4"	2 1/8"

FUNCTIONS

KNOB

DUMMY 80
PASSAGE 10
ONE SIDED w/Plate 60
PRIVACY 20
BATH* 26
ENTRY 70

CLASSROOM 75
STOREROOM 78

*Bath: Privacy with US26 interior finish

FLASHship™	US3	US5	US10BP	US10BE	US15	US15A	US26	US26D	GM	SB
BRIDGEPORT	•				•					
CAMBRIDGE	•	•	•		•	•	•	•	•	•
DARTMOUTH	•		•		•					
OXFORD	•		•		•					

Does your lock have these features?

PUSH BUTTON LOCKING
panic-free egress

PRE-INSTALLED SCREWS
aligned for ease of installation

FOUR-WOUND SPRING
longer life cycles/
eliminates lever sag

SHROUD
anti-pry
security

CONCEALED
SCREWS
clean design

NON-HANDED
LEVERS
eliminate handing issues


SOLID STEEL
SPINDLE
greater durability



Lever selection



DIMENSIONS	A	B	C
ACADEMY	2 9/16"	2 7/16"	4 19/64"
AUGUSTA	2 9/16"	2 1/2"	4 3/4"
DELAWARE	2 9/16"	2 3/4"	4 5/8"
KINCAID	2 9/16"	2 7/16"	4 1/2"
MARINA	2 9/16"	3 5/16"	4 7/8"
McCLURE	2 9/16"	2 7/16"	4 3/16"
MILAN	2 9/16"	2 7/16"	4 1/16"
MONROE	2 9/16"	2 7/16"	4 5/8"
NORWOOD	2 9/16"	2 1/2"	4 7/32"
PACIFIC BEACH	2 9/16"	2 7/16"	4 3/4"
VALDOSTA	2 9/16"	2 1/2"	4 5/8"
VIRGO	2 9/16"	2 9/16"	4 1/2"

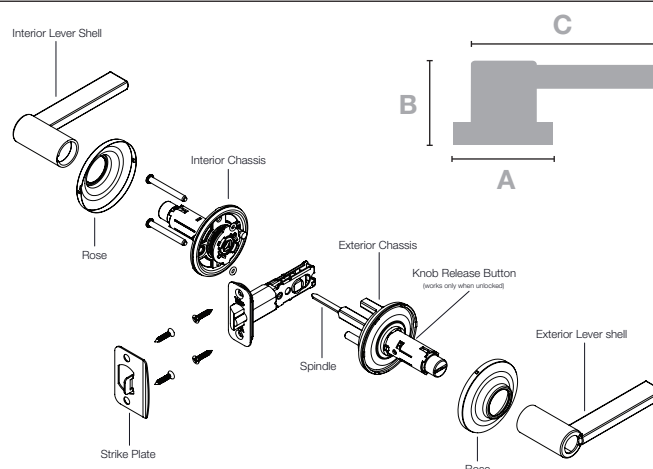

FUNCTIONS
LEVER
DUMMY 81
PASSAGE 11
ONE SIDED w/Plate 61
PRIVACY 21
BATH* 22
ENTRY Lever/Lever 71
ENTRY T-turn 73
ENTRY SFIC** 74LC
CLASSROOM 76
STOREROOM 79

*Bath: Privacy with US26 interior finish
 **Available in Augusta, Monroe, Pacific Beach

FLASHship™	US3	US5	US10BP	US10BE	US15	US15A	US26	US26D	GM	SB
ACADEMY		•			•			•		
AUGUSTA	•		•		•			•		
DELAWARE										
KINCAID			•		•					
MARINA			•		•		•			
McCLURE	•		•		•					
MILAN	•				•		•			
MONROE								•		
NORWOOD	•	•	•		•	•	•	•	•	•
PACIFIC BEACH	•				•			•		
VALDOSTA					•		•	•		•
VIRGO										


YH Collection™

Superior light commercial quality with a lifetime limited finish and mechanical warranty.


- Easy install mounting system and square spindles simplify knob and lever installation
- Keyway: KW-1; SC-1, PARA optional
- Non-handed levers eliminate handing issues
- Solid brass key cylinder and housing
- Removable levers/knobs and rosettes allow for easy scratch-free installation
- Premier series deadbolts are face removable for easy access to the deadbolt cylinders to make quick work of rekeying without removing the entire deadbolt
- Heavy-duty shroud adds a security level of anti-pry robustness

Knob | Lever rosettes

Select an upgrade for any knob or lever styles in Polished Brass, Oil Rubbed Bronze Permanent, Satin Nickel, or Polished Chrome.

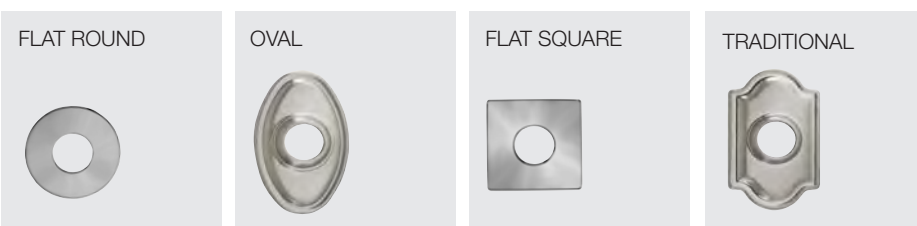


Deadbolt selection

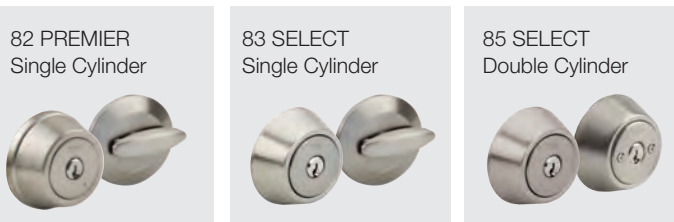


Deadbolt Specifications

Door Specs	2 1/8" Face Bore 1" Edge Bore 2 3/8" or 2 3/4" Backset
	Box Pack: Latch Face 1" x 2 1/4" RC (Round Corner) SC (Square Corner, optional)
Latch	Box Pack: Adjustable 2 3/8" to 2 3/4" RC RC (Round Corner)
Door Thickness	1 3/8" to 1 3/4" 2" to 2 1/4"
Requires Ext. Kit 07600; 83 Select Single Cylinder Only	
Cylinder	6 Pin Cylinder (KW-1 Compatible)
Keying	Box Pack: KA3 (Keyed Alike)
Faceplate	1" W x 2 1/4" H RC (Round Corner)
Strike	Box Pack: 1 1/8" x 2 1/4" RC (Round Corner)
Certified ANSI/BHMA	A156.2 Series 4000 Grade 2 BHMA CERTIFIED

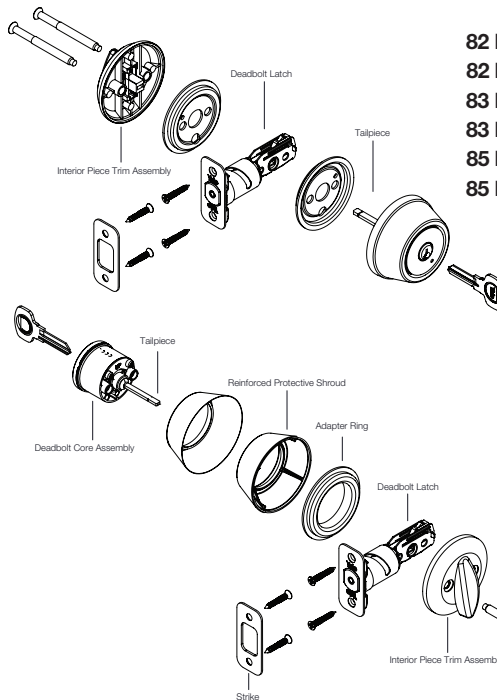

DIMENSIONS

	A	B	C
82 EXTERIOR	2 19/32"	1 1/8"	2"
82 INTERIOR	2 19/32"	1 9/64"	1 31/32"
83 EXTERIOR	2 1/2"	1"	1 7/8"
83 EXTERIOR	2 1/2"	1 7/8"	2"
85 EXTERIOR	2 1/2"	1"	1 7/8"
85 INTERIOR	2 1/2"	1"	1 7/8"

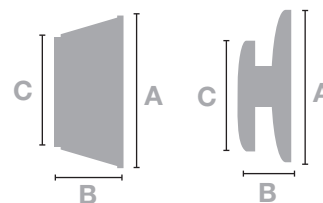


FUNCTIONS

DEADBOLT
SINGLE CYLINDER PREMIER 82
SINGLE CYLINDER SELECT 83
DOUBLE CYLINDER SELECT 85

FLASHship™	US3	US5	US10BP	US10BE	US15	US15A	US26	US26D	GM	SB
SINGLE CYL 82	•		•		•	•		•		•
SINGLE CYL 83	•		•		•	•	•	•	•	
DOUBLE CYL 85	•		•		•	•			•	

Yale Designer Finishes

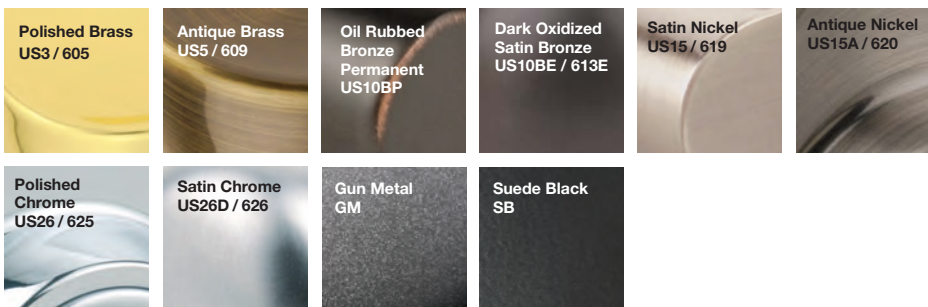

Yale Locks & Hardware 225 Episcopal Road, Berlin, CT 06037 USA
 Tel 1-800-438-1951 Fax 1-800-338-0965 YaleHome.com

Yale Locks & Hardware is a division of Yale Security Inc., an ASSA ABLOY Group company.

Yale® is a registered trademark of Yale Security Inc., an ASSA ABLOY Group company. YH Collection™ is a trademark of Yale Security Inc., an ASSA ABLOY Group company. Copyright © 2016, Yale Security Inc., an ASSA ABLOY Group company. All rights reserved. Reproduction in whole or in part without express written permission of Yale Security Inc., an ASSA ABLOY Group company is prohibited.

YALE, with its unique global reach and range of products, is the world's favorite lock — the preferred solution for securing your home, family and personal belongings.

ASSA ABLOY is the global leader in door opening solutions, dedicated to satisfying end-user needs for security, safety and convenience.

099647E 9/17

Community Service

Yale is Habitat for Humanity's national lockset partner and has helped families build strength, stability and self-reliance since 2001.

