

MCB-JBAS

Square Junction Box Plate



 

Gasket included (not shown in photo)

Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with MicroBullet® Series
	Works with AV-JBA

Mechanical	Casing	Die-cast aluminum
		IP66 weather proof standard
		IK-10 impact-resistant
	Color	Ivory (Pantone® Cool Gray 1C)
	Dimensions	See dimensional drawings below
	Weight	w/o Camera 0.28lbs (127g)

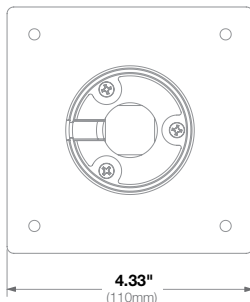

Quick Installation:

1. Attach base gasket to MicroBullet.
2. Pass cables through the center hole of the adapter plate.
3. Attach MicroBullet to MCB-JBAS adapter plate.
4. Attach the adapter plate to the AV-JBA junction box (sold separately) using the appropriate hardware and mounting holes.

MCB-JBA

Round Junction Box Adapter



Gasket included (not shown in photo)

Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with MicroBullet® Series
	Works with MCD-EBA and AV-EBAS

Mechanical	Casing	Die-cast aluminum
		IP66 weather proof standard
		IK-10 impact-resistant
	Color	Ivory (Pantone® Cool Gray 1C)
	Dimensions	See dimensional drawings below
	Weight	w/o Camera 0.74lbs (335g)

