

# AutoDome Easy Compact PTZ Camera

[www.boschsecurity.com](http://www.boschsecurity.com)



**BOSCH**

Invented for life



- ▶ Ultra-compact for discrete surveillance and improved aesthetics
- ▶ Designed for indoor applications
- ▶ Affordable, yet feature rich
- ▶ 100x zoom (10x optical, 10x digital) color camera
- ▶ Simple to install and use

The AutoDome Easy combines a high performance pan/tilt unit, compact mini dome housing, and a state-of-the-art autofocus zoom camera into a single unit. This rugged, compact and easy to install PTZ camera system has been specifically designed for discrete video surveillance applications in indoor environments.

## Easy Series highlights

With a dome diameter of less than 4 inches (10 cm), AutoDome Easy is about 70% smaller than traditional PTZ cameras and 20% smaller than other compact domes. These compact dimensions make AutoDome Easy ideal for discrete surveillance applications.

Even though it's small, AutoDome Easy still delivers many of the features found on full-size PTZ cameras. Variable pan and tilt speeds, and autopivot ensure optimal camera control and viewing at all zoom levels. The high-performance 100x (10x optical/10x digital) zoom autofocus camera incorporates the latest digital imaging technology to deliver excellent sensitivity and resolution. With 60 user-defined presets, 4 preset tours, and multiple autoscan modes, AutoDome Easy is not small on features.

A single AutoDome Easy provides as much coverage as four fixed mini domes at half the cost of a traditional PTZ dome camera. AutoDome Easy maximizes your security investment by integrating with the entire line of Bosch video products including variable speed<sup>1</sup> Allegiant matrix switchers, DiBos and Divar digital recorders, and the full range of Bosch video over IP products.

And AutoDome Easy is simple to install and use. Available with surface, wall and pipe mount options, AutoDome Easy can be mounted nearly anywhere. Intuitive set-up menus make dome configuration quick and easy. Built-in IntuiKey support means that AutoDome Easy uses the same familiar keyboard and joystick commands as the rest of the Bosch AutoDome family.

1. The AutoDome Easy is not compatible with fixed-speed dome controllers.

## Functions

The following are some of the features that make the AutoDome Easy Series the perfect fit for a variety of indoor surveillance applications.

### High-performance 100x PTZ color camera

AutoDome Easy PTZ cameras have a 1/4-inch color CCD. With 430 TVL (NTSC/PAL) resolution and sensitivity down to 1.3 lux, the AutoDome Easy Series offers exceptional performance at a very affordable price.

AutoDome Easy supports up to 60 user-defined preset positions, as well as 4 preset tours and 4 autoscan modes. Each preset tour can be programmed with up to 16 preset positions and configurable dwell time between positions. Pan, tilt, and preset tracking are accurate to within  $\pm 0.1$  to capture the correct scene every time. The integrated pan/tilt unit delivers variable pan/tilt speeds up to 120 degrees per second. AutoDome Easy provides a tilt range of 0-90 degrees, and a pan range of 0-359 degrees. The camera's overlapping field of view provides a full 360 degrees of visual coverage, eliminating any blind spots.

### Cost effective coverage

It typically requires four or more fixed dome cameras to provide a full 360 degrees of surveillance coverage. Traditional PTZ dome cameras provide full coverage, but at a significantly higher cost. A single AutoDome Easy provides as much coverage as four fixed domes, but at half the cost of a traditional PTZ dome camera. Not only is your initial investment smaller, but installation and maintenance costs are reduced as well.

### Rugged reliability

A heavy-duty, tamper-resistant aluminum housing and rugged polycarbonate bubble protect the camera from vandalism and theft, ensuring the AutoDome Easy continues to deliver critical images even in the toughest environments.

As with all Bosch products, AutoDome Easy has been subjected to the industry's most comprehensive and demanding battery of endurance tests to make sure it will hold up through years of use. And of course it comes with Bosch's industry-leading 3-year warranty.

### Ease of installation and servicing

AutoDome Easy has been designed for quick and easy installation. The dome comes fully assembled and ready for surface mount applications. Available wall and pipe mount kits allow AutoDome Easy to easily be adapted for the individual site requirements. Available in white or charcoal.


An intuitive set-up menu structure and multiple language support make dome configuration quick and easy. Supported on-screen display menu languages include: English, Spanish, and French.

### Certifications and approvals

Electromagnetic Compatibility (EMC)	Complies with FCC Part 15, ICES-003, and CE regulations
Product Safety	Complies with CE regulations, UL, CSA, EN, and IEC Standards

Region	Certification
Europe	CE

### Installation/configuration notes

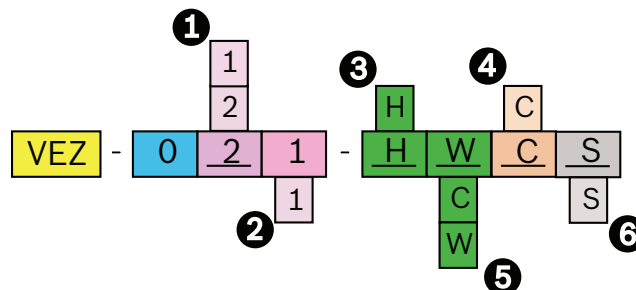

### Ordering Guide

#### 1 Video Format

- 1 PAL
- 2 NTSC

#### 2 Camera Type

- 1 Color (10X)

#### 3 Housing

- H High Impact

#### 4 Bubble


- C Clear

#### 5 Color


- C Charcoal
- W White

#### 6 Communications


- S Analog

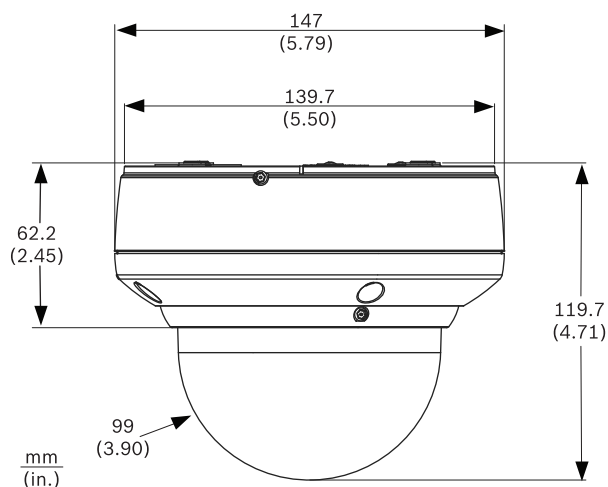


AutoDome Easy Dimensions

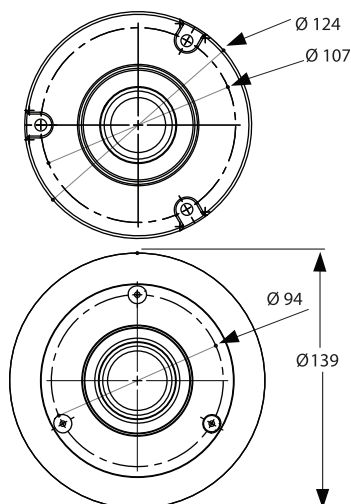

Surface Mount Dimensions

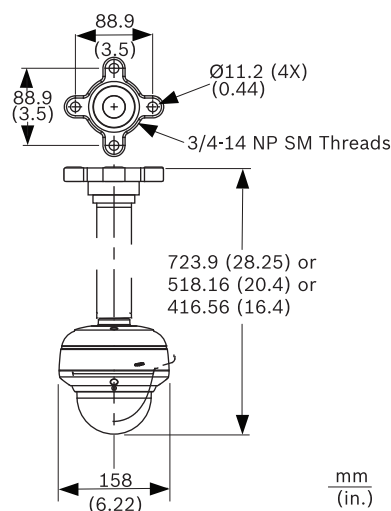

Pipe Mount Dimensions

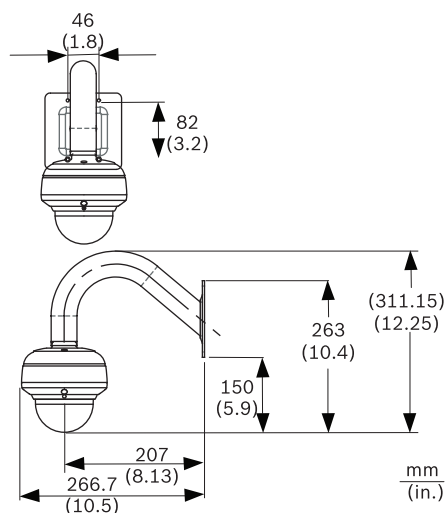

Wall Mount Dimensions

**Technical specifications****Camera 10x Color**

Imager	1/4 in. Exview HAD CCD	
	(752 x 582 PAL)/(768 x 494 NTSC)	
Lens	10x Zoom (3.15–31.5 mm)	
Focus	Automatic with manual override	
Iris	Automatic with manual override (F1.6 to F3.2)	
Field of View	Approx. 6.5° (TELE end) to 48° (Wide end)	
Video Output	1.0 Vp-p, 75 Ohm	
Gain Control	AGC on/off (30dB max)	
Synchronization	Internal/external (line-lock auto switching)	
Digital Zoom	10x	
Sensitivity (typical)	30 IRE	50 IRE
	1.3 lx	2.7 lx
SNR	48 dB	

**Mechanical/Electrical**

Weight	1.3 kg (2.86 lb)
Pan Range	0-359°
Tilt Angle	0-90°
Pan Speed	120°/s max
Tilt Speed	120°/s max
Preset Accuracy	± 1° typ.
Rated Voltage	12 VDC / 24 VAC 50/60 Hz
Voltage Range	10.8 to 13.2 VDC 21.6 to 26.4 VAC
Power Draw: (typ.)	10 W

**Environmental**

Operating Temp.	-10°C to 40°C (14°F to 104°F)
Operation Humidity	0% to 96%
Storage Temp.	-20°C to 60°C (-4°F to 140°F)

**Miscellaneous**

Sectors/Titling	8 independent sectors with 10-character titles/sector
Camera Setup/Control	Biphase (variable speed only)

Communications Protocols	Biphase (variable speed only)
Pre-positions	60, each with 10-character titles
Preset Tours	<ul style="list-style-type: none"> <li>• Preset tour - four (4), consisting of up to 16 scenes, consecutively</li> </ul>
ID Address	1 - 63
Supported Languages	English, French, and Spanish

### User Connections

Power (Camera)	24 VAC, 50/60 Hz or 12 VDC
Control	Biphase +/-
Video	1 Vp-p on BNC
Alarm Input (1)	NC/NO/OFF

### Ordering information

#### VEZ-011-HWCS Easy Dome

Easy Dome 10X Color PAL White

Order number **VEZ-011-HWCS**

#### VEZ-021-HWCS Easy Dome

Easy Dome 10X Color NTSC white

Order number **VEZ-021-HWCS**

#### VEZ-011-HCCS Easy Dome

Easy Dome 10X Color PAL Charcoal

Order number **VEZ-011-HCCS**

#### VEZ-021-HCCS Easy Dome

Easy Dome 10X Color NTSC Charcoal

Order number **VEZ-021-HCCS**

### Accessories

#### VEZ-A-WW Wall Mount

AutoDome Easy wall mount white

Order number **VEZ-A-WW**

#### VEZ-A-WC Wall Mount

AutoDome Easy wall mount charcoal

Order number **VEZ-A-WC**

#### VEZ-A-PW Pipe Mount

AutoDome Easy pipe mount white

Order number **VEZ-A-PW**

#### VEZ-A-PC Pipe Mount

AutoDome Easy pipe mount charcoal

Order number **VEZ-A-PC**

#### VDA-NWDFMT Flush-mount Ceiling Kit

Order number **VDA-NWDFMT**

#### VDA-NWDSKT Support Kit for VDA-NWDFMT

Order number **VDA-NWDSKT**