



CL Series cabinet locks conventional cylinder

CL Series cabinet and drawer locks

Conventional cylinder



Cabinet door lock - CL100PB

Rekeyable: Easily rekeyed via patented set-screw cylinder removal mechanism

Certifications: ANSI A156.11, Grade 2

Body: Die cast zinc

Bolt: Brass, ¹⁵/₁₆" projection

Door thickness: ⁷/₈" to 1³/₈"

Barrel diameter: 1¹/₈"

Cylinder: Schlage Everest 29 S123

Keying: KD, KA or MK

Finishes: 626 and 605

Not available without cylinder.



Drawer lock - CL200PB

Rekeyable: Easily rekeyed via patented set-screw cylinder removal mechanism

Certifications: ANSI A156.11, Grade 2

Body: Die cast zinc

Bolt: Steel, ³/₄" throw

Door thickness: ⁷/₈" to 1³/₈"

Barrel diameter: 1¹/₈"

Cylinder: Schlage Everest 29 S123

Stock keying: KD, KA or MK

Finishes: 626 and 605

Not available without cylinder.

Finishes

See product description for available finishes.

Bright brass 605



Satin chrome 626



Full size interchangeable core (FSIC)



Cabinet door lock - CL777R

Rekeyable: Easily rekeyed via patented set-screw cylinder mechanism

Certifications: ANSI A156.11, Grade 1

Body: Die cast zinc

Bolt: Brass, ¹⁵/₁₆" projection

Barrel length: 1⁷/₁₆"

Barrel diameter: 1¹/₈"

Cylinder: Primus XP, Everest or Classic

Keying: KA, KD, MK or construction core

Finishes: 626 and 605

Not available without cylinder.



Drawer lock - CL888R

Rekeyable: Easily rekeyed via patented set-screw cylinder mechanism

Certifications: ANSI 156.11, Grade 2

Body: Die cast zinc

Bolt: Brass, ⁷/₈" projection

Door thickness: ⁷/₈" to 1³/₈"

Barrel diameter: 1¹/₈"

Cylinder: Primus XP, Everest or Classic

Keying: KA, KD, MK or construction core

Finishes: 626 and 605

Not available without cylinder.



Cam lock - CL920R

Body: Die cast zinc

Body diameter: 1¹/₈"

Mounting cutout: 1⁵/₃₂"

Max material thickness: 1¹/₈"

Min material thickness: 0.08"

Across flats: ⁷/₈"

Cylinder: Primus XP, Everest or Classic

Keying: KA, KD, MK or construction core

Finishes: 626 and 605


Not available without cylinder.

Cylinders for exit devices, aluminum door, etc.

CL Series cabinet locks

CL1000

CL2009

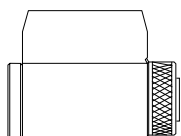

Door



Drawer

Application	Bolt	Complete lock			Cylinder only		
		Conventional	Primus/ Primus XP	Primus/ Primus XP UL	Conventional	Primus XP	Primus UL
Door	1" (std)	CL100PB	CL1740PB CL1740PB-XP	CL1540PB CL1540PB-XP	20-172	20-772XP	20-572
Drawer	$\frac{3}{4}$ " (std)	CL200PB	CL2749PB	CL2549PB	20-174	20-774XP	20-574

Available 605 and 626 finish. Everest 29 S123 keyway standard.