

Recessed Mount Magnetic Contacts

1055 Series

OVERVIEW

The 1055 Series of Magnetic Contacts is designed for tight-fitting installations. The 1/4-inch diameter makes the contacts perfect for applications such as casements or awning-style windows and security screens.

The contacts can be either recessed or surface mounted in window frame channels, and are difficult to detect in recessed door applications. A wide-gap model is available for loose-fitting doors and windows.

Each contact includes a hermetically sealed reed switch that is potted in the housing.

STANDARD FEATURES

- 1/4-inch diameter allows for recessed or surface mounting
- Attractive, added security of recessed mounting
- Ideal for casement and awning-style windows
- Wide-gap model available




Specifications

Voltage	100VAC/VDC max.
Current	0.5A max.
Power	7.5W max.
Loop type	Closed
Electrical configuration	Normally open
Gap distance	1055: Up to 1/2 in. 1055W: Up to 1-1/4 in.
Lead type	1 ft. #22 wire
Dimensions	1.125 in. L x 0.25 in. dia. (29 x 6.4 mm)
Housing	Flame retardant ABS plastic
Color	White
Regulatory	UL, CUL

Ordering Information

1055-N	Recessed Mount Magnetic Contact w/Wire Leads, 1/4" Diameter, 1/2" Gap Size, White
1055W-N	Recessed Mount Magnetic Contact w/Wire Leads, 1/4" Diameter, Wide Gap, 1-1/4" Gap Size, White

Dimensional Diagram

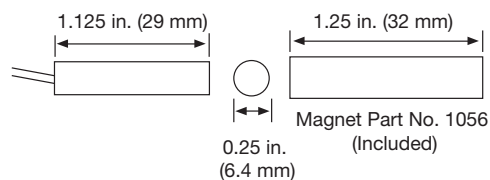

interlogix.com

Specifications subject to change without notice.

© 2014 United Technologies Corporation.

All rights reserved.

Interlogix is part of UTC Building & Industrial Systems, a unit of United Technologies Corporation.

305-3669 2014/04 (75043)

North America
T 855-286-8889

Latin America
T 561-998-6114