


## DOOR & WINDOW CONTACTS / **SURFACE MOUNT**

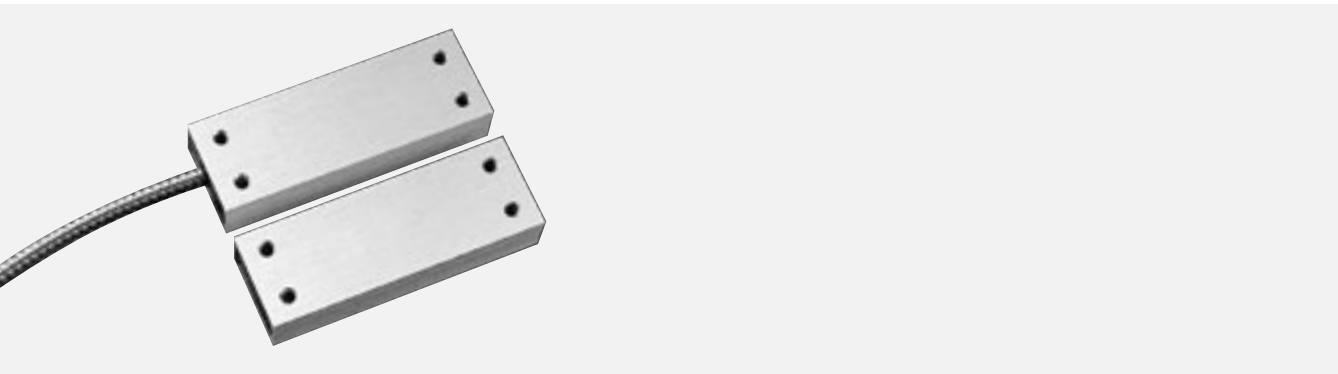


### 2700 Series

- High security
- Triple-biased reeds, highly resistant to defeat
- Includes magnetic field tamper and pry tamper plate
- Factory compensated for the effects of steel
- Suitable for outdoor use
- Listed for use on safes and vaults
- UL/ULC

#### Ordering Information

<b>2706AP-L</b>	3/16" to 5/8" Gap, SPDT, Remote Test-protective Loop
<b>2706AS-L</b>	3/16" to 5/8" Gap, SPDT, Remote Test-supervised Loop
<b>2707A-L</b>	3/16" to 5/8" Gap, SPDT
<b>2707AD-L</b>	3/16" to 5/8" Gap, DPDT

## DOOR & WINDOW CONTACTS / **RECESSED MOUNT**

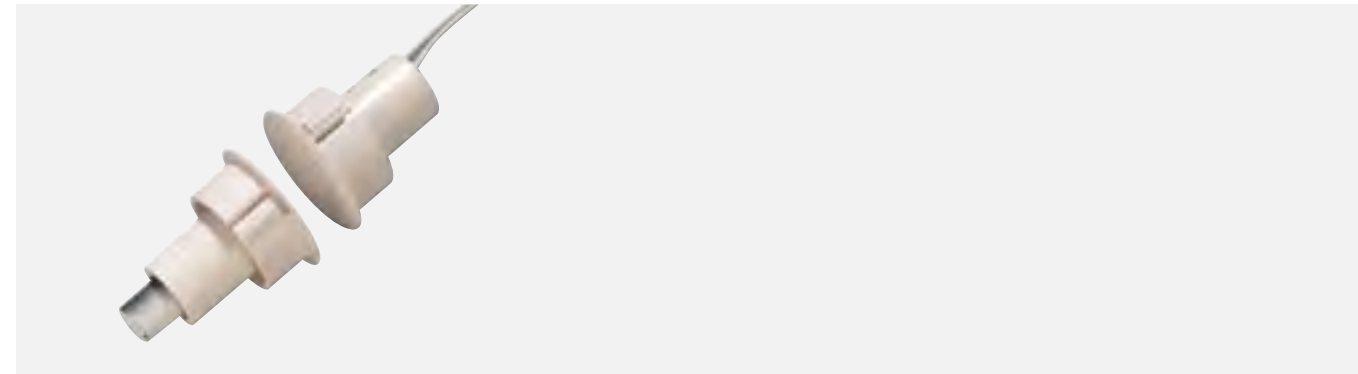

### 1078/1076 Series

- Easy, press fit design for steel doors
- Ribbed, self-lock mounting
- Rugged, unibody construction for maximum durability. Sealed Reed Switches for maximum corrosion protection
- Flexible gap distances allow for fast, easy installation and prevent false alarms caused by loose-fitting doors
- Rare Earth Magnet designed for steel door with top channel available
- UL/ULC

#### Ordering Information

<b>1076</b>	1" dia., SPDT, 1/2" Gap
<b>1076C</b>	3/4" dia., SPDT, 3/4" Gap
<b>1076W</b>	3/4" dia., SPDT, 3/4" Gap
<b>1076D</b>	1" dia., DPDT, 1/2" Gap
<b>1078</b>	1" dia., Closed Loop, 1/2" Gap
<b>R1078</b>	1" dia., Closed Loop, 1/2" Gap, Rare Earth Magnet
<b>1078C</b>	3/4" dia., Closed Loop, 3/8" Gap
<b>1078W</b>	1" dia., Closed Loop, 1" Gap
<b>1078CT</b>	3/4" dia., Closed Loop, 7/8" Gap (3/8" in steel)
<b>1078CTW</b>	3/4" dia., Closed Loop, 2" Gap (3/4" in steel)

Note: Additional colors and variations may be available.