


QRN-810

8CH Network Video Recorder

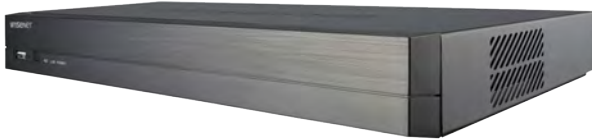


Key Features

- Up to 8CH, 8megapixel camera supported
- H.265, H.264, MJPEG codec support
- 100Mbps network camera recording
- Max. 1HDD, e-SATA supported
- HDMI / VGA local monitor
- ARB supported
- P2P service(QR code connect) support

Dimensions

Unit : mm (inch)

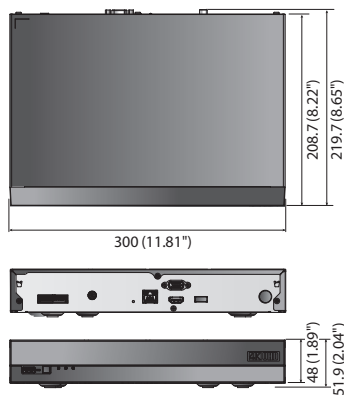

QRN-810		
DISPLAY		
Video	Inputs	Up to 8CH
	Resolution	CIF ~ 8MP
	Protocols	Samsung, ONVIF
Live	Local Display	HDMI /VGA
	Multi Screen Display	[Local monitor] 1 / 2V / 3V / 4 / 6 / 8 / Auto sequence [Web] 1 / 4 / 8 / Auto sequence
	Performance	[Local monitor] 8MP (60fps), 5MP (90fps), 3MP (120fps), 2MP (240fps), 720p (240fps), D1 (240fps)
PERFORMANCE		
Operating System	Embedded	Linux
Recording	Compression	H.265, H.264, MJPEG
	Recording Bandwidth	100Mbps
	Resolution	CIF ~ 8MP
	Mode	Manual, Schedule (Continuous / Event), Event (Pre / Post)
	Event Trigger	Alarm input (4), Video loss, Camera event (Sensor, MD, Video analytics, Defocus)
	Event Action	E-mail, PTZ preset, Alarm out, Buzzer, Monitor out
	Playback Bandwidth	32Mbps (8CH simultaneously)
Search & Playback	Performance	Max. 3 users (Local 1, Remote 3)
	Mode	Date & Time (Calendar) / Event log list / Text search (POS, ANPR), ARB search, Smart search (Virtual Line w/ direction, Enter / Exit)
	Simultaneous Playback	Up to 8CH (Local, Network)
	Resolution	CIF ~ 8MP
	Playback Control	Fast/Slow Forward/Backward, Move one step up/down
Storage	Default Built-In	0TB ~ 6TB (Dependent on region)
	Internal	1(Max.6TB)
	Max. Capacity	6TB
Backup	File Backup	BU/EXE (USB), JPG/AVI (Web, CMS)
	Function	Multi channel (Up to 8CH) play, Date-time/title display
Sensor	Input / Output	4 / 3 (NO 2ea, NO/NC 1ea)
Audio	Input	8CH (Network)
	Compression	G.711, G.726, AAC (16/48KHz)
	Audio Communication	2-way
NETWORK		
Protocol Support		TCP/IP, UDP/IP, RTP (UDP), RTP (TCP), RTSP, NTP, HTTP, DHCP (Server, Client), PPPoE, SMTP, ICMP, IGMP, ARP, DNS, DDNS, uPnP, HTTPS, SNMP, ONVIF (Profile-S), SUNAPI (Server, Client)
DDNS		Hanwha security DDNS
Transmission Bandwidth		128Mbps
Max. Remote Users		Search 3 / Live unicast 10 / Live multicast 20
IP		IPv4 / IPv6
Security		IP address filtering, User access log, 802.1x authentication, Encryption
Language	GUI / Web	English, French, German, Italian, Spanish, Russian, Turkish, Polish, Dutch, Swedish, Czech, Portuguese, Danish, Rumanian, Serbian, Croatian, Hungarian, Greek, Norwegian, Finnish, Korean, Chinese(Simplified), Japanese, Thai
OS		Supported OS : Windows 7, 8, 10, Mac OS X 10.8, 10.9, 10.10, 10.11
Web Browser		Non-plugin Webviewer Supported Browser : Google Chrome 47, MS Edge 20 Plug-in Webviewer Supported MS Explore 11, Mozilla Firefox 43, Apple Safari 9 * Mac OS X only
Viewer	Type	SSM, Webviewer, SmartViewer, Wisenet mobile
Software	CMS Support	SDK / CGI (SUNAPI)
FUNCTIONS		
Camera Setup	Register	Auto mode, Manual mode
	Setup Items	IP address, Add profile edit, Bitrate, Compression, GOP, Quality, Camera MD setup, Camera video setup (Simple focus, Brightness / Contrast, Flip / Mirror, IRIS, WDR, D&N, SSNR, Shutter, SSDR, DIS), Fisheye dewarping (Web), Hallway view setup, Camera webpage
Easy Configuration		Setup wizard (Date/Time, Network, Auto camera configuration), P2P (QR code)
Redundancy	ARB	Yes
PTZ	Control / Preset	Via GUI, Webviewer, 255 presets
	OS	Android, iOS
Smart Phone	Protocol Support	RTP, RTSP, HTTP, CGI (SUNAPI)
	Control	Live (8CH) : Multi-profile support, Playback (1CH), Event push
	Max. Remote Users	Search 3 / Live unicast 10 / Live multicast 20
System Control		Mouse, IR Remocon, Web
INDICATOR / INTERFACE		
Front	Indicator	Power status LED 1ea, LAN LED 1ea, Record status LED 1ea
	VGA	1ea
	HDMI	1ea - Support up to 4K (3840 x 2160)
Connections	Audio	Out 1ea (RCA, Line)
	Ethernet	1ea (WAN, 1Gbps) - WAN : Uplink to CMS
	Alarm	In 4ea (Terminal block) / Out 3ea (Terminal block)
	USB	2ea (Front 1, Rear 1)
	Reset	Switch (1ea)
	Power Cord	Included
SYSTEM		
Log	Log List	Max. 20,000 (System log, Event log each)
GENERAL		
Electrical	Input Voltage / Current	12V DC / 4A
	Power Consumption	MAX. 9W(31BTU, 2TB HDD x 1ea)
Environmental	Operating Temperature	+0°C ~ +40°C (+32°F ~ +104°F)
	Operating Humidity	20% ~ 85% RH
Mechanical	Color / Material	Black / Metal
	Dimensions (WxHxD)	300.0 x 48.0 x 208.7mm (17.32" x 1.89" x 8.22") (1U)
	Weight	1.66Kg (3.66 lb) (2TB HDD)

* The latest product information / specification can be found at hanwha-security.com
 * Design and specifications are subject to change without notice.