

Flush Mounts



SHD-B-3100FP1


SHD-400F

Description	Plenum rated In-ceiling Flush Mount Accessory		In-ceiling flush mount
Operating Temperature	N/A		-22°F to 131°F (-30°C to 55°C)
Operating Humidity	N/A		Less than 90% RH
Materials	Body	Aluminum trim ring, galvanized steel backbox	Aluminum
	Bubble	N/A	N/A
Ingress Protection	N/A		N/A
Vandal Resistance	N/A		N/A
Dimensions (WxHxD)	External	8.6"x8.6"x4.6"	6.8"x6.8"x4.3" (173x173x109mm)
	Internal	6.5" Hex, various depth	N/A
Weight	2.25 lbs		1.0 lbs
Input Voltage	N/A		N/A
Power Consumption	N/A		N/A
Color	White trim ring, gray backbox		Ivory
Applicable Model	SCV-2080/3080/6081R SNV-3082/3120/5080/5080R/5084/6084/6084R/7082/7080R/7084/7084R SND-5084/5084R/6083/6084/6084R/7084/7084R		SNV-6013


* Design and specifications are subject to change without notice

Dimensions

Unit : inch

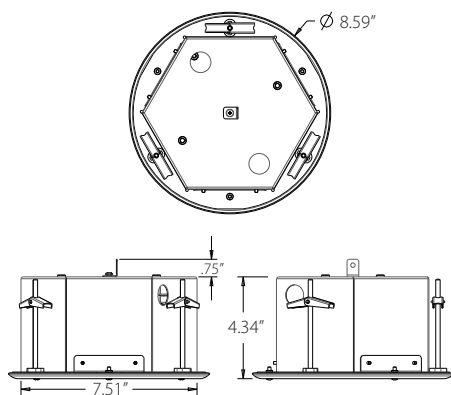

SHD-B-3100FP

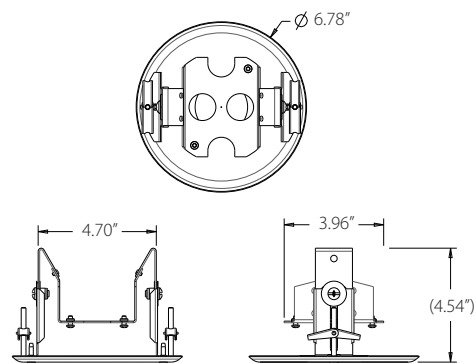

SHD-400F