



EV INNOVATION

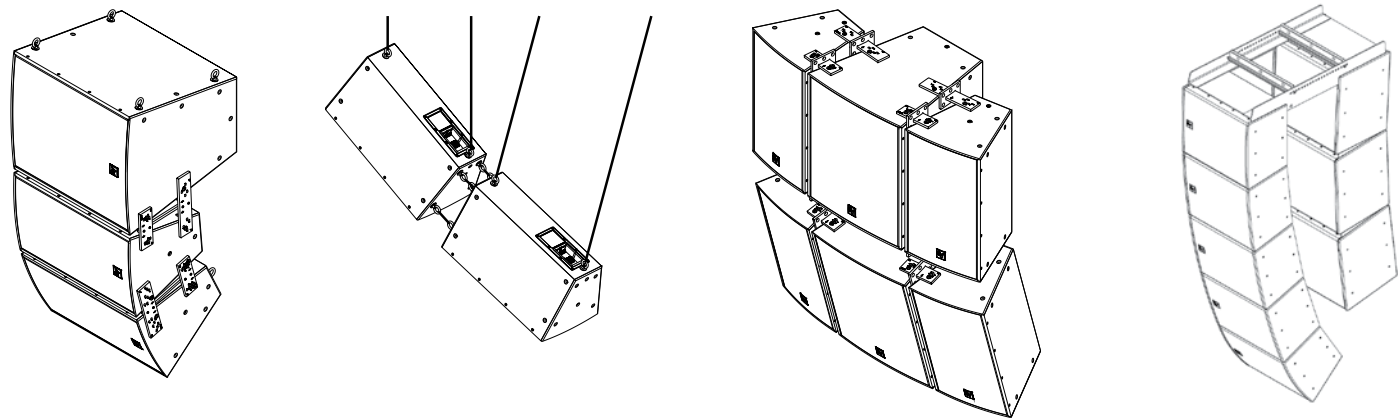


EVF and EVH Series

HRK AND VRK RIGGING KITS

VRK-1

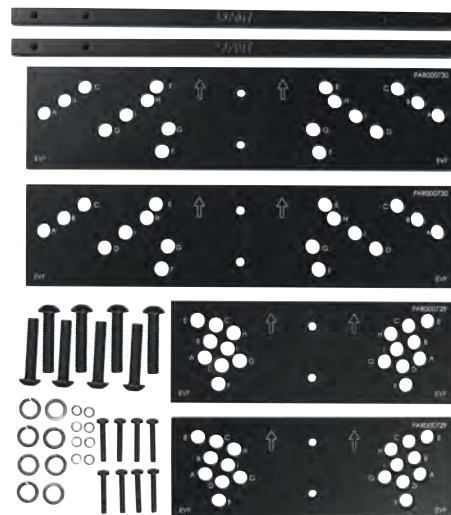

VRK-2

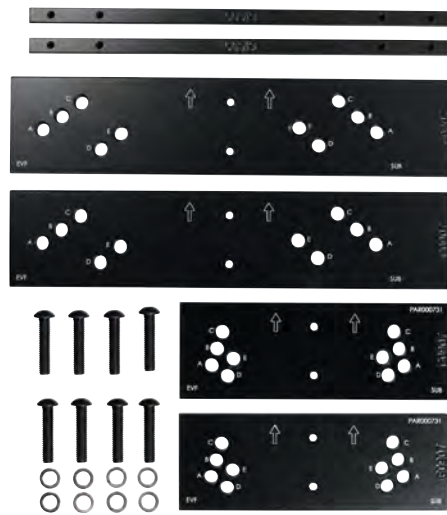

(HRK not shown)

EVA Rigging

EVA modules connect with an integrated internal top-to-bottom metal structure. Hidden by cover panels, this nearly invisible rigging system gives an EVA cluster the aesthetic appeal of an architectural element rather than a loudspeaker system. The rigging system is designed to carry an array with a safety factor of greater than 8:1.



EVA-SG2 (Standard Grid)

For typical tilt angles in 3 and 4 module arrays and pull-up applications in large arrays when extreme angles are required. Includes one spreader bar.



EVA-EG2 (Extended Grid)

For typical tilt angles in arrays taller than four modules, or extreme angles in arrays of four modules or less. Includes one spreader bar.

EVA-CG (Coupler Grid, not shown)

Connects full-range modules and single 15" subwoofers so that you can fly the subs without increasing trim height.

EVA, EVF AND EVH

GLAND NUT COVER PLATES



CDG

Dual gland nut cover plate



CDNL4

Dual NL4 cover plate



CSG

Single gland nut cover plate

EV INNOVATION ACCESSORIES

EVI-AC



ACCESS CARD

EV Innovation Access Card lets you test EVA, EVF or EVH transducers and protection circuitry without disassembling the cabinet.

TK-150



TRANSFORMER KIT

70/100 V transformer kit for EVF and EVH.

EVU-TK60



TRANSFORMER KIT

60-Watt, 70.7/100-Volt input transformer for EVU systems, with multiple taps.

EVU-CDNL4




COVER PLATE KIT

Dual NL4 cover plate for EVU series only.

EVI

EVI Series


EBK-1 (EYEBOLT KIT)

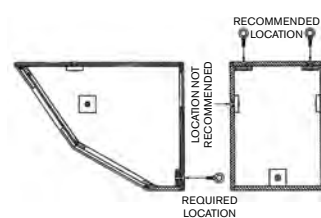

Contains three 3/8-16 forged shoulder bolts.

EVI-15


"U" STYLE BRACKET

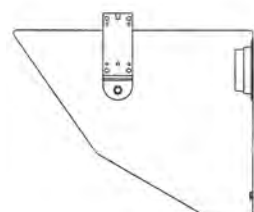

EVI-15MBB: black
EVI-15MBW: white

EVI-12


"U" STYLE BRACKET

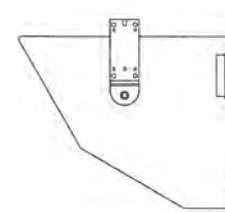

EVI-12MBB: black
EVI-12MBW: white

EVI-28

"U" STYLE BRACKET

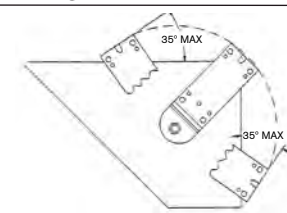

EVI-28MBB: black
EVI-28MBW: white
The radius of action is 140°.