



16-Port Rack Mount USB KVM Switch TK-1603R

The 16-Port USB KVM Switch lets you manage multiple computers with just one set of keyboard, monitor and mouse. This rack mount device supports USB and PS/2 interface on the console and USB only on the PC side. Popular hardware platforms such as PC, Linux and Mac are supported. Users can switch between PCs using hot-key or push button for flexible management. Users can also hot-plug PCs on the fly to avoid downtime. The 16-Port USB KVM Switch is the perfect choice for managing multiple PC's.

FEATURES


- 16-Port USB KVM Switch
- Supports both USB and PS/2 Interface for console port
- Supports Microsoft IntelliMouse, IntelliMouse Explorer, Logitech NetMouse, Optical Mouse, and more
- Supports Windows 98SE/ME/ 2000/XP/2003 Server, Linux, Mac OS and more
- High video quality; up to 2048 x 1536 VGA resolution
- Firmware upgradeable via PC port
- Auto-Scan for monitored PCs with adjustable scan interval from 10-99 seconds
- Keyboard status restored when switching between PCs
- LEDs display for easy status monitoring
- Beeping sound for port switching confirmation (enable/disable)
- Hot-Key or push button switching
- Plug & Play and Hot-Pluggable
- Standard 19" (1U) rack mount design
- 2-Year Warranty

16-Port Rack Mount USB KVM Switch TK-1603R

SPECIFICATIONS

Hardware	
Management	• 16 Computers
Standard	• USB 1.1 Compliant
PC Ports	• 16 x VGA HDB 15-pin (female)
Console Port	• 1 x USB (Type A) / PS/2 (6-pin Mini Din) Mouse • 1 x USB (Type A) / PS/2 (6-pin Mini Din) Keyboard • 1 x VGA HDB 15-pin (female)
Cable Interface (Optional, not included)	• To KVM: 1 x VGA HDB 15-pin (male) • To PC: 1 x VGA HDB 15-pin (male), 1 x USB (Type A)
Supported OS	• Windows 98(SE)/ME/ 2000/XP/2003 Server, Linux, Mac and More
PC Selection	• Hot-Key or Push Buttons
Auto-Scan Interval	• 10-100 seconds (Programmable through Hot-Key)
LEDs	• On-line (Red), Select (Green)
Keyboard Status	• Saved & Restored
Power Adapter	• 9V DC 1A External Power Adapter
Dimension (W x H x D)	• 407 x 165 x 45mm (16.0 x 6.5 x 1.8in.)
Weight	• 2.04kg (4.5lb)
Temperature	• Operating: 0 °C~40 °C (32 °F~104 °F) Storage: -20 °C~60 °C (-4 °F~140 °F)
Humidity	• 0%~80% (non-condensing)
Certification	• CE, FCC

NETWORKING SOLUTIONS

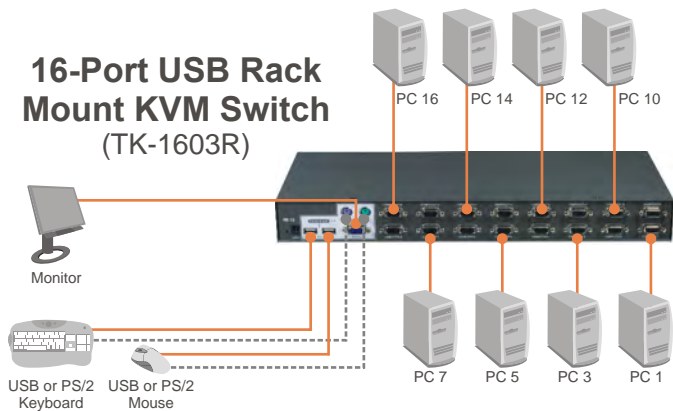

PACKAGE CONTENTS

- TK-1603R
- Multi-Language Quick Installation Guide
- Power Adapter (9V DC, 1A)
- Rack Mount Kit

RELATED PRODUCTS

TK-803R	8-Port Rack Mount USB KVM Switch
TK-1601R	16-Port Rack Mount KVM Switch
TK-1602R	16-Port Stackable Rack Mount KVM Switch with OSD

ORDERING INFORMATION

TRENDnet[®]

20675 Manhattan Place, Torrance, CA 90501 USA

Tel: 1-310-961-5500

Fax: 1-310-961-5511

Web: www.trendnet.com

Email: sales@trendnet.com

To Order Please Call:

1-888-326-6061

