



2-Port HDMI KVM Switch

TK-215i (v1.0R)

- Control two computers with one set of console controls
- Works with displays with an HDMI port
- Full HD 1080p resolution
- HDMI and 3.5 mm analog audio
- Fully integrated cabling
- Ergonomic computer toggle switch
- No CD installation
- USB Powered - No external power adapter

TRENDnet's 2-Port HDMI KVM Switch, model TK-215i, controls two computers (with an available HDMI port) with one set of console controls. No driver installation required, simply plug in the integrated cables to share two computers with a full HD 1080p display. The TK-215i supports HDMI and 3.5 mm analog audio and features an ergonomic computer toggle switch.



Computers
Control up to 2 computers



1080p HD
Supports full HD 1080p (progressive 1920 x 1080 pixels) with a 60 Hz refresh rate



2-Way Audio
Full audio support through HDMI cable connections with optional 3.5 mm microphone and speaker jacks



Toggle Switch
Use the integrated 1.5 m (5 ft.) cable to position the toggle switch in the most ergonomic location



Console Connectors
Emulation Technology supports advanced USB keyboard and mouse designs



HDMI Display
HDMI 1.3 with HDCP support



Computer Ports
Requires free USB and HDMI ports from connected computer




Integrated Cables
All required cables are integrated



Switch Software
Windows® and Mac® based KVM switch software to define hot keys and create auto-scan intervals

Networking Solution

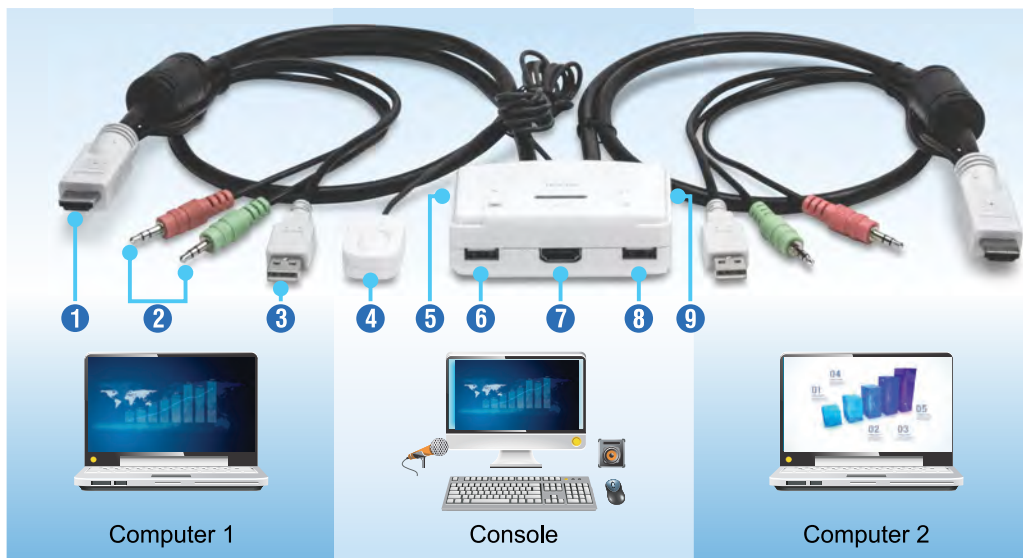

Computer 1-2

- ① HDMI connector
- ② Optional analog microphone & speaker connectors
- ③ USB keyboard/mouse connector

Console

- ④ Computer toggle switch
- ⑤ Microphone port
- ⑥ USB keyboard port
- ⑦ HDMI display port
- ⑧ USB mouse port
- ⑨ Speaker port

Specifications

Console Port on KVM

- Keyboard: USB
- Mouse: USB
- Monitor: HDMI 1.3 (19-pin)
- Speaker jack: 3.5 mm
- Microphone jack: 3.5 mm

Computer Connections (up to 2)

- Keyboard/mouse: USB 2.0 type A
- Monitor: HDMI 1.3 (19-pin)
- Speaker jack: 3.5 mm
- Microphone jack: 3.5 mm

Monitor Resolution

- 1920 x 1080 @ 60 Hz

Audio Support

- 5.1 Audio support over HDMI cables
- Analog audio over speaker and microphone jacks

LED

- Computer 1 and Computer 2

Switching Control

- One touch toggle switch
- Keyboard hot key commands
- KVM Switch Software

Supported OS

- Windows® and Mac®

Operating Temperature

- 0 – 40 °C (32 – 104 °F)

Operating Humidity

- Max. 90 % non-condensing

Dimensions

- Unit: 85 x 58 x 28 mm (3.3 x 2.3 x 1.1 in.)
- Integrated Cable: 85 cm (3 ft.)
- Toggle switch: 150 cm (5 ft.)

Weight

- 350 g (12.3 oz.)

Warranty

- 2 year limited

Certifications

- CE
- FCC

Package Contents

- TK-215i
- Quick Installation Guide
- CD-ROM (Utility & User's Guide)

